



iM2875

Storm

Travel Case

The Peli™ Storm Case™ has the same legendary DNA as our Peli Protector Case, with one primary difference: A unique Press and Pull latch that locks automatically, but open with a light touch. Guaranteed for life, the Peli Storm case is made in the USA and engineered using the finest components.

- Six Press & Pull Latches
- Two Padlockable Hasps
- Two Double-layered, Soft-grip Handles
- Powerful Hinges
- O-ring seal
- Telescoping Handle



CONFIGURATIONS



iM2875
Standard



iM2875-X0000
No Foam



iM2875-X0002
With Padded Dividers



iM2875-X0001
With Foam

DIMENSIONS

Interior (L×W×D)	22.50 x 21.10" x 11.40 (57.2 x 53.6 x 29 cm)
Exterior (L×W×D)	24.90 x 23.70" x 13.10 (63.2 x 60.2 x 33.3 cm)
Lid Depth	2.00" (5.1 cm)
Bottom Depth	9.40" (23.9 cm)
Total Depth	11.4" (29 cm)
Int Volume	3.13 ft ³ (0.089 m ³)
Padlock Hole Diameter	0.38" (1 cm)

MATERIALS

Body	Injection Molded HPX™ high performance resin
Latch	Valox - Polybutylene Terephthalate (PBT)
Latch (Alt)	Xenoy - Polyester/Polycarbonate blend
O-Ring	EPDM
Pins	Stainless Steel
Pins (Alt)	Aluminum
Foam	1.3/1.35 polyester
Purge Body	Valox - Polybutylene Terephthalate (PBT)
Purge Body (Alt)	Xenoy - Polyester/Polycarbonate blend
Purge Vent	Gortex membrane

COLOURS

 Black	 OD Green
---	--

WEIGHT

Weight With Foam	24.60 lbs (11.16 kg)
Weight Empty	20.10 lbs (9.12 kg)
Buoyancy	194.16 lbs (88.07 kg)
Master Pack Weight	32.00 lbs (14.51 kg)

TEMPERATURE

Minimum Temperature	-20°F (-28.9 °C)
Maximum Temperature	140°F (60 °C)

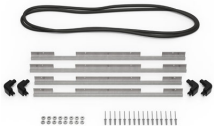
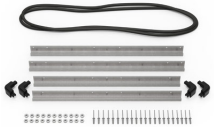
CERTIFICATIONS

IP67

OTHER

Extendable Handle	yes
Master Pack	1
Military	yes

ACCESSORIES

				
iM2875-UTILITYORG Utility Organizer	iM2875-FOAM 7 pc. Replacement Foam Set	iM-LIDSTAY Lid Stay	iM2875-M4-BEZEL-L Lid Bezel Kit (Metric)	1506TSA TSA Lock
				
1500D Desiccant Silica Gel	iM2875-M4-BEZEL Base Bezel Kit (Metric)			