

COBRA

ESSENTIAL WRAP-AROUND COMFORT

The essential all rounder with a panoramic visual field! Wrap-around fit without any visual interference, COBRA offers 180° vision and perfect optical quality. The option of swapping the temples for an adjustable strap and foam seal means COBRA is a highly versatile model.

 PLATINUM




25 g

SUPPLIED WITH

Adjustable cord
CORDC



Microfibre pouch
ETUIFS

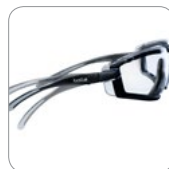

Strap + foam kit
Réf. KITFSCOB



COBFSPSI



COBFTPSI



COBPSJ



COBPSF



 
COBPSI



COBCONT



COBESP




COBHDP



COBWPC5



 KITFSCOB



OCCOBPSI

- + 1 PRODUCT = 2 USES
- + UPPER PROTECTION
- + PANORAMIC VISION
- + NON-SLIP BRIDGE
- + COMFORTABLE, NON-SLIP STRAIGHT TEMPLES
- + TEMPLE OR STRAP VERSION WITH INTERCHANGEABLE FOAM
- + PIVOTING TEMPLES

bolle
SAFETY

COBRA

ESSENTIAL WRAP-AROUND COMFORT

MODEL	VERSIONS	REFERENCES	LENS MARKING	FRAME MARKING	COATINGS
COBRA Strap + foam version	Clear	COBFSPSI	2C-1.2 ☞ 1 BT KN €€	☞ EN166 3 BT €€	Anti-scratch/Anti-fog (☞)
COBRA Temples + foam version	Clear	COBFTPSI	2C-1.2 ☞ 1 BT KN €€	☞ EN166 FT €€	Anti-scratch/Anti-fog (☞)
Transformation Kit	Strap + foam	KITFSCOB	-	-	-
COBRA temple version	Clear	COBPSI	2C-1.2 ☞ 1 BT €€	☞ EN166 FT €€	ASAF
	Comfort yellow	COBPSJ	2C-1.2 ☞ 1 BT €€	☞ EN166 FT €€	ASAF
	Contrast	COBCONT	5-1.1/1.4 ☞ 1 BT €€	☞ EN166 FT €€	ASAF
	ESP	COBESP	5-1.4 ☞ 1 BT €€	☞ EN166 FT €€	Hydrophobic/Anti-reflective/ AS
	HD	COBHDI	2C-1.2 ☞ 1 BT €€	☞ EN166 FT €€	ASAF
	Smoke	COBPSF	5-3,1 ☞ 1 BT €€	☞ EN166 FT €€	ASAF
	Welding shade 5	COBWCC5	5 ☞ 1 BT €€	☞ EN166 FT €€	ASAF
Spare lens	Clear	OCCOBPSI	2C-1.2 ☞ 1 BT €€	-	ASAF

LENS MARKING

Optical class symbols:

1. Continuous work

Mechanical strength symbols:

- B.** Medium energy impact, resists a 6 mm, 0.86 g ball at 120 m/s
- T.** The letter T, immediately after the mechanical strength symbol, authorises use for high speed particles at extreme temperatures.

Others symbols:

- K.** Resistance to surface damage by fine particles (optional)
- N.** Resistance to fogging (optional)
- €€ European standard ☞ Manufacturer name

TECHNOLOGY

B ESP

ESP, Extra sensory Perception, an innovative coating to reduce dazzle and the harmful affects of blue light. B-ESP filters 70% of blue light, 64% of visible light and 99.99% of UVA/UVB.

B CONTRAST

A revolutionary coated, gradient lens offering better long term eye comfort. B-Contrast is particularly suited to wearers of safety glasses with clear lenses. B-Contrast filters 99.99% of UVA/UVB up to 400 nm and over 30% of blue light.

B HD

A revolutionary coating for exceptional clarity and light transmission. It can be used for every type of job except those requiring solar protection in industrial fields. Unlike any other lens, wearers forget they are protected by the HD coating. Its visible light transmission rate is 96% compared with 90% for conventional clear lenses. Featuring a hydrophobic coating as standard, B-HD is a real polymer barrier and resists water and dirty marks.

PLATINUM

This permanent coating on both sides of the lens gives them a high resistance to scratching, to the most aggressive chemicals and delays the onset of fogging. In all circumstances and at all times the PLATINUM lens innovation guarantees your eyes improved protection.



FRAME MARKING

EN 166: guaranteed minimum resistance of the protective eyewear against everyday risks including dropping the protective eyewear onto the ground, ageing by light exposure, exposure to heat or corrosion etc.

- F.** Low energy impact, resists a 6 mm, 0.86 g ball at 45 m/s
Maximum protection for glasses.
- B.** Medium energy impact, resists a 6 mm, 0.86 g ball at 120 m/s
- T.** The letter T, immediately after the mechanical strength symbol, authorises use for high speed particles at extreme temperatures.

€€ European standard ☞ Manufacturer name

Bollé Safety product approval certificates to CE standards will be sent on request.

CLEANING AND STORAGE

CLEANING: The lenses should be cleaned regularly. Bollé Safety recommends only using the B-clean lens cleaning system.

MAINTENANCE: Pitted, scratched or damaged lenses must be replaced by replacing the complete product. If the frame is damaged also replace the complete product. After each use it is recommended to keep the spectacles or goggles in a microfiber pouch or rigid case.

STORAGE: All products must be stored in a dry and clean environment.

Europe Bollé Safety
95 rue Louis Guérin
69100 Villeurbanne - France
Tél. : 00 33 (0) 4 78 85 23 64
Fax : 00 33 (0) 4 78 85 28 56
contact@bolle-safety.com

bolle-safety.com

U.K. Bollé Safety
Unit C83 - Barwell Business Park Leatherhead Road - Chessington
Surrey - KT9 2NY
Tél. : 00 44 (0)208 391 4700
Fax : 00 44 (0)208 391 4733
e-mail : sales@bolle-safety.co.uk

bolle
SAFETY

COBRA

ESSENTIAL WRAP-AROUND COMFORT

CHARACTERISTICS

LENSES	PC - 2,2 mm - Curve 9
FRAME	Nylon/PC/TPR
STRAP	15mm adjustable
FOAM	COBFSPSI & COBFTPSI
SPARE LENSES	Yes

PACKAGING AND EAN 13 CODE

	COBFSPSI	KITFSCOB	COBFTPSI
Individual plastic bag	3660740005986	3660740006037	3660740006921
10 safety spectacles and 20 foam and strap kit per box	3660740105983	3660740106034	3660740106928
240 safety spectacles and 240 foam and strap kit per outer pack	3660740205980	3660740206031	3660740206925

PACKAGING AND EAN 13 CODE

	OCCOBPSI
Individual plastic bag	3660740006020
25 safety spectacles per box	3660740106027
300 safety spectacles per outer pack	3660740206024

PACKAGING AND EAN 13 CODE

	COBPSI	COBHDI	COBPSJ	COBPSF	COBESP	COBCONT	COBFTPSI
Individual plastic bag	3660740006129	3660740006013	3660740006143	3660740006136	3660740006006	3660740005993	3660740006921
10 safety spectacles per box	3660740106126	3660740106010	3660740106140	3660740106133	3660740106003	3660740105990	3660740106928
200 safety spectacles per outer pack	3660740206123	3660740206017	3660740206147	3660740206130	3660740206000	3660740205997	3660740206925



Europe Bollé Safety
95 rue Louis Guérin
69100 Villeurbanne - France
Tél. : 00 33 (0) 4 78 85 23 64
Fax : 00 33 (0) 4 78 85 28 56
contact@bolle-safety.com

bolle-safety.com

U.K. Bollé Safety
Unit C83 - Barwell Business Park Leatherhead Road - Chessington
Surrey - KT9 2NY
Tél. : 00 44 (0)208 391 4700
Fax : 00 44 (0)208 391 4733
e-mail : sales@bolle-safety.co.uk

bolle
SAFETY

KIT COBRA

KIT VERSION

MODEL	VERSIONS	REFERENCES	LENS MARKING	FRAME MARKING	COATINGS
KIT COBRA	Smoke	KITCOBRA	2C-1.2 ☞ 1 BT ☐	☞ EN166 FT ☐ (Strap)	ASAF
	ESP		5-1.4 ☞ 1 BT ☐	☞ EN166 3BT ☐ (Temples)	Hydrophobic/Anti-reflective/AS
	Clear		5-3.1 ☞ 1 BT ☐		ASAF

SUPPLIED WITH

Case with belt clip and loop



Microfibre pouch ETUIFS



+



+



+ THREE SPARE LENSES: CLEAR, SMOKE, ESP

+ INTERCHANGEABLE FOAM FOR COMFORT

+ ADJUSTABLE STRAP AND STRAIGHT TEMPLES

PACKAGING AND EAN13 CODE

	KITCOBRA
Individual plastic bag	3660740000707
90 safety spectacles per outer pack	3660740200701

CHARACTERISTICS

LENSES	PC - 2,2 mm - Curve 9
FRAME	Nylon/PC/TPR
STRAP	15mm adjustable
FOAM	EVA
SPARE LENSES	ESP and smoke
CASE	Rigid case



17/07/2014

Europe Bollé Safety
95 rue Louis Guérin
69100 Villeurbanne - France
Tél. : 00 33 (0) 4 78 85 23 64
Fax : 00 33 (0) 4 78 85 28 56
contact@bolle-safety.com

bolle-safety.com

U.K. Bollé Safety
Unit C83 - Barwell Business Park Leatherhead Road - Chessington
Surrey - KT9 2NY
Tél. : 00 44 (0)208 391 4700
Fax : 00 44 (0)208 391 4733
e-mail : sales@bolle-safety.co.uk

bolle
SAFETY