




SCMT13200

Crowfoot Wrenches - Metric (10 Piece)

Barcode: 9311927132004

Metric Set

- 10, 11, 12, 13, 14, 15, 16, 17, 18, 19mm
- Suits 3/8" drive extensions: SCMT13915, SCMT13916, SCMT13917, SCMT13918

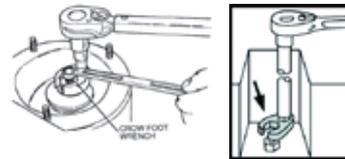


SCMT13400

Crowfoot Wrenches - AF (7 Piece)

Barcode: 9311927134008

AF Set

- 3/8, 7/16, 1/2, 9/16, 5/8, 11/16, 3/4"
- Suits 3/8" drive extensions: SCMT13915, SCMT13916, SCMT13917, SCMT13918

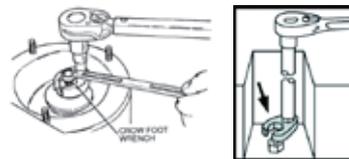

SCMT25105

Adjustable Big Mouth Wrench Premium

Barcode: 9311927251057

- Effectively a 300mm wrench head on a 200mm wrench body
- 39mm rated opening – 58% more than standard 200mm wrench
- 35% lighter than standard 300mm wrench
- Allows access where space is tight, but high torque is not necessary
- Ideal for plumbing applications



Chrome Plated Adjustable Wrench Premium

Part No.	Barcode	Max. Opening	Size
SCMT25110	9311927251101	13mm	100mm
SCMT25111	9311927251118	24mm	150mm
SCMT25112	9311927251125	30mm	200mm
SCMT25113	9311927251132	34mm	250mm
SCMT25114	9311927251149	41mm	300mm
SCMT25115	9311927251156	43.12mm	375mm
SCMT25116	9311927251163	53mm	450mm



Black Finish Adjustable Wrenches Premium

Part No.	Barcode	Max. Opening	Size
SCMT25206	9311927252061	19.2mm	150mm
SCMT25207	9311927252078	24.05mm	200mm
SCMT25208	9311927252085	29mm	250mm
SCMT25209	9311927252092	34mm	300mm
SCMT25210	9311927252108	43.12mm	375mm
SCMT25211	9311927252115	53mm	450mm



Adjustable Wrenches Chrome Plated

- Performance exceeds standard specs
- Optimised contact surfaces for max. user comfort
- Contoured handle
- Ergonomic worm screw
- Improved ergonomics
- 15° angled head
- Tapered jaw tips for optimum access

Part No.	Barcode	Size
SCMT25150	9311927251507	100mm
SCMT25151	9311927251514	150mm
SCMT25152	9311927251521	200mm
SCMT25153	9311927251538	250mm
SCMT25154	9311927251545	300mm
SCMT25155	9311927251552	375mm
SCMT25156	9311927251569	450mm
SCMT25157	9311927251576	600mm



SCMT25180

300mm Black Finish Adjustable Wrench

Barcode: 9311927251804

