

CC1,0-TS-0,34M AU - Crimp contact



1064040
<https://www.phoenixcontact.com/gb/products/1064040>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Crimp contact, contact diameter: 1 mm, turned, Pin, contact material: CuZn, contact surface: Ni/Au, connection cross section: 0.14 mm² ... 0.34 mm², AWG 26 ... 22

Commercial data

Item number	1064040
Packing unit	100 pc
Minimum order quantity	100 pc
Sales key	AF2CJN
Product key	AF2CJN
Catalog page	Page 27 (C-2-2019)
GTIN	4055626719993
Weight per piece (including packing)	0.138 g
Weight per piece (excluding packing)	0.138 g
Customs tariff number	74152900
Country of origin	DE

CC1,0-TS-0,34M AU - Crimp contact

1064040

<https://www.phoenixcontact.com/gb/products/1064040>



Technical data

Mounting

Mounting type	Snap in
---------------	---------

Product properties

Product type	Crimp contact
Type	Individual male contact
Contact material type	turned

Connection data

Connection method	Crimp connection
Contact connection type	Pin
Connection technology	Crimp connection
Conductor cross section	0.14 mm ² ... 0.34 mm ² (flexible)
Connection cross section AWG	26 ... 22 (flexible)
Stripping length of the individual wire	4 mm +0,5 mm
Conductor cross section flexible	0.14 mm ² ... 0.34 mm ²

Material specifications

Contact material	CuZn
Contact surface material	Ni/Au

Dimensions

Mechanical characteristics

Contact diameter	1 mm
------------------	------

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 100
-----------------------------	-------

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 85 °C
---------------------------------	------------------

CC1,0-TS-0,34M AU - Crimp contact


1064040

<https://www.phoenixcontact.com/gb/products/1064040>



Drawings

Dimensional drawing

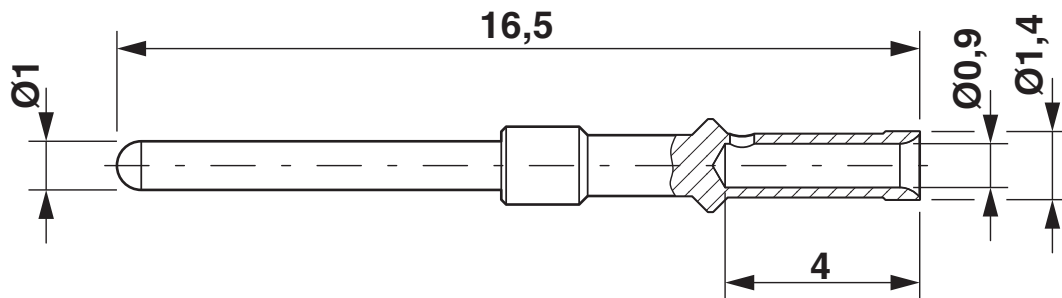

Crimp contact, diameter :1.0 mm

CC1,0-TS-0,34M AU - Crimp contact



1064040

<https://www.phoenixcontact.com/gb/products/1064040>

Classifications

ECLASS

ECLASS-13.0	27440204
-------------	----------

ETIM

ETIM 9.0	EC000796
----------	----------

UNSPSC

UNSPSC 21.0	39121500
-------------	----------

CC1,0-TS-0,34M AU - Crimp contact

1064040

<https://www.phoenixcontact.com/gb/products/1064040>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

EF3.0 Climate Change

CO2e kg	0.09 kg CO2e
---------	--------------

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd
Halesfield 13, Telford
Shropshire, TF7 4PG
01952 681700
info@phoenixcontact.co.uk