
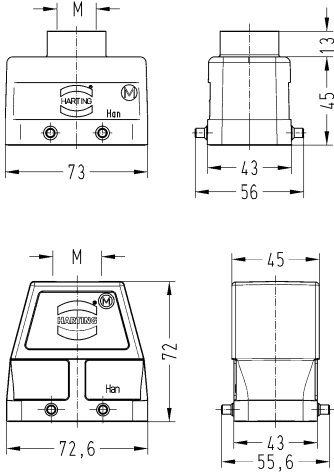

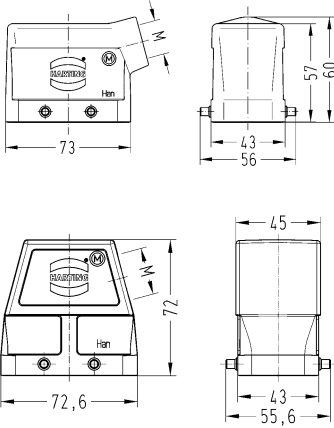

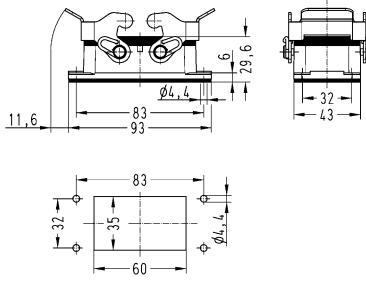


Hoods/Housings for higher EMC requirements  
Double locking lever

Identification	Cable entry	Part number		Drawing (dimensions in mm)
		Low construction	High construction	
Han® EMC/B Han® High Temp , Hoods, Top entry  	1x M20 1x M25 1x M32	19 62 810 1420 19 62 810 1421	19 62 810 0426 19 62 810 0427	
Han® EMC/B Han® High Temp , Hoods, Side entry  	1x M20 1x M25 1x M32	19 62 810 1520	19 62 810 0526 19 62 810 0527	
Han® High Temp , Bulkhead mounted housings  		09 62 810 0391		 <p>Panel cut out</p>

High Temp