


SI

Mobile helpers

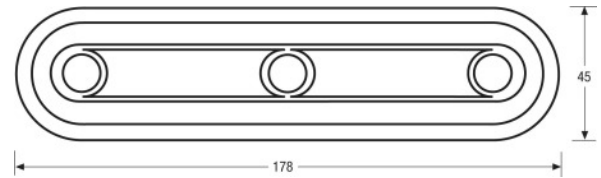

Technical data

Electrical data

Nominal wattage	0.23 W
Nominal voltage	4.5 V

Photometrical data

Light color as per EN 12464-1	White
-------------------------------	-------

Light technical data

Beam angle	135 °
------------	-------

Dimensions & weight

Length	178.0 mm
Width	46.0 mm
Height	29.0 mm

Colors & materials

Product color	Silver
Body material	Plastic
Cover material	Plastic

Temperatures

Ambient temperature range	0...+25 °C
---------------------------	------------

Additional product data

Lamp designation according to LBS	LED
Equipped with lamp	Yes
Equipment	LED
Light source included	Yes

Capabilities

Type of installation	Surface-mounted
Accessories	Adhesive pad / Hook-and-loop pad / Magnet
Adjustable	Yes
Dimmable	No
LED module replaceable	Not replaceable

Product datasheet

Certificates & standards

Standards	CE
Type of protection	IP20
EEL of included LED module	A++

Country specific categorizations

Order number	OTD23003S0
--------------	------------

Country specific information

Product code	METEL code	SEG-No.	STK number	UK Org
4008321930828	OSRDOTITLVPPSBLI	-	8771135	-

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321305640	DOT-it LINEAR VARIO SI	Shipping carton box 6	255 mm x 113 mm x 194 mm	5.59 dm ³	1210.00 g
4008321930835	DOT-it LINEAR VARIO SI	Shipping carton box 6	116 mm x 260 mm x 198 mm	5.97 dm ³	1180.00 g
24902901619278	DOT-it LINEAR VARIO SI	Shipping carton box 6	255 mm x 113 mm x 194 mm	5.59 dm ³	1210.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.