


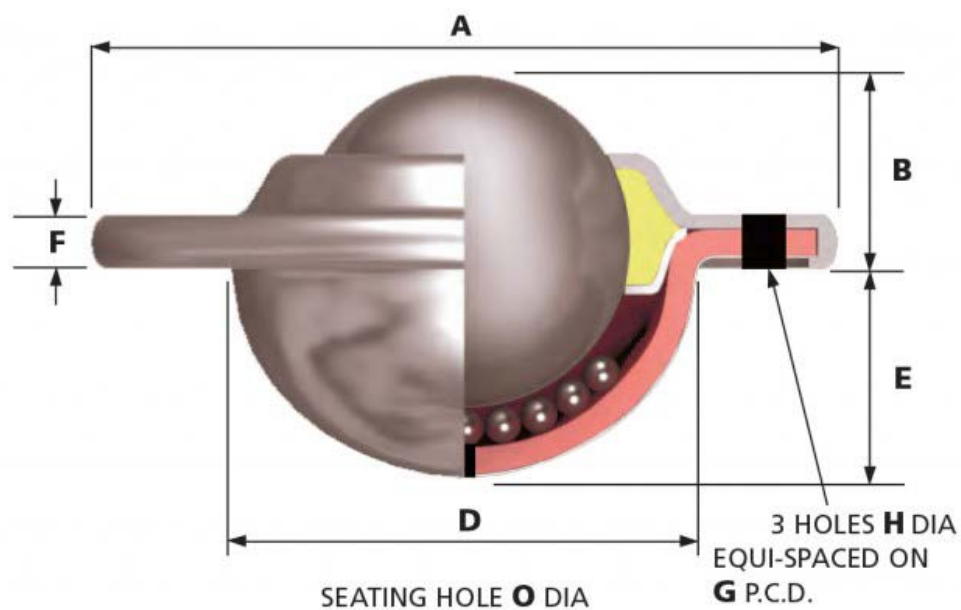

687-584 - ALWAYS 300613

3006-13

Type 13: Carbon
Steel balls & housing

Max Dynamic Loading (Kg) LOAD BALL UP	25
Max Dynamic Loading (Kg) LOAD BALL DOWN	10
Weight (Kg)	0.087
Load Ball Diameter Ø (mm)	19
Fixing Holes	3
Fixing Methods	Flange
Dimension A - Max Diameter (mm)	61
Dimension B - Working Height of Ball (mm)	10
Dimension D - Body Diameter (mm)	29.1 +/- 0.2
Dimension E - Under Flange to Base (mm)	12
Dimension F - Flange Thickness (mm)	3.2
Dimension G - PCD or Centres of Fixing Holes (mm)	44.5 +/- 0.2
Dimension H - Hole Diameter of Fixing Holes (mm)	5.1
Dimension I / O - Seating Hole Diameter (mm)	30
Load Ball Material	Carbon Steel
Support Ball Material	Carbon Steel
Unit Housing Material	Carbon Steel - Bright Zinc Plated