




DT 2143 KTX

CRANKED SOCKET KEY WITH 2C-T-HANDLE for recessed TORX® screws

- ▶ Working angle approx. 25°
- ▶ With hanging hole
- ▶ Chrome-vanadium steel, blades chrome-plated, tip phosphated
- ▶ TORX® = reg. trademark of Acument Intellectual Properties, LLC. USA

 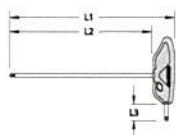


⊕	M	mm	L ₁	L ₂	L ₃	Code	No.
T10	M3 - M3,5	2,74	157	130	12	0.091 2647486	DT 2143 KTX T10
T15	M3,5 - M4	3,27	177	150	14	0.081 2647494	DT 2143 KTX T15
T20	M4 - M5	3,86	197	170	16	0.071 2647508	DT 2143 KTX T20
T25	M4,5 - M5	4,43	228	190	19	0.121 2647516	DT 2143 KTX T25
T27	M4,5 - M6	4,99	248	210	22	0.120 2647524	DT 2143 KTX T27
T30	M6 - M7	5,52	303	265	25	0.140 2647532	DT 2143 KTX T30
T40	M7 - M8	6,65	333	295	28	0.180 2647540	DT 2143 KTX T40

42 T (AF)

HEXAGON ALLEN KEY WITH T-HANDLE for in-hex screws

- ▶ Blue handle with hanging hole
- ▶ GEDORE vanadium steel 61CrSIV5, chromated

 


AF	L ₁	L ₂	Code	No.
1/8	229	190	0.040 1996010	42 T 1/8AF
5/32	249	210	0.068 1996029	42 T 5/32AF
3/16	279	240	0.088 1996037	42 T 3/16AF
1/4	309	270	0.120 1996045	42 T 1/4AF
5/16	349	310	0.190 1996053	42 T 5/16AF
3/8	369	330	0.230 1996061	42 T 3/8AF

42 T (MM)

HEXAGON ALLEN KEY WITH T-HANDLE for in-hex screws

- ▶ Blue handle with hanging hole
- ▶ GEDORE vanadium steel 61CrSIV5, chromated

 


mm	L ₁	L ₂	Code	No.
2	162.5	130	0.029 1531360	42 T 2
2,5	192.5	160	0.036 6354130	42 T 2,5
3	222.5	190	0.040 6353670	42 T 3
4	249.0	210	0.073 6353750	42 T 4
5	279.0	240	0.093 6353830	42 T 5
6	309.0	270	0.124 6353910	42 T 6
7	329.0	290	0.157 6366730	42 T 7
8	349.0	310	0.198 6354050	42 T 8
10	369.0	330	0.295 6354210	42 T 10

DT 42

HEXAGON ALLEN KEY WITH T-HANDLE for in-hex screws

- ▶ Blue handle with hanging hole
- ▶ With 2 hexagons, same size each end



mm	L ₁	L ₂	L ₃	Code	No.
2	107.0	87	12.0	0.012 1476408	DT 42 2
2,5	127.0	107	12.0	0.015 1476424	DT 42 2,5
3	147.0	127	12.0	0.019 1476432	DT 42 3
4	173.5	141	15.5	0.049 1476440	DT 42 4
5	193.5	161	17.5	0.068 1476459	DT 42 5
6	213.5	181	20.5	0.091 1476467	DT 42 6
7	231.0	192	28.0	0.142 1476475	DT 42 7
8	246.0	207	28.0	0.175 1476483	DT 42 8
10	261.0	222	28.0	0.257 1476491	DT 42 10

V 42 T

538



1500 CT2-DT 42

109

