


# push-in T-connector NPQP-T-Q4-E-FD-P10

Part number: 133110

FESTO

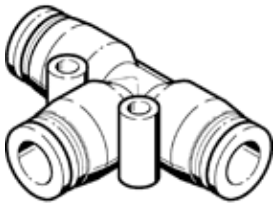

## Data sheet

Feature	Value
Size	Standard
Nominal size	2.6 mm
Container size	10
Design structure	Push/pull principle
Temperature dependent operating pressure	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	4 - Very high corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	-20 ... 60 °C
Product weight	6.5 g
Pneumatic connection, port 1	for tubing, 4mm outside diameter
Pneumatic connection, port 2	For tubing outside diameter 4 mm
Materials note	Contains PWIS substances Conforms to RoHS
Material housing	PP
Material of tube retaining claw	High alloy steel, non-corrosive