


Features

- IEC-584-3
- Fast response, welded exposed junction
- Miniature Plug termination

RS PRO PFA Insulated Flat Pair IEC Exposed Junction Thermocouple with Miniature Plug - Type K

RS Stock No.: 0652776

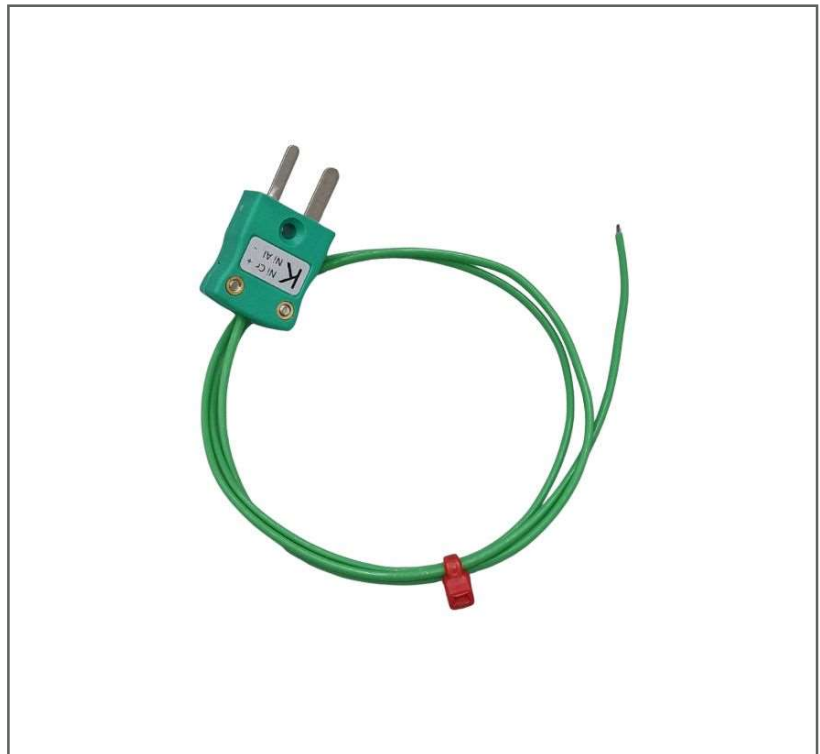

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

Exposed junction thermocouples are often used in applications where fast response times are crucial, such as in research laboratories, semiconductor manufacturing, and certain industrial processes.

General Specifications

Thermocouple Type	Type K
Temperature Measurement Range	-75°C to +260°C
Construction	Terminated with a miniature flat pin plug
Measuring Junction	Exposed
Standards Met	IEC
Application	Fast response, welded exposed junction

Mechanical Specifications

Termination	Miniature Plug
Length	0.3m (0.98ft)
Cable Insulation	1/0.3mm PFA Flat pair

Approvals

Declarations	RoHS
--------------	------

Similar Products

Colour Code	Type	Style	Cable Size	Length	Termination	RS Stock#
IEC	K	PFA	1/0.3mm	0.3m (0.98ft)	Miniature Plug	0652776
IEC	K	PFA	1/0.3mm	1m (3.3ft)	Miniature Plug	1365885
IEC	K	PFA	1/0.3mm	2m (6.56ft)	Miniature Plug	1365886
IEC	K	PFA	1/0.3mm	3m (9.84ft)	Miniature Plug	1365887
IEC	K	PFA	1/0.3mm	3m (9.84ft)	Miniature Plug	2623203 (x5)
IEC	K	PFA	1/0.3mm	5m (16.4 ft)	Miniature Plug	1365888
IEC	K	PFA	1/0.3mm	5m (16.4 ft)	Miniature Plug	2623204 (x5)
IEC	K	PFA	1/0.5mm	0.3m (0.98ft)	Miniature Plug	0652777
IEC	K	PFA	1/0.5mm	1m (3.3ft)	Miniature Plug	1365889
IEC	K	PFA	1/0.5mm	2m (6.56ft)	Miniature Plug	1365890
IEC	K	PFA	1/0.5mm	3m (9.84ft)	Miniature Plug	1365891
IEC	K	PFA	1/0.5mm	5m (16.4 ft)	Miniature Plug	1365892
IEC	K	PFA	1/0.5mm	10m (32.8ft)	Miniature Plug	1365893