


Geberit Mapress Stainless Steel elbow adaptor 90° with female thread



Example image

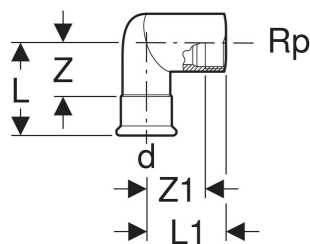

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water $\leq 120\text{ }^{\circ}\text{C}$
- For saturated steam $\leq 120\text{ }^{\circ}\text{C}$
- For service water and process water
- For treated water
- For rainwater with a pH value ≥ 5.5
- For grey and black water with a pH value ≥ 5.5
- For extinguishing water (wet)

- For extinguishing water (wet/dry, dry)
- For sprinklers (wet)
- For chemicals and technical liquids
- For compressed air (oil purity class 0–3)
- For negative pressure
- For inert gases (e.g. nitrogen)
- For industrial gases (e.g. acetylene, shielding gases)
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator

- Leaky if unpressed
- Seal ring made of CIIR, black
- Pressing socket with transparent protection plug

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

ACCESSORIES

- Fastening for Geberit Mapress elbow adaptor 90°

Art. no.	DN	d, ø mm	Rp "	arc °	L cm	L1 cm	Z cm	Z1 cm
33802	12 / 10	15	3/8	90	5.7	3.4	3.7	2.4
33803	12 / 15	15	1/2	90	5.7	3.7	3.7	2.4
33804	15	18	1/2	90	5.7	3.9	3.7	2.6

Art. no.	DN	d _e mm	R _p "	arc °	L cm	L1 cm	Z cm	Z1 cm
33808	20 / 15	22	1/2	90	5.8	3.9	3.7	2.4
33810	20 / 15	22	1/2	90	5.8	4.9	3.7	3
33805	20	22	3/4	90	6	4.6	3.9	3.1
33806	25	28	1	90	6.7	5.4	4.3	3.7
33807	32	35	1 1/4	90	7.5	6.3	4.9	4.4