


MFM SERIES - MICRONIC FILTER

MFM basic filtration - Filtration threshold : 1 µm



Part number	Female thread	Flow rate at 7 bar (m ³ /h) (ΔP= 0,08 bar)	Temperature min/max (°C)	Max. operating pressure (bar)	Filtration (µm)
MFM 55	G1/2	55	3 / 80	20	1
MFM 70	G1/2	70	3 / 80	20	1
MFM 100	G1/2	100	3 / 80	20	1
MFM 150	G3/4	55	3 / 80	20	1
MFM 225	G 1	225	3 / 80	20	1
MFM 300	G 1 1/2	300	3 / 80	20	1
MFM 400	G 1 1/2	400	3 / 80	20	1
MFM 500	G 2	500	3 / 80	20	1
MFM 800	G 2	800	3 / 80	20	1

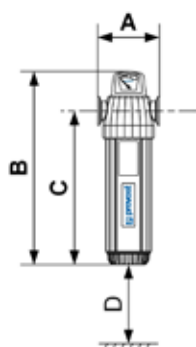

Part number	Dim. A (mm)	Dim. B (mm)	Dim. C (mm)	Dim. D (mm)	Dim. E (mm)
MFM 55	90,00 mm	37,00 mm	252,00 mm	230,00 mm	19,00 mm
MFM 70	128,00 mm	45,00 mm	273,00 mm	250,00 mm	32,00 mm
MFM 100	128,00 mm	45,00 mm	303,00 mm	279,00 mm	32,00 mm
MFM 150	140,00 mm	45,00 mm	370,00 mm	335,00 mm	31,00 mm
MFM 225	140,00 mm	45,00 mm	398,00 mm	365,00 mm	31,00 mm
MFM 300	140,00 mm	45,00 mm	474,00 mm	432,00 mm	31,00 mm
MFM 400	140,00 mm	45,00 mm	564,00 mm	522,00 mm	31,00 mm
MFM 500	151,00 mm	45,00 mm	511,00 mm	465,00 mm	25,00 mm
MFM 800	151,00 mm	45,00 mm	696,00 mm	650,00 mm	25,00 mm