




Low profile transformer FL 30/18

Type		FL 30/18
Electrical data	Input	
	Rated input Voltage	2 x 115 Vac
	Rated frequency	50 - 60 Hz
	Output	
	Rated output voltage	2 x 18 Vac
	Rated Power	30.0 VA
	No-load voltage (app. x factor)	1.17
	No-load loss (typ.)	1.70 W
	Efficiency	81 %
	Standards	
Classification	Safety isolating transformer	
Approvals		
Approvals	cURus, ENEC 10 (VDE)	
Environment		
Ambient temperature max.	40 °C	
Safety and protection		
Type	encapsulated	
Class of Insulation System	VDE=E, UL=class 105	
Protection index	IP 00	
Safety class (prepared)	II	
Short circuit strength	non-short-circuit proof	
Order numbers		
Order Number	FL 30/18	

Type		FL 30/18
Terminal and mounting		
Terminals		Pins for printed circuit boards
Measures and weights		
Core type		UI 39/21
Weight		0.53 kg

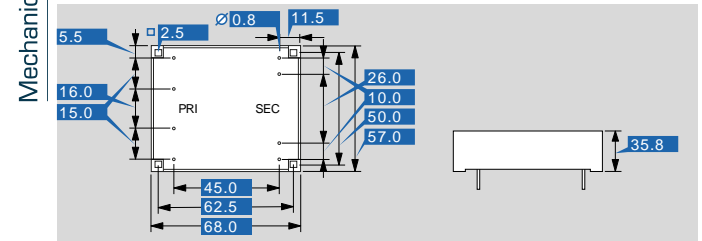

Subjects to change.