

### Cleaning

### Professional vacuums

Last update : 15/01/07

**SIDAMO**



Guaranteed  
2 years


## > POLYPROPYLENE TANK VACUUMS DC 25 / DC 25 S

#### Characteristics :

- **DC 25 S** : Equipped with a socket for synchronous starting by a hand held power tool  
Accessory holder and electric cord  
Adapter for hand held power tools
- Made in Europe
- Water and dust vacuums
- "PUSH & CLEAN" cleaning system: filter unclogged by a powerful air flow by simply pressing a button
- Class L cartridge filter
- Support for accessories
- Support for power cord
- Shock-resistant undeformable polypropylene tank
- Easy to move (lightweight and small size)

- Double electric isolation
- H05 VV-F 2G0.75 vinyl power cord
- Standard accessories:
  - 2 plastic tubes, length 500 mm (aluminium on DC 25 S)
  - 1 dust nozzle (DC 25)
  - 1 mixed nozzle (DC 25 S)
  - 1 flat nozzle
  - 1 upholstery nozzle
  - 1 round brush
  - 1 class L cartridge filter
  - 1 cloth bag
  - 1 water filter
  - 1 flexible hose Ø 32 mm, length 1,9 m on DC 25 / 2,5 mon DC 25 S
  - 1 adapter for hand-held power tool (DC 25 S)

	Tank	Capacity (L)	Power (W)		Vacuum			Flow-rate		Decibels at 1 m (dBA)	Ø accessories (mm)	Dimensions a x b x c (mm)	(kg)	
					(Kpa)	(mm H2O)	(mbar)	(m³/h)	(l/min)					
DC 25	Polypropylen	25	1400	230 v mono	19	1938	190	216	3600	67	32	380 x 545 x 375	5,7	20405004
DC 25 S	Polypropylen	25	1400	230 v mono	19	1938	190	216	3600	67	32	380 x 545 x 375	5,7	20405005

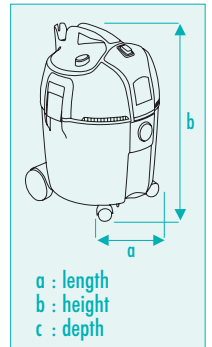

"Push & Clean" system




#### Recommendations for use :

These vacuums are not suited for vacuuming hazardous dust (flour, asbestos, lead, inflammable materials...)

#### Accessories and consumables :

##### Filters :

		For vacuum	Class	
Cartridge	1	DC 25 / DC 25 S	L	20498436
PET cartridge	2	DC 25 / DC 25 S	M	20498400

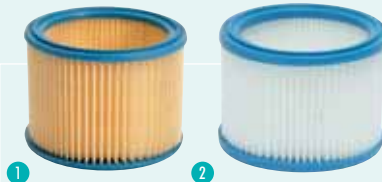


##### Tubes :

		For vacuum	
Ø 32, 2 x 500 mm long, plastic	1	DC 25	20498439
Ø 32, 2 x 500 mm long, aluminium	2	DC 25 S	20498440
Telescopic Ø 32, 550 to 970 mm long	3	DC 25 / DC 25 S	20498441

##### Complete flexible hose :

		For vacuum	
Ø 32, 2500 mm long	1	DC 25 / DC 25 S	20498438

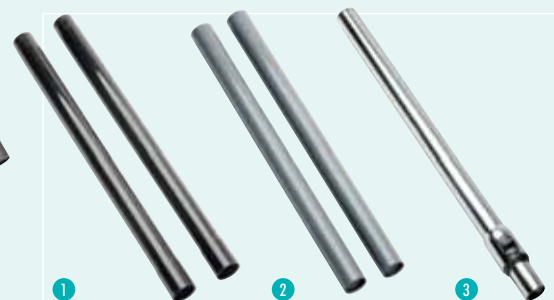



DC 25




DC 25 S

**Accessories and consumables :**

• Nozzles and brushes :

		For vacuum	
Dust nozzle	1	DC 25	20498442
Mixed nozzle	2	DC 25 S	20498443
Water nozzle	3	DC 25 / DC 25 S	20498444
Flat nozzle	4	DC 25 / DC 25 S	20498445
Upholstery nozzle	5	DC 25 / DC 25 S	20498446
Round brush	6	DC 25 / DC 25 S	20498447
Radiator nozzle	7	DC 25 / DC 25 S	20498027

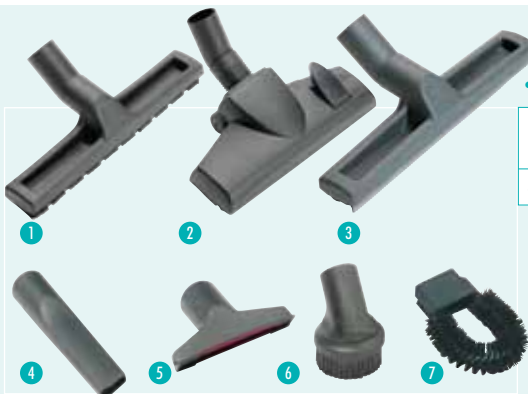

• Cloth bags :

		For vacuum	
4 bags + 1 water filter	1	DC 25 / DC 25 S	20498437



• Accessory holder :

		For vacuum	
For Ø 32 accessories	1	DC 25 / DC 25 S	20498448



• Tool adaptor :

		For vacuum	
For hand held power tools	1	DC 25 S	20498449

