


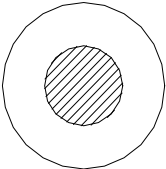

Datasheet

Product Name:	UL1213 28AWG
Product Discription:	UL1213 28AWG
Specification No.:	
Customer's Name:	

Description		Construction			
Rated Voltage:	Not specified	Conductor	Stranded Sliver plated copper		
Rated Temperature:	105°C, 60 °C Oil	Size(AWG)	28		
Reference Standard:	UL758	Construction(±0.008mm)	7/0.127		
Cross Section 		Stranded Dia.(mm)Ref.	0.38		
		Insulation Material	PTFE		
		Insulation Color	ANY COLOR		
		Ave Thickness(mm)	0.2		
		Insulation Dia.(±0.08mm)	0.89		

Marking	
No marking on the cable jacket, have UL label on the Reel.	

Remark:			
8739624 Red	8739633 Blue	8739646 Grey	8739655 Violet
8739627 Black	8739636 White	8739649 Yellow	
8739620 Brown	8739630 Green	8739642 Orange	

Applications		Characteristics		Customer Approve
Internal wiring where not subjected to mechanical abuse, Oil Resistant 60 deg C.		Test Item	Standard Value	Seal & Stamp
		Test Material	PTFE(ROHS)	
		Insulation resistance(20°C MΩ*m)	1000	
		Vol. Tesr(AC.V.60S) (V)	2000	
		Flammability Test	Horizontal flame	
		Max.DC Resistance(20°C Ω/km)	203(MAX)	

Revisions				
Version	Description	Drawn by	Approved by	Date
0	New document issue	Danniel	Jason	24/04/2015

Signature:
Date: