
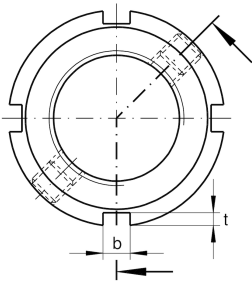


ZMA35/58

Precision locknut

Precision locknuts ZMA, locking pegs, radially arranged, heavy series

Technical information

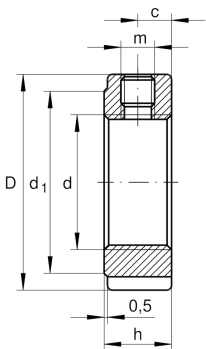

Main Dimensions & Performance Data

d	M35X1,5	Thread
D	58 mm	Outside diameter
h	22 mm	Height
M _A	5 Nm	Mounting torque set screw
F _{aB}	300,000 N	Breaking load, axial
M _L	80 Nm	Breakawag
M _{AL}	40 Nm	Mounting torque reference
M _M	1.66 kg*cm ²	Mass moment of inertia

≈m 0.277 kg Weight

Dimensions

d ₁	52 mm	Plant diameter outside
t	2.5 mm	Hight retaining slot
b	6 mm	Width retaining slot
c	11 mm	Distance bore
m	M6	Threaded - threaded pin