


Features

- High precision tweezers with straight, thick, squared, strong, oblique line serrated tips.
- Suitable to applications which require holding a component very firmly.
- The line serration provides the tips and the handles with extra grip, also preventing any possible slips.
- Anti-magnetic Anti-Acid Stainless Steel (SA).
- Laser marking.
- MADE IN ITALY.

RS PRO High precision tweezers. MADE IN ITALY.

RS Stock No.: 0845440

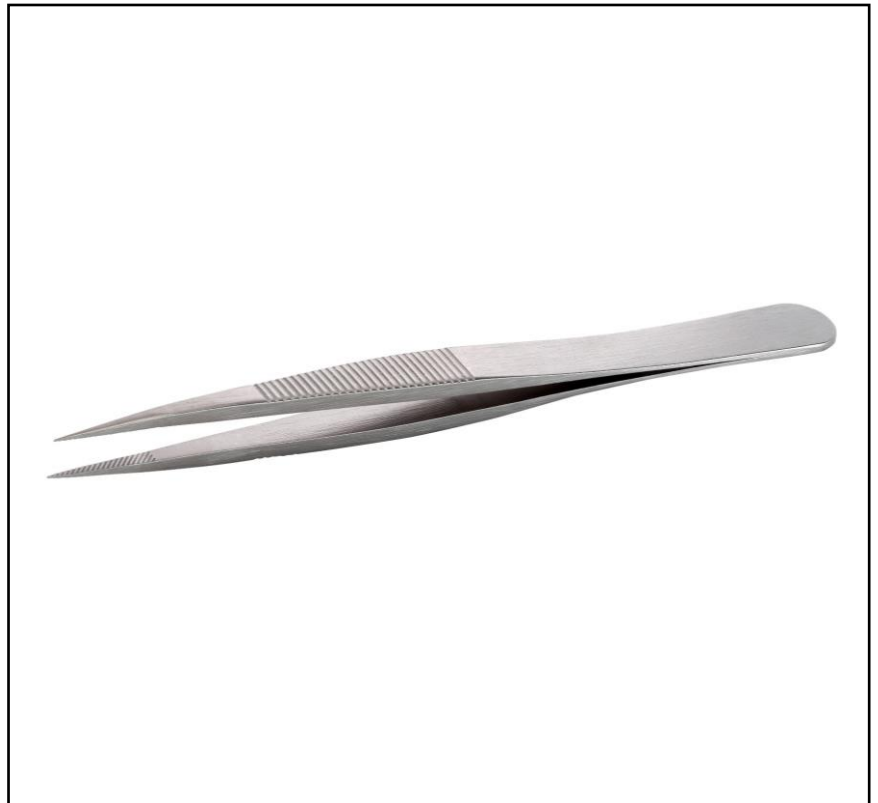

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description


High Precision tweezers are the ideal instruments to hold a component firmly and to handle, grab or hold small objects when precision and accuracy is needed. Typical applications include different tasks in microelectronics, jewellery making, laboratory, watch making and repairs, DIY and medical fields in mild aggressive chemical environments.

General Specifications


Point Type	Straight, thick, squared, strong, oblique line serrated
Overall length (mm)	120
Overall length (")	4.724"
Tweezers width (mm)	10.0 (0.394")
Tweezers height (mm)	12.0 (0.472")
Tip width (mm)	0.50 (0.020")
Tip thickness (mm)	0.50 (0.020")
Net weight	17.7 g
Version	SA
Type of material	Low carbon austenitic Steel
Anti-magnetic	Yes
Anti-acid	Yes



TIP DETAILS:

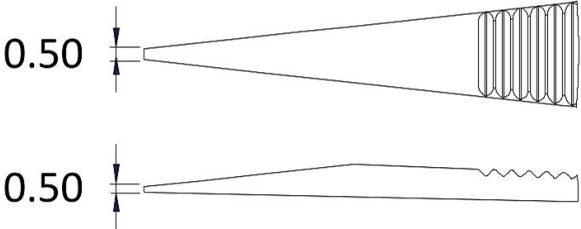

Dimensions mm

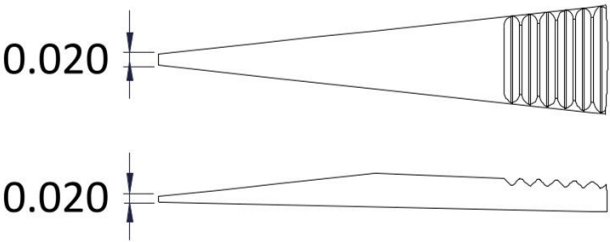

Dimensions inch