



002 PCB TERMINAL BLOCKS

081 TERMINAL STRIPS

095 WIRE TO BOARD CONNECTORS

100 CIRCULAR CONNECTORS


151 IP68 CONNECTORS

158 INTERFACE MODULES AND RELAY BASES


Diode module and component modules

Product overview

- Protects against return voltage to circuits
- Low profile
- 45° cable entry for easy access
- Available also as a component carrier
- Custom interfaces available to order

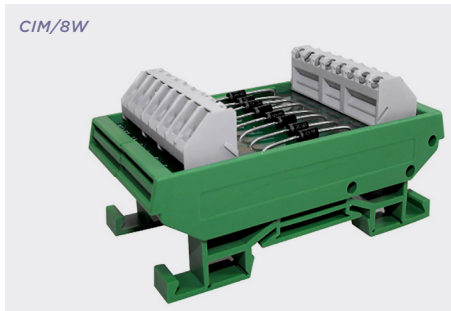

SPECIFICATION	
Voltage	250V DC max
Current	1A max
Characteristics of IN4007	1000V Peak 250V 1Amp
Width	82mm
Length	45mm

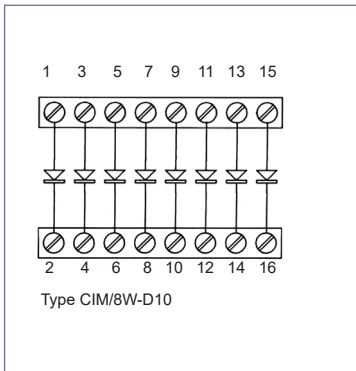

PART NO.	DESCRIPTION
CIM/8W-D10	Diode module
CIM/8W-COMP	Without diodes component carrier