

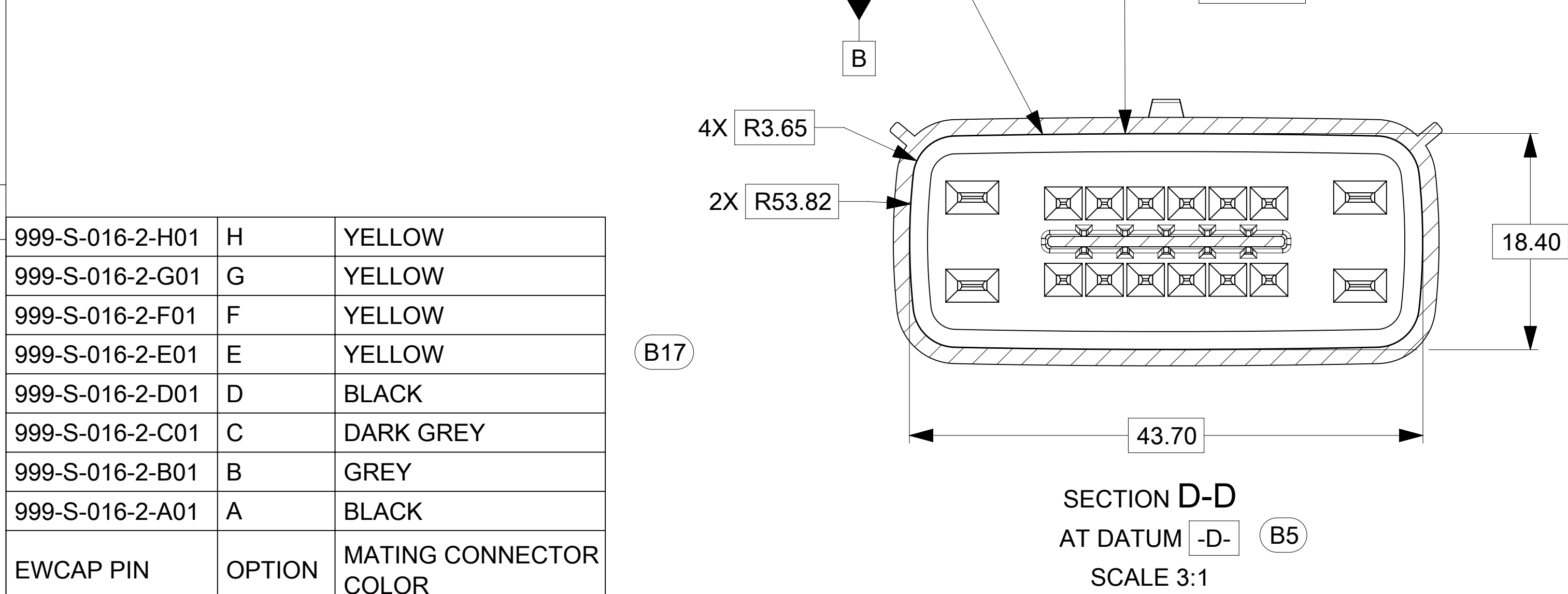
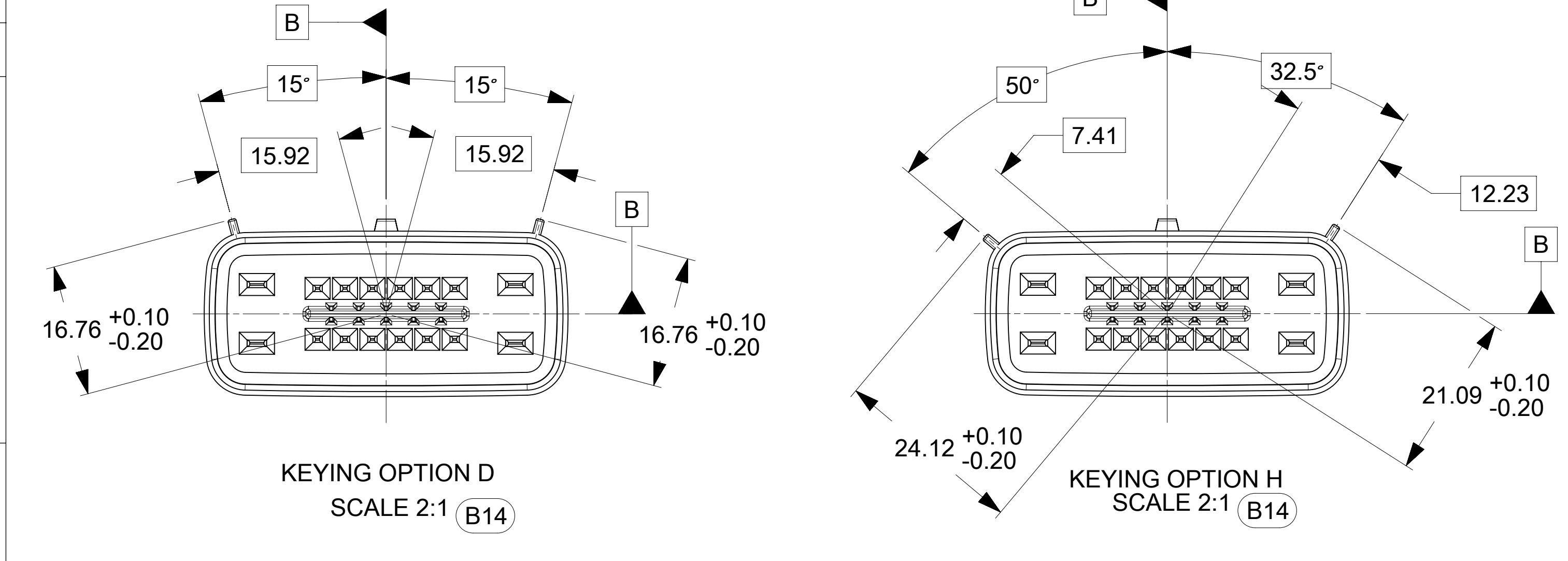
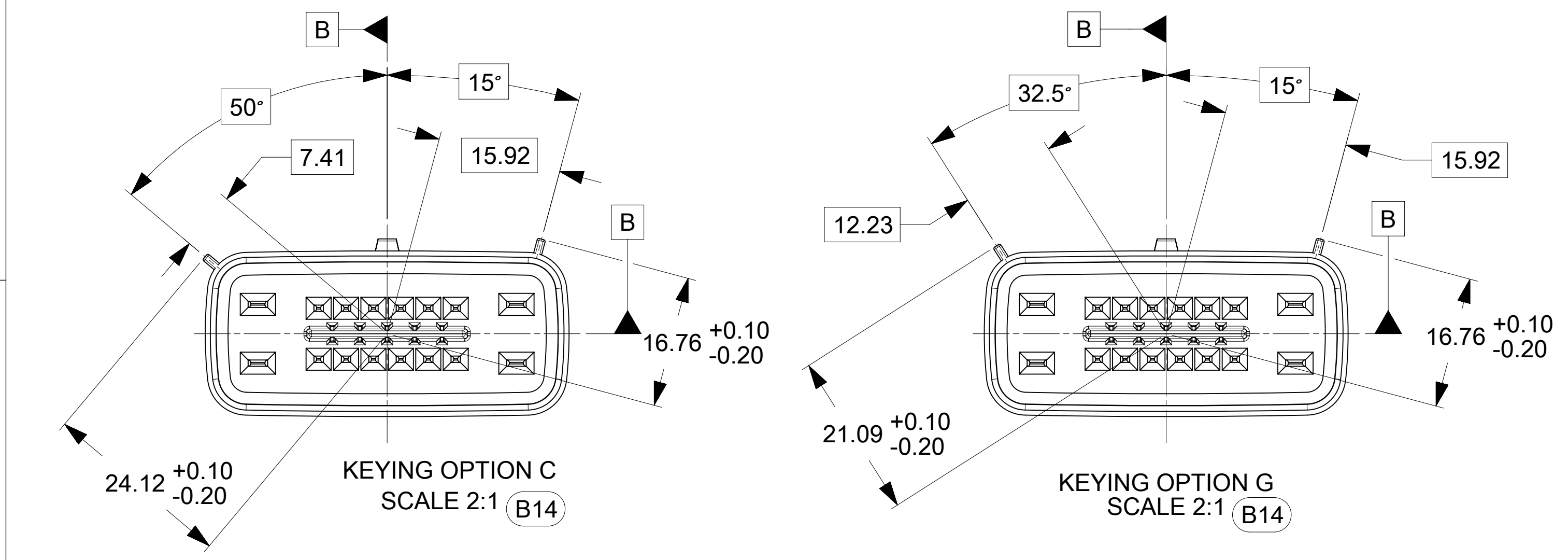
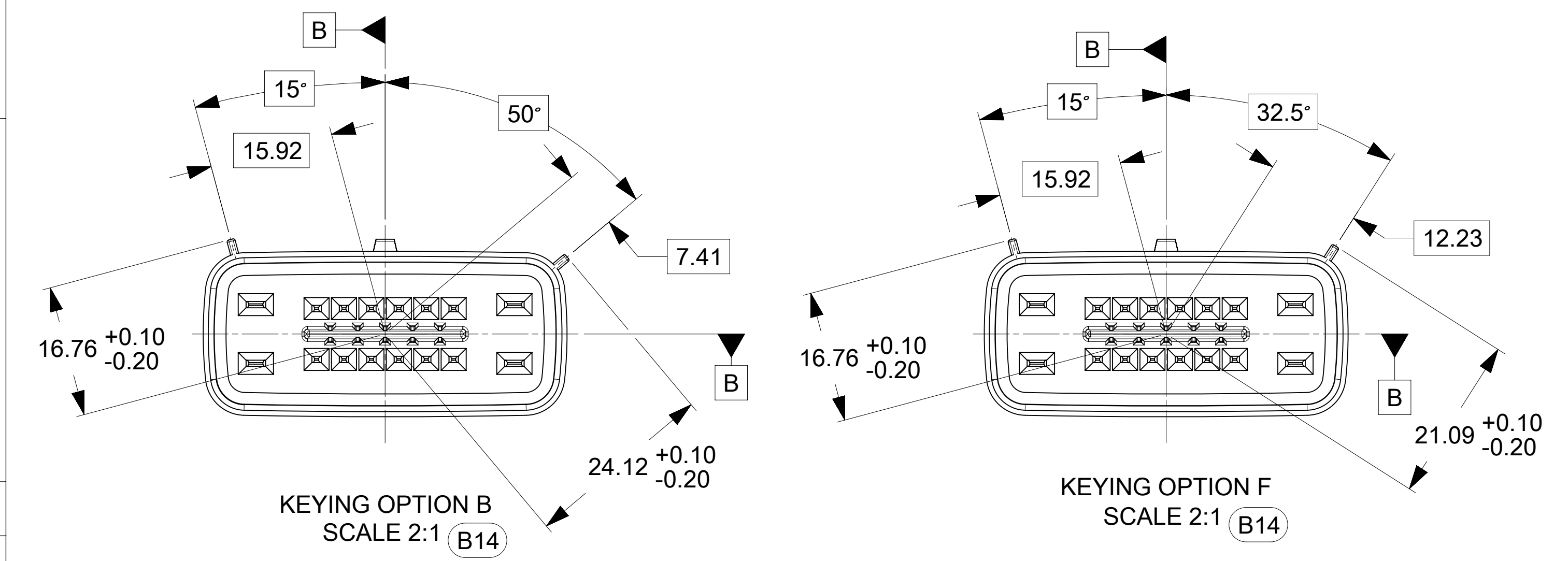
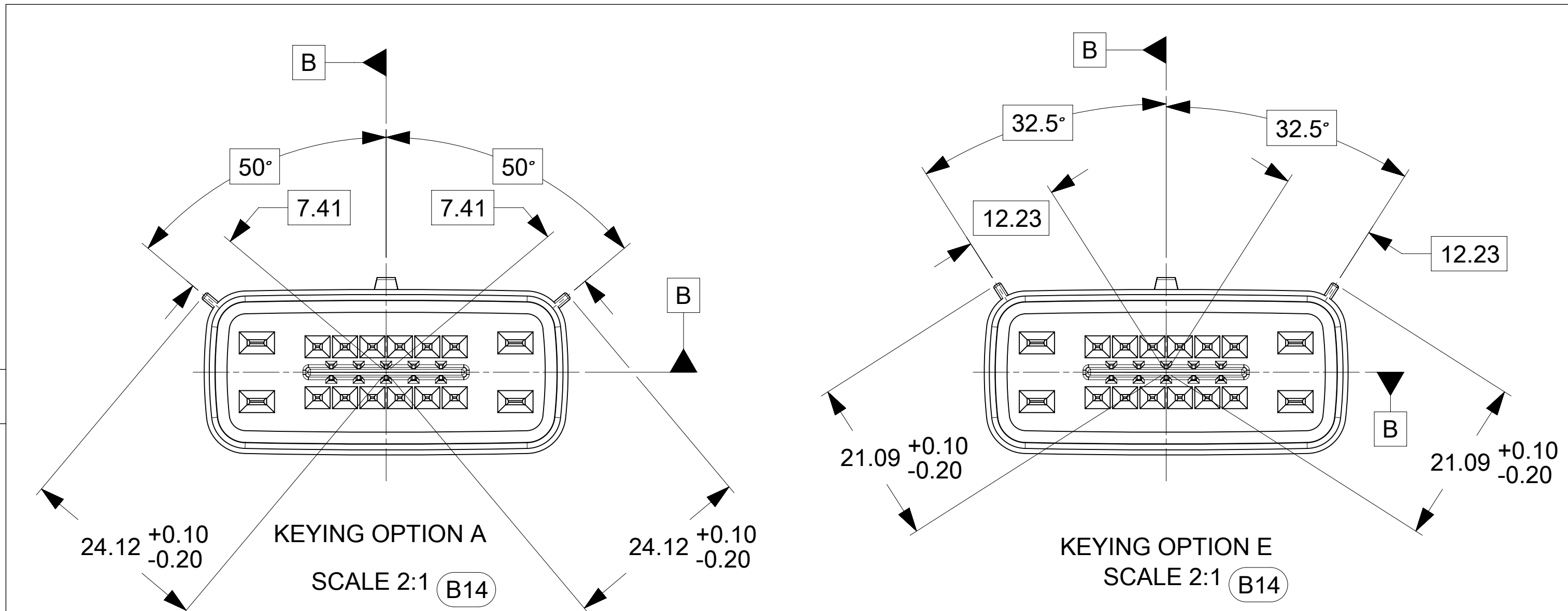
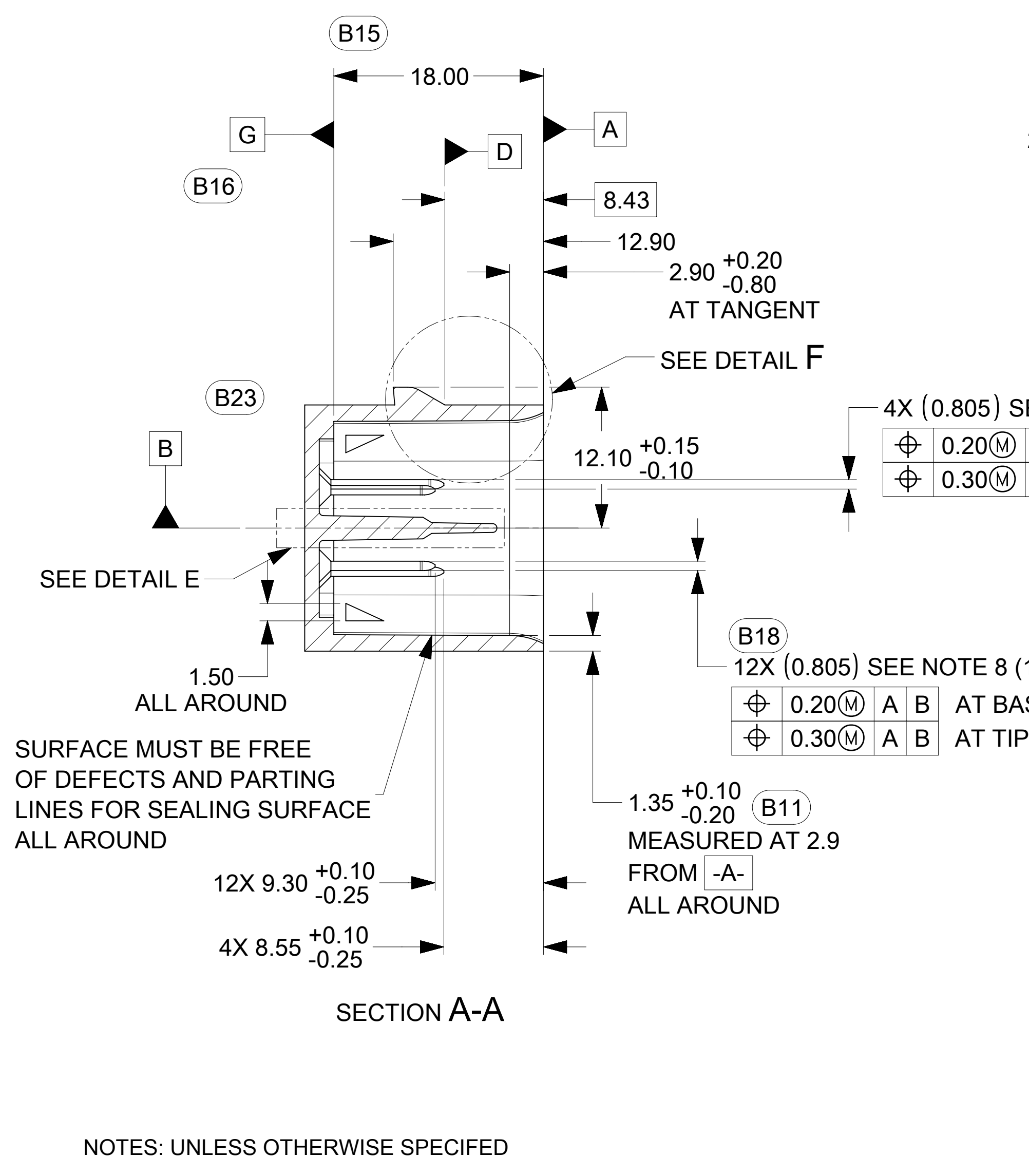





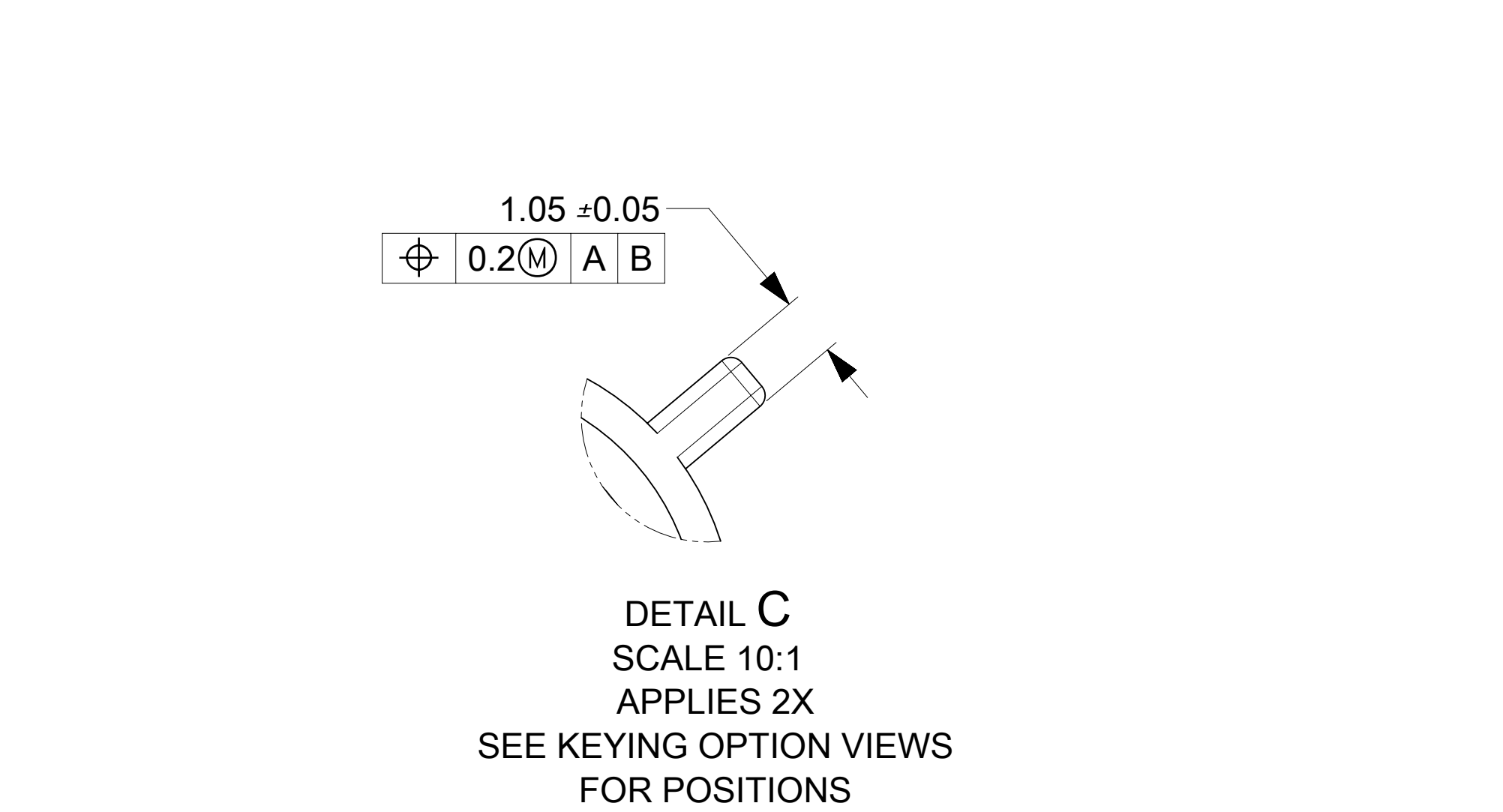


EWCAP PIN	OPTION	MATING CONNECTOR COLOR
999-S-016-2-H01	H	YELLOW
999-S-016-2-G01	G	YELLOW
999-S-016-2-F01	F	YELLOW
999-S-016-2-E01	E	YELLOW
999-S-016-2-D01	D	BLACK
999-S-016-2-C01	C	DARK GREY
999-S-016-2-B01	B	GREY
999-S-016-2-A01	A	BLACK

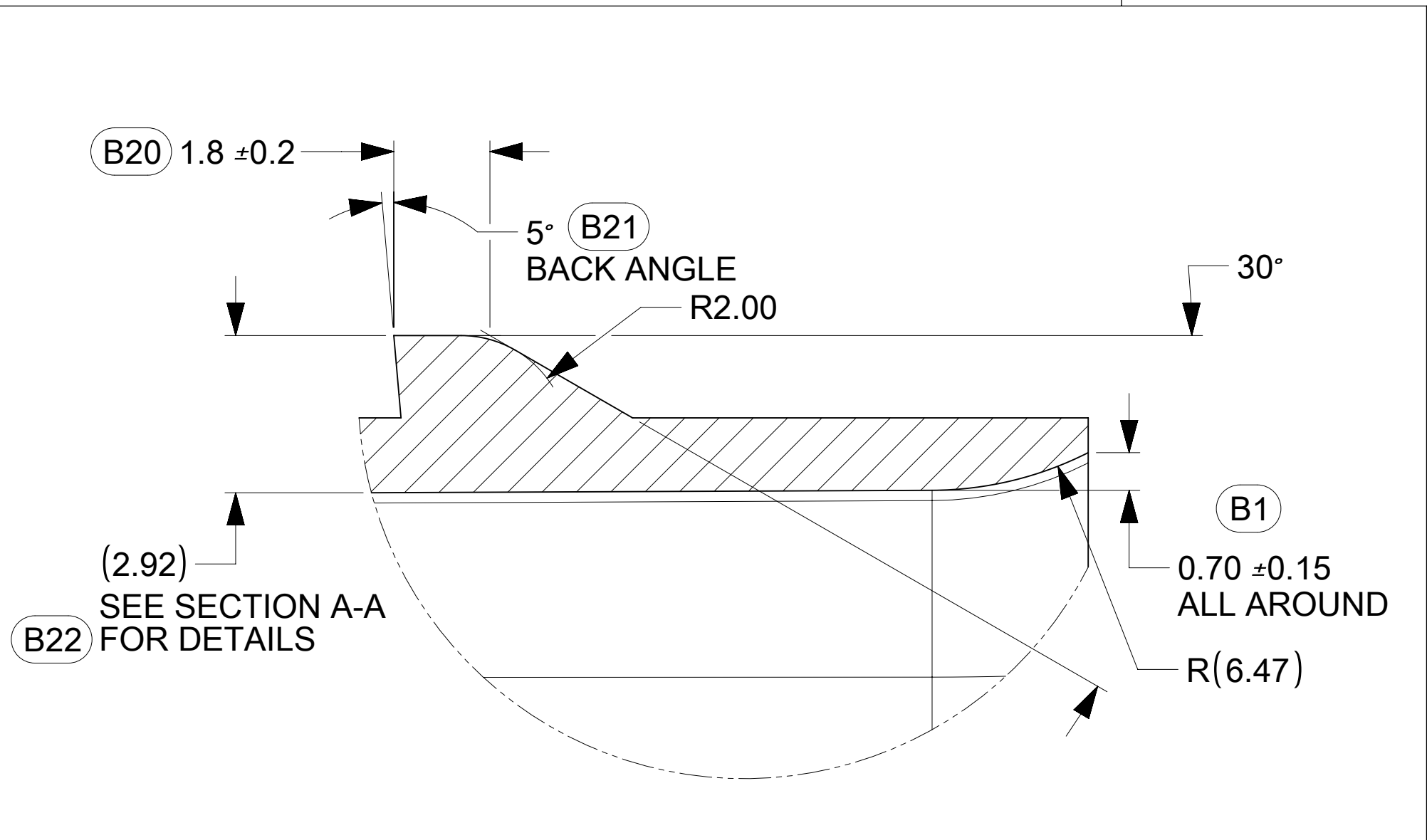

NOTES: UNLESS OTHERWISE SPECIFIED

- DRAFT ANGLE PERMISSIBLE 0.25° MAXIMUM.
- ALL DIMENSIONS SHOWN IN MILLIMETERS.
- DIMENSIONING AND TOLERANCING PER ASME Y14.5M-1994
- RADII ON ALL CORNERS SHOWN SHARP OR ALL UNSPECIFIED RADII: 0.25 EXCEPT AS NOTED.
- STANDARD COLORS FOR POLARIZATION (SEE CHART). DEVIATION REQUIRES APPROVAL OF AUTHORIZED PERSON.
- A FULL SHROUD ON THE MATING CONNECTOR IS REQUIRED TO INSURE THAT THE CONNECTOR-HEADER POLARIZATION FEATURES (OPTIONS A THRU H) WILL FUNCTION. THE SHROUD ALSO PREVENTS SCOOP DAMAGE TO THE HEADER PINS. REFER TO "SAE/USCAR-12 CONNECTOR DESIGN GUIDE LINES" FOR ADDITIONAL INFORMATION.
- REFER TO USCAR/EWCAP PART LIST AS FOUND ON WEBSITE <http://www.uscarteams.org>
- FOR BLADE TERMINAL DESIGN INFORMATION SEE EWCAP DWG. # EWCAP-001
- THIS IS A 100% CAD GENERATED PART. THE CAD MATHEMATICAL DATA IS THE MASTER FOR THIS PART. FOR DIMENSIONAL OR ANY INFORMATION NOT SHOWN ON THIS DRAWING, ANALYZE THE CAD MODEL.

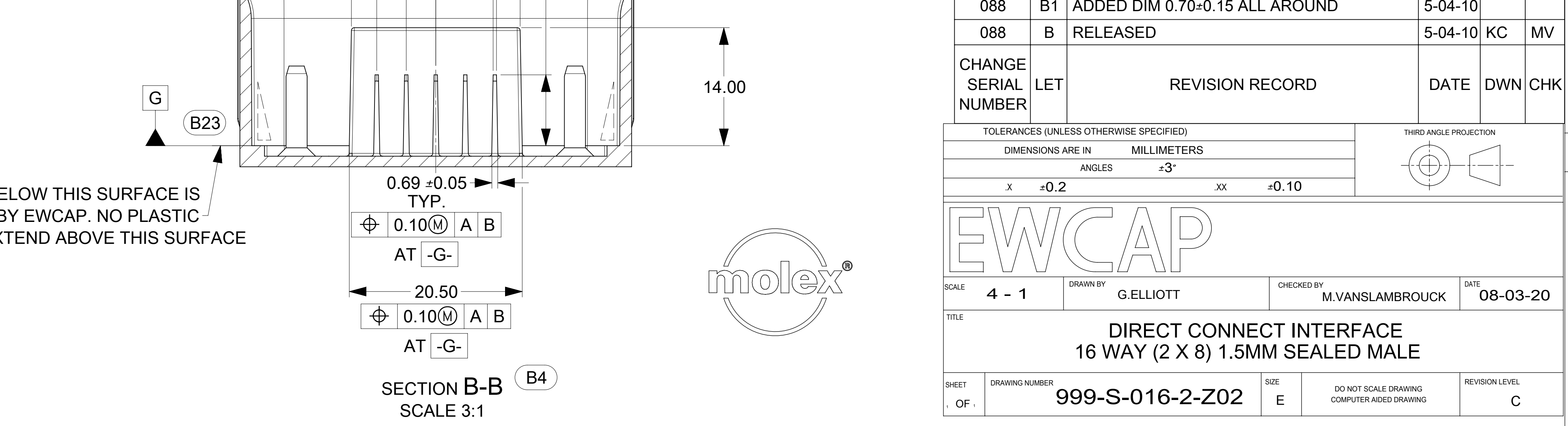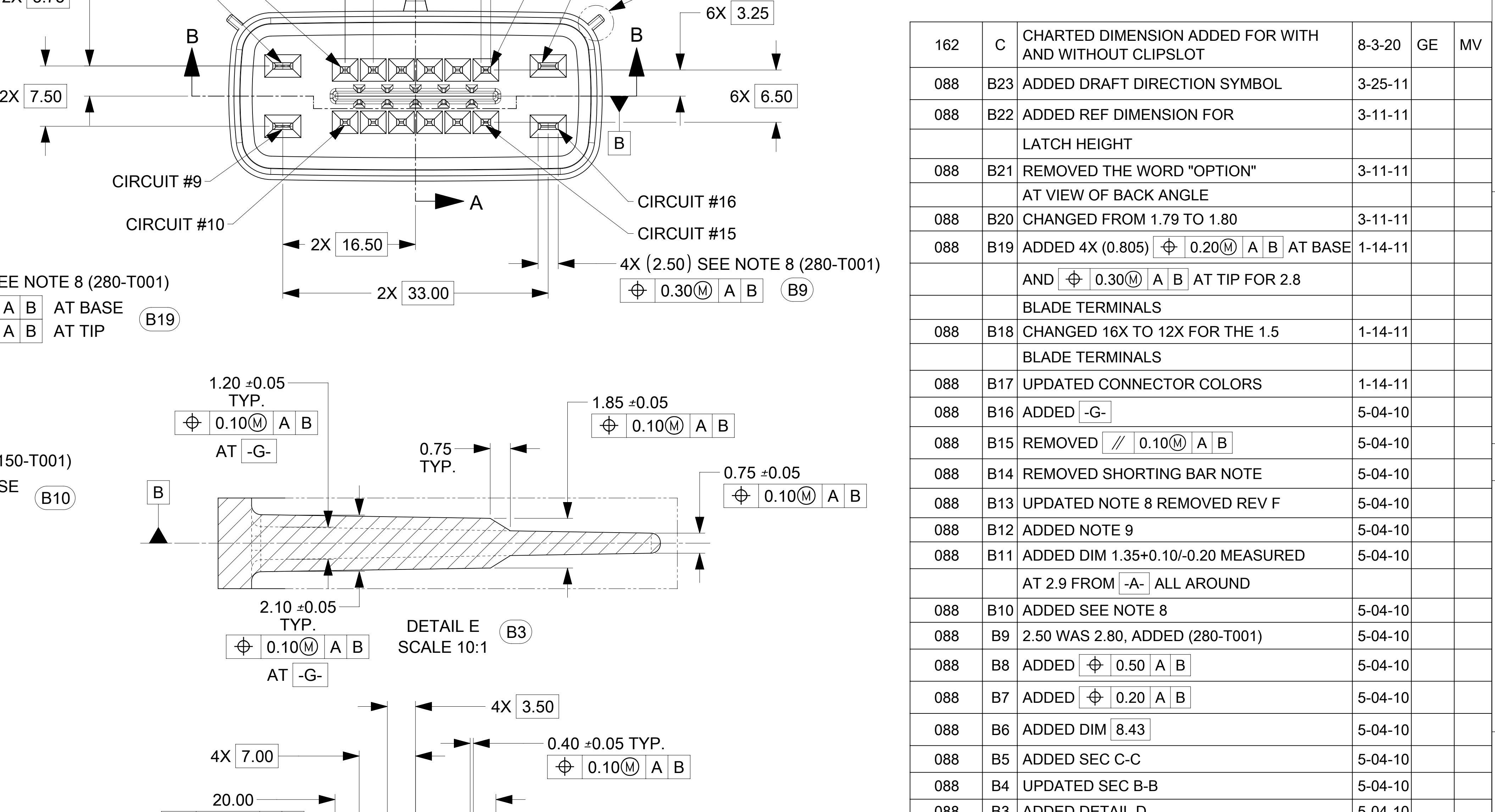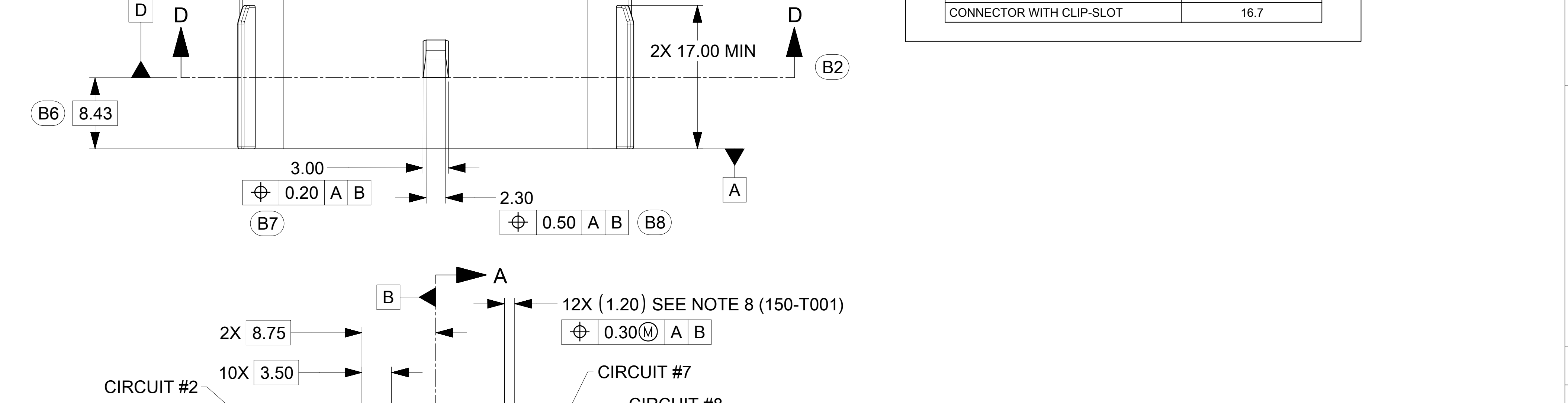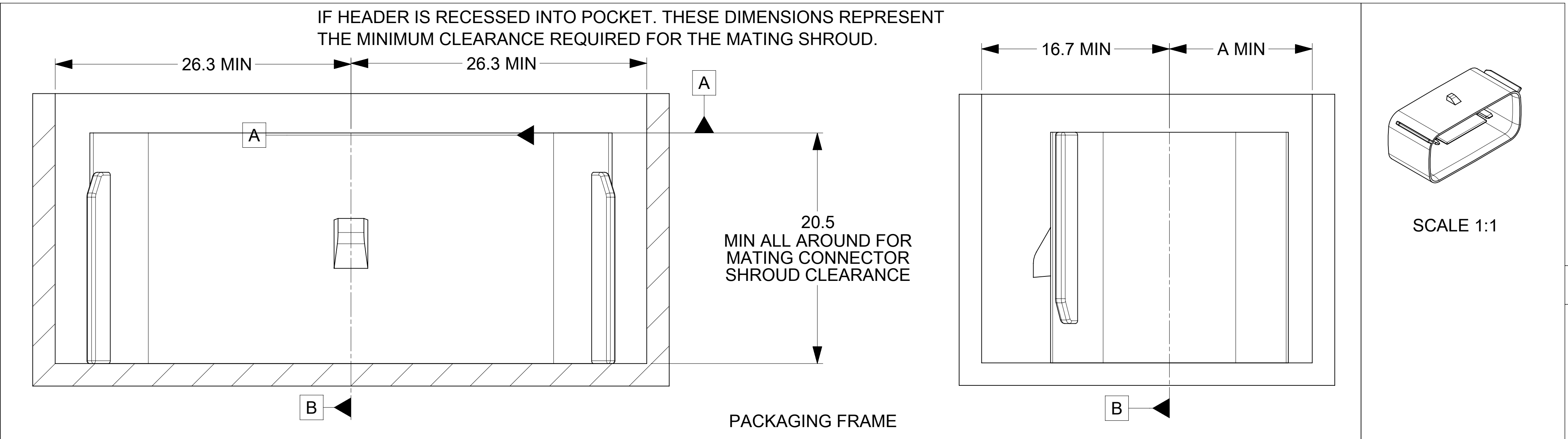

162	C	CHARTED DIMENSION ADDED FOR WITH AND WITHOUT CLIPSLOT	8-3-20	GE	MV
088	B23	ADDED DRAFT DIRECTION SYMBOL	3-25-11		
088	B22	ADDED REF DIMENSION FOR	3-11-11		
		LATCH HEIGHT			
088	B21	REMOVED THE WORD "OPTION" AT VIEW OF BACK ANGLE	3-11-11		
088	B20	CHANGED FROM 1.79 TO 1.80	3-11-11		
088	B19	ADDED 4X (0.805) AT BASE	1-14-11		
		AND AT TIP FOR 2.8			
		BLADE TERMINALS			
088	B18	CHANGED 16X TO 12X FOR THE 1.5	1-14-11		
		BLADE TERMINALS			
088	B17	UPDATED CONNECTOR COLORS	1-14-11		
088	B16	ADDED -G-	5-04-10		
088	B15	REMOVED	5-04-10		
088	B14	REMOVED SHORTING BAR NOTE	5-04-10		
088	B13	UPDATED NOTE 8 REMOVED REV F	5-04-10		
088	B12	ADDED NOTE 9	5-04-10		
088	B11	ADDED DIM 1.35+0.10/-0.20 MEASURED AT 2.9 FROM -A- ALL AROUND	5-04-10		
088	B10	ADDED SEE NOTE 8	5-04-10		
088	B9	2.50 WAS 2.80, ADDED (280-T001)	5-04-10		
088	B8	ADDED	5-04-10		
088	B7	ADDED	5-04-10		
088	B6	ADDED DIM 8.43	5-04-10		
088	B5	ADDED SEC C-C	5-04-10		
088	B4	UPDATED SEC B-B	5-04-10		
088	B3	ADDED DETAIL D	5-04-10		
088	B2	ADDED SEC C-C	5-04-10		
088	B1	ADDED DIM 0.70=0.15 ALL AROUND	5-04-10		
088	B	RELEASED	5-04-10	KC	MV
CHANGE SERIAL NUMBER	LET	REVISION RECORD	DATE	DWN	CHK

TOLERANCES (UNLESS OTHERWISE SPECIFIED)		THIRD ANGLE PROJECTION	
DIMENSIONS ARE IN MILLIMETERS			
ANGLES ±3°			
X	±0.2	XX	±0.10
EWCAP			
SCALE	4 - 1	DRAWN BY	G ELLIOTT
CHECKED BY	M VANSLAMBOUCK	DATE	08-03-20
TITLE			
DIRECT CONNECT INTERFACE			
16 WAY (2 X 8) 1.5MM SEALED MALE			
SHEET OF	DRAWING NUMBER	SIZE	REVISION LEVEL
999-S-016-2-Z02	E	DO NOT SCALE DRAWING COMPUTER AIDED DRAWING	C



TABLE OF CONTENTS	
SHEET NO.	SHEET DESCRIPTION
1	NOTES AND BOM
2	CONFIGURATIONS
3	KEY CONFIGURATIONS
4	RECEPTACLE CONNECTOR ASSEMBLY

NOTES: VALID UNLESS OTHERWISE SPECIFIED

1. GENERAL:
a. APPLICATION SPECIFICATION SEE: AS-33472-100
-CONTAINS: PRODUCT INTRODUCTION, PRODUCT SUMMARY, CONNECTOR ASSEMBLY, PACKAGING INFORMATION, CONNECTOR MATING, SERVICE INSTRUCTIONS, ELECTRICAL CONTINUITY CHECKING, CRIMPING, AND TROUBLESHOOTING.
-DESIGNED TO MATE WITH DEVICE OR CONNECTOR AS SPECIFIED IN THE MATING INTERFACE/CONNECTOR DRAWINGS CHART.
*DENOTES DRAWINGS THAT CAN BE ACCESSED AT <http://ewcap.uscarteams.org/>.
-ASSEMBLY SHIPPED WITH PLR IN PRE-LOCK POSITION (SEE PLR PRE-LOCK VIEW SHEET 4).
- b. PRODUCT SPECIFICATION SEE: PS-33476-000
CONTAINS: PRODUCT INTRODUCTION, PRODUCT SUMMARY, RATINGS (CURRENT, TEMPERATURE, SEALING, AND FLAMMABILITY), TERMINALS, WIRE DIAMETER RANGE, PRODUCT VALIDATION, AND PRODUCT DEVIATIONS.
- c. PACKAGING SPECIFICATION PER MOLEX DRAWING: SEE PACKAGING CHART
- d. PARTS MUST BE IN COMPLIANCE TO MOLEX CHEMICAL SUBSTANCES FOR PRODUCTS AND PACKAGING SPECIFICATION: QEHS-699000-300
- e. DATA MUST BE SUBMITTED UNDER THE MOLEX PART NUMBER TO IMDS (COMPANY ID#13255)
2. DESIGN - MATERIALS:
a. SEE BOM TABLE IN SD-34985-8002
3. DESIGN - GEOMETRY:
a. THE 3-D CAD DATA IS BASIC (WITHOUT TOLERANCE) AND MASTER FOR THIS PART WITH THE EXCEPTION OF UNDERLINED DIMENSIONS. DIMENSIONAL INFORMATION NOT SHOWN ON THIS DRAWING IS DEFINED BY THE DATA FILE AT ITS LATEST REVISION.
b. GEOMETRIC DIMENSIONS AND TOLERANCES PER ASME Y14.5M-2009
c. EDGES AND UNDIMENSIONED DETAILS PER ISO13715
d. CORNERS SHOWN AS SHARP TO BE R 0.2 MAX.
e. LETTERING SHALL BE 0.15 MAX RAISED IN 0.25 MAX RECESS PAD. THIS INCLUDES RECYCLING CODE, CAVITY ID, VENDOR IDENTIFICATION, AND CUSTOMER MATERIAL NUMBER.
f. VISUAL DEFECTS SHALL MEET COSMETIC STANDARD PS-45499-002 (Class B).
g. LASER MARKING:
1. PART NUMBER
2. DAY OF THE YEAR
3. SHIFT
4. YEAR
FOR ADDITIONAL INFORMATION SEE SECTION 5 UNDER PROCEDURES IN ES-34735-008.

PACKAGING	
DESCRIPTION	DRAWING NO.
W/ CLIPSLOT	PK-30907-895
W/O CLIPSLOT	PK-31300-094

MATING INTERFACE/CONNECTOR DRAWINGS		
DESCRIPTION	INTERFACE DEFINITION	MOLEX INLINE
W/O SHORTING BAR	*999-S-016-2-Z02	SD-34986-8001
W/ SHORTING BAR	N/A	SD-34986-8001

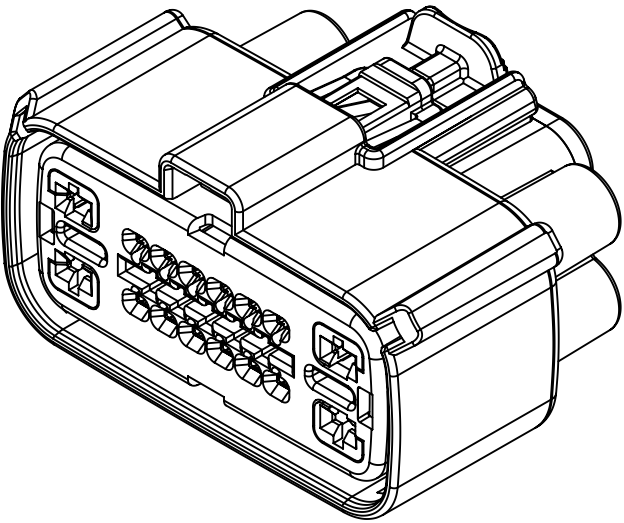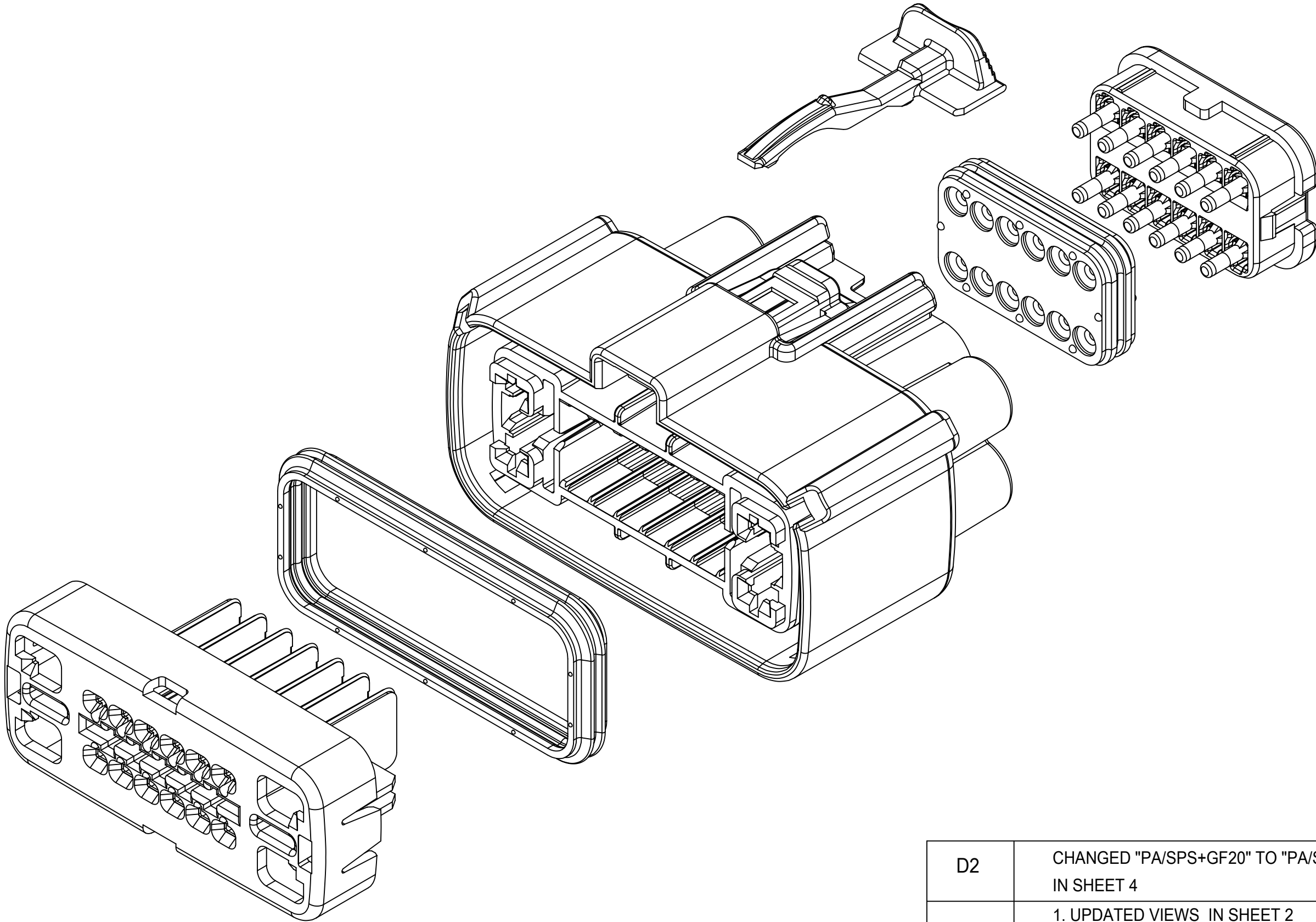



INSPECTION NUMBER LOG	A1	FIXED TYPO IN NOTE 1a
LAST NUMBER: 11 ADDED:	A	INITIAL RELEASE
REMOVED:	REV	REV DESCRIPTION

SYMBOLS		THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION									
	= 0	DIMENSION UNITS		SCALE		CURRENT REV DESC:					
		mm	1.5:1								
	= 0	GENERAL TOLERANCES (UNLESS SPECIFIED)				molex					
	= 0										
	= 0	ANGULAR TOL ± 3.0 °				MX150 16 WAY HYBRID RECPT SEALED ASSEMBLY					
	= 0	4 PLACES ±									
	= 0	3 PLACES ±				PRODUCT CUSTOMER DRAWING					
	= 0	2 PLACES ± 0.1									
	= 0	1 PLACE ± 0.3				DOCUMENT NUMBER					
	= 0	0 PLACES ±									
	= 0	DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS				SD-34985-8001					
	= 0										
						DOCUMENT TYPE		DOC PART		REVISION	
						PSD		001		D2	
						MATERIAL NUMBER		CUSTOMER		SHEET NUMBER	
						A1-SIZE		GENERAL MARKET		1 OF 4	
						SERIES					
						34985					



DOCUMENT STATUS	P1	RELEASE DATE	2019/08/02 15:55:47
-----------------	----	--------------	---------------------

SHEET DESCRIPTION



CONFIGURATIONS

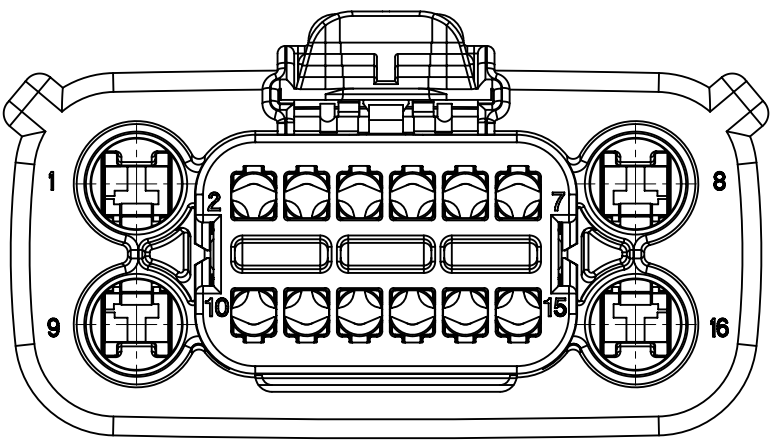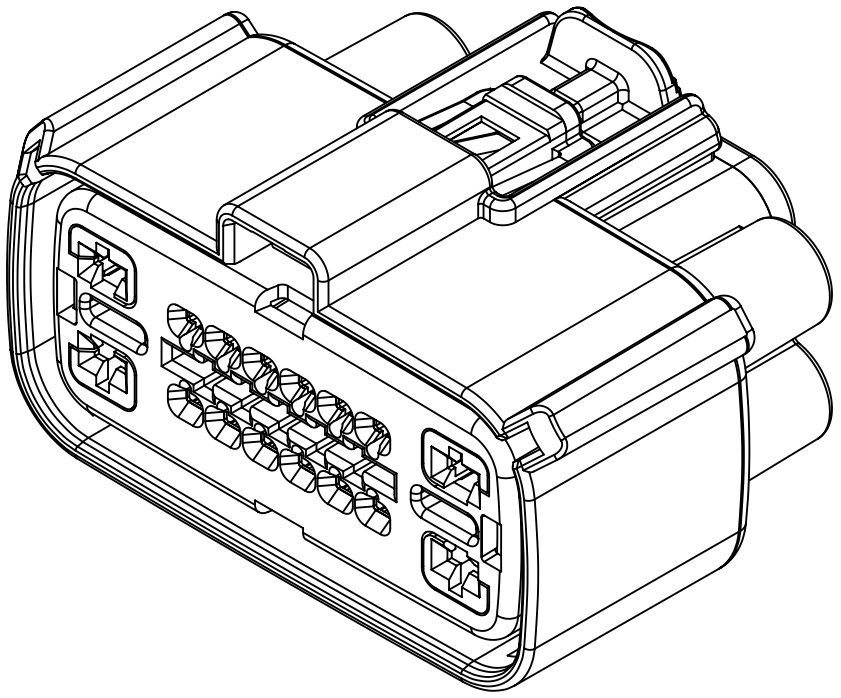



STANDARD (STD) - ALL OPEN 2.8mm CAVITIES

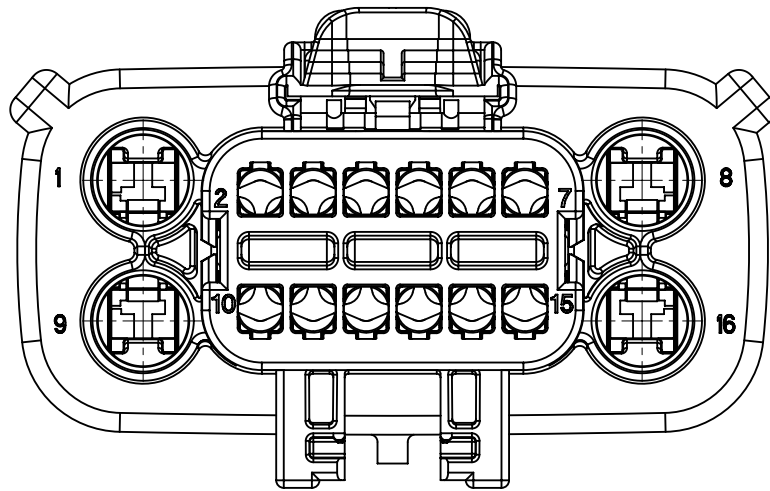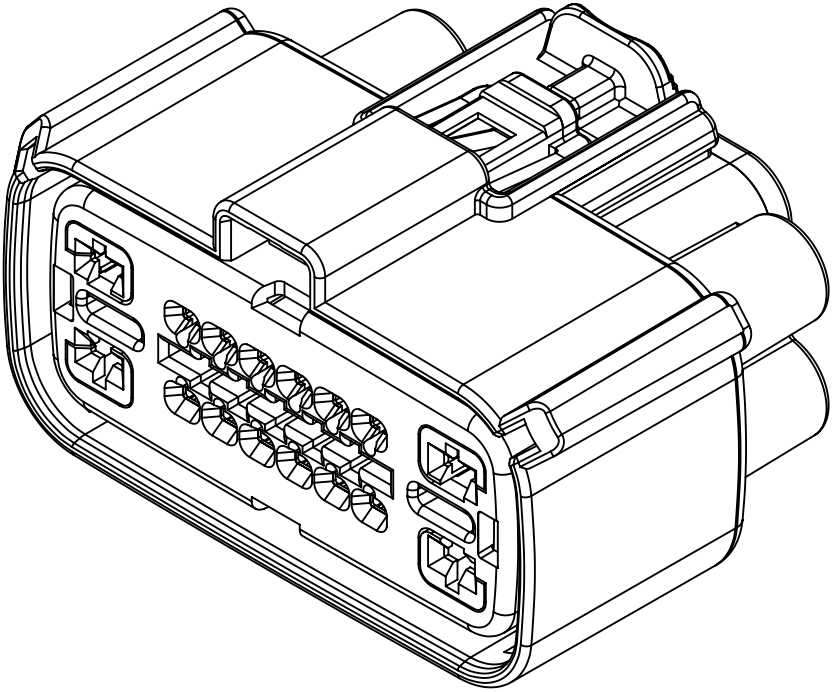

STANDARD (STD) - ALL OPEN 2.8mm CAVITIES
WITH CLIPSLOT

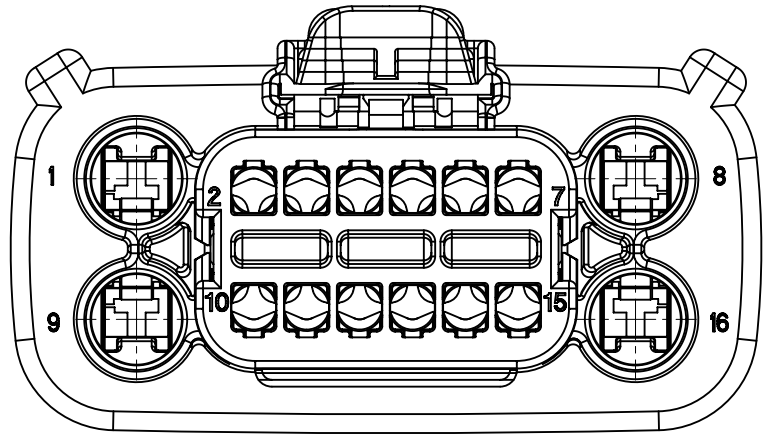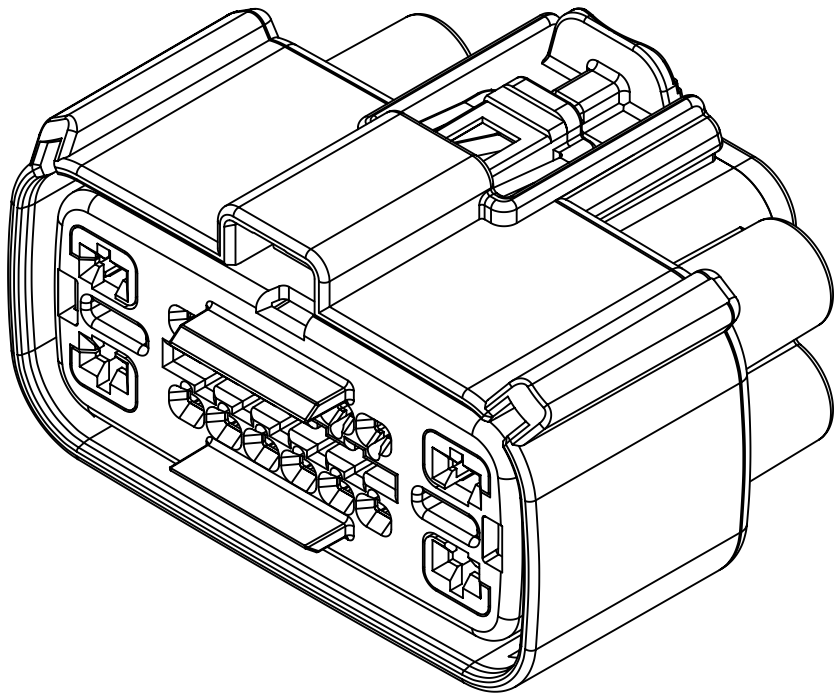

SHORTING (SHRT) BAR - ALL OPEN 2.8mm CAVITIES

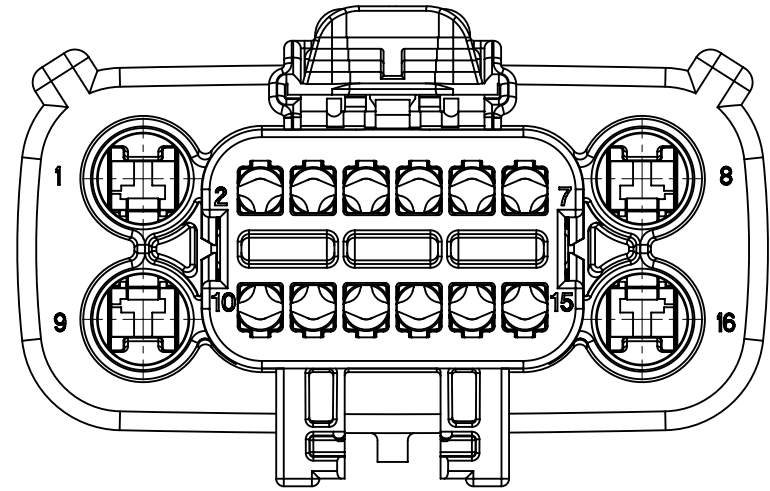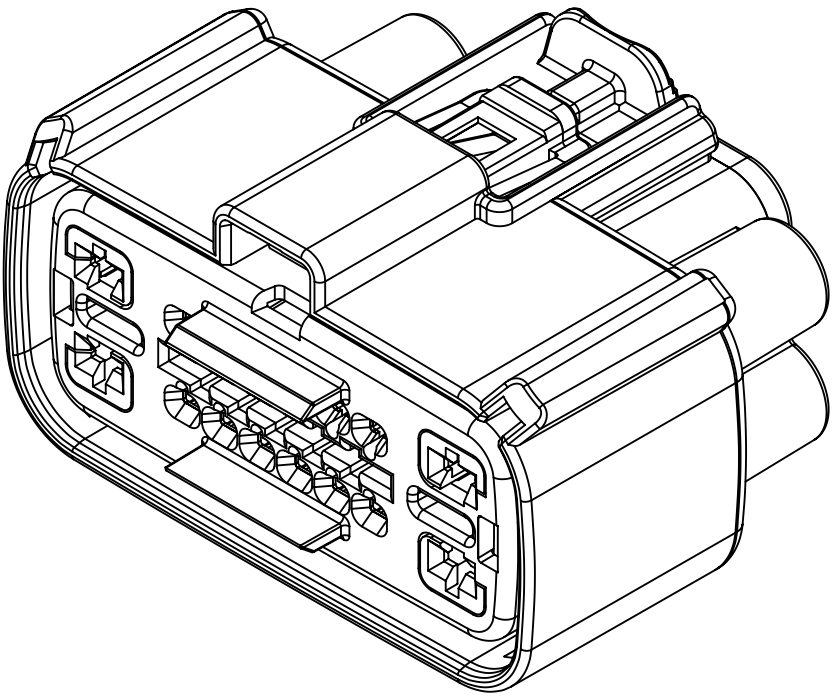


SHORTING (SHRT) BAR - ALL OPEN 2.8mm CAVITIES
WITH CLIPSLOT

SYMBOLS	THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION																
▽ = 0 ▽ = 0 ▽ = 0 ▽ = 0 ▽ = 0 ▽ = 0 ▽ = 0 ▽ = 0 ▽ = 0 ▽ = 0	DIMENSION UNITS		SCALE		CURRENT REV DESC: EC NO: 619601 DRWN: HKLIANG 2019/07/25 CHK'D: MVANSLAMBROU 2019/08/02 APPR: MVANSLAMBROU 2019/08/02 INITIAL REVISION: DRWN: TYE 2014/09/12 APPR: VKOSHY 2014/09/22 THIRD ANGLE PROJECTION DRAWING SERIES A1-SIZE 34985					molex							
	GENERAL TOLERANCES (UNLESS SPECIFIED)		2:1														
	ANGULAR TOL ± 3.0 °									MX150 16 WAY HYBRID RECPT SEALED ASSEMBLY							
	4 PLACES ±									PRODUCT CUSTOMER DRAWING							
	3 PLACES ±																
	2 PLACES ± 0.1																
	1 PLACE ± 0.3																
	0 PLACES ±									DOCUMENT NUMBER		DOC TYPE		DOC PART		REVISION	
	DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS		THIRD ANGLE PROJECTION							DRAWING		SERIES		SD-34985-8001		PSD	
					MATERIAL NUMBER		CUSTOMER		SHEET NUMBER								
GENERAL MARKET					2 OF 4												


DOCUMENT STATUS	P1	RELEASE DATE	2019/08/02 15:55:47
-----------------	----	--------------	---------------------

SHEET DESCRIPTION


KEY CONFIGURATIONS

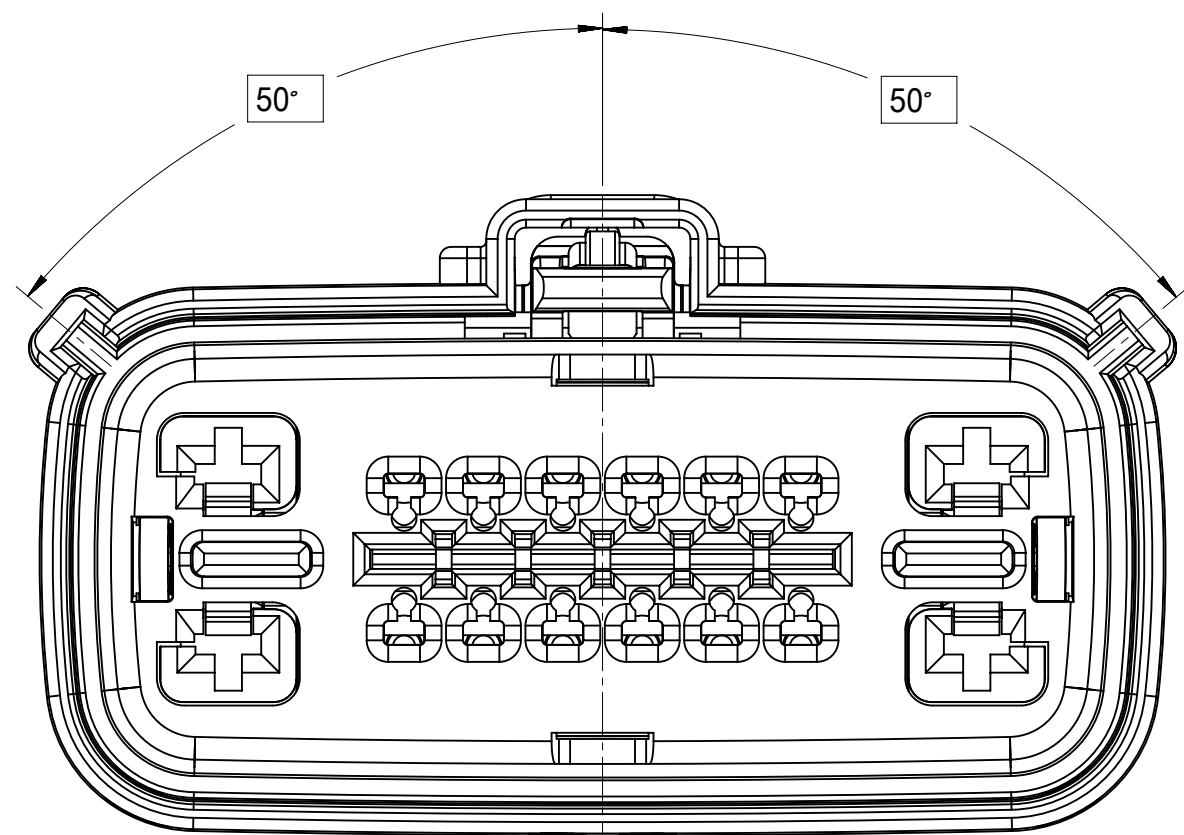


KEY A

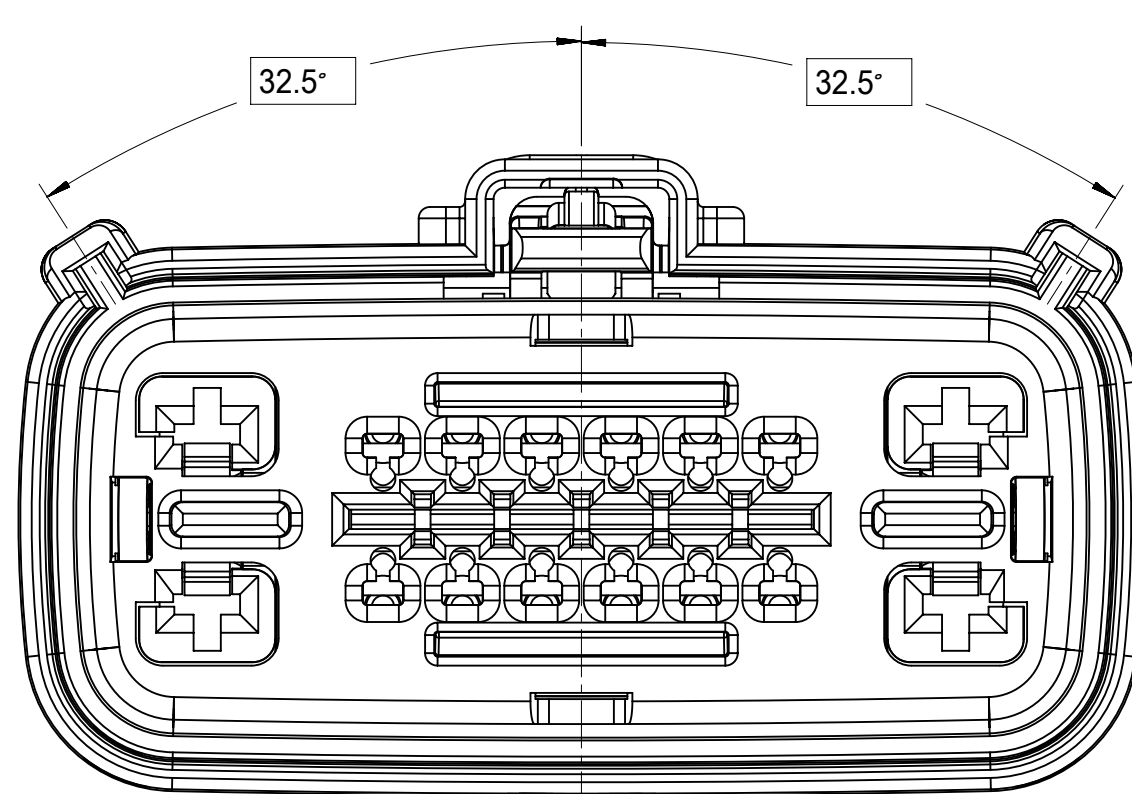


KEY E

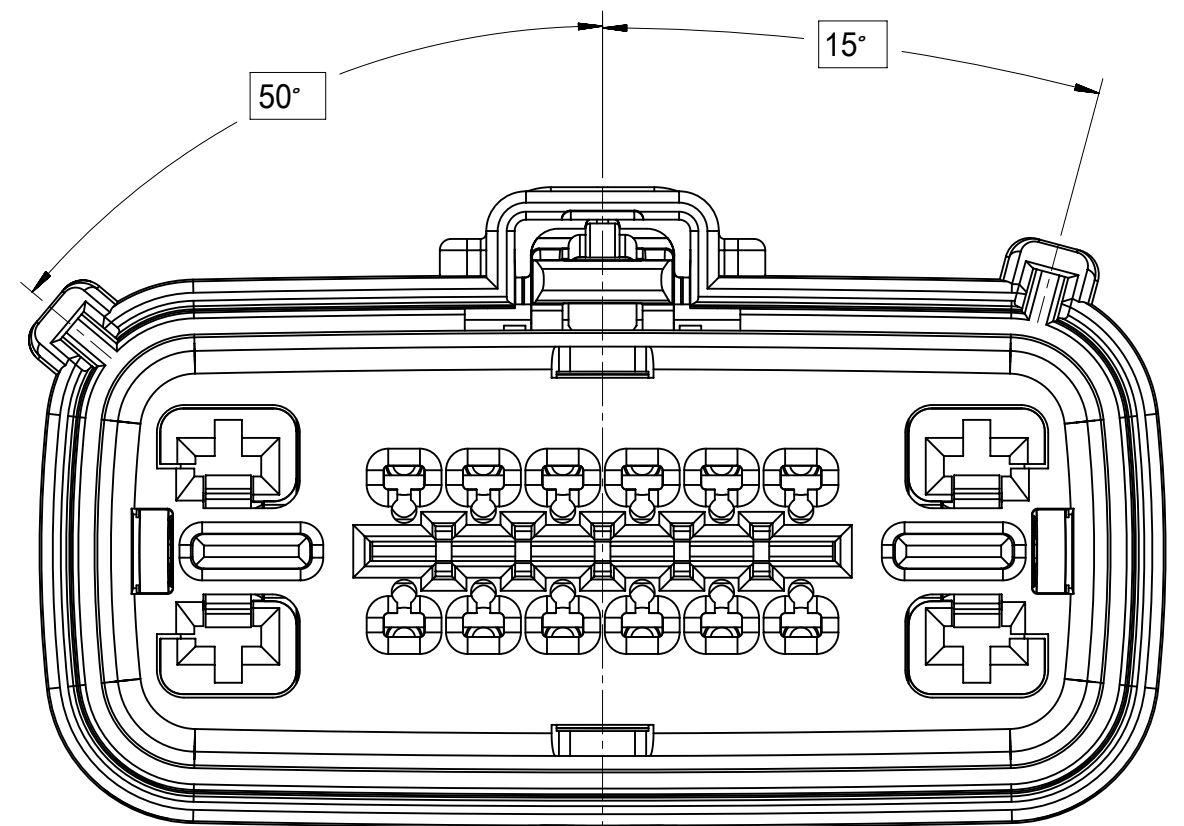


KEY B

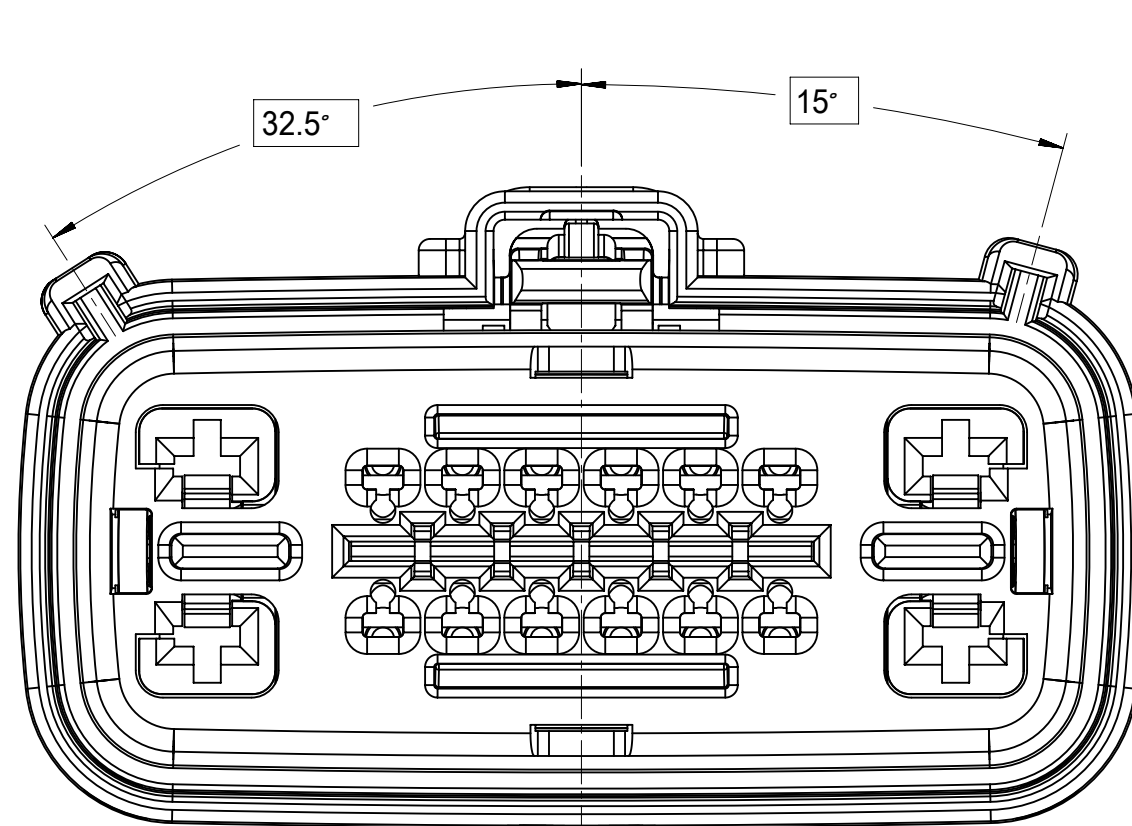


KEY F

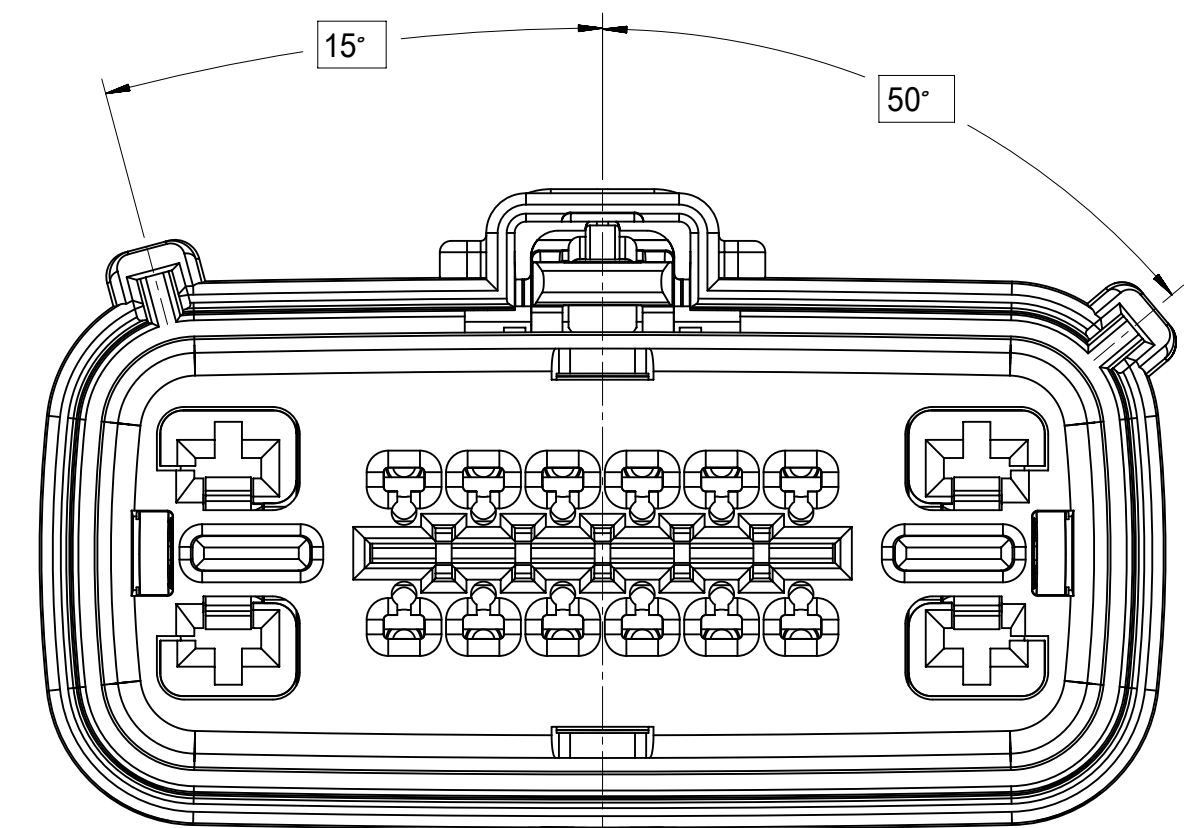


KEY C

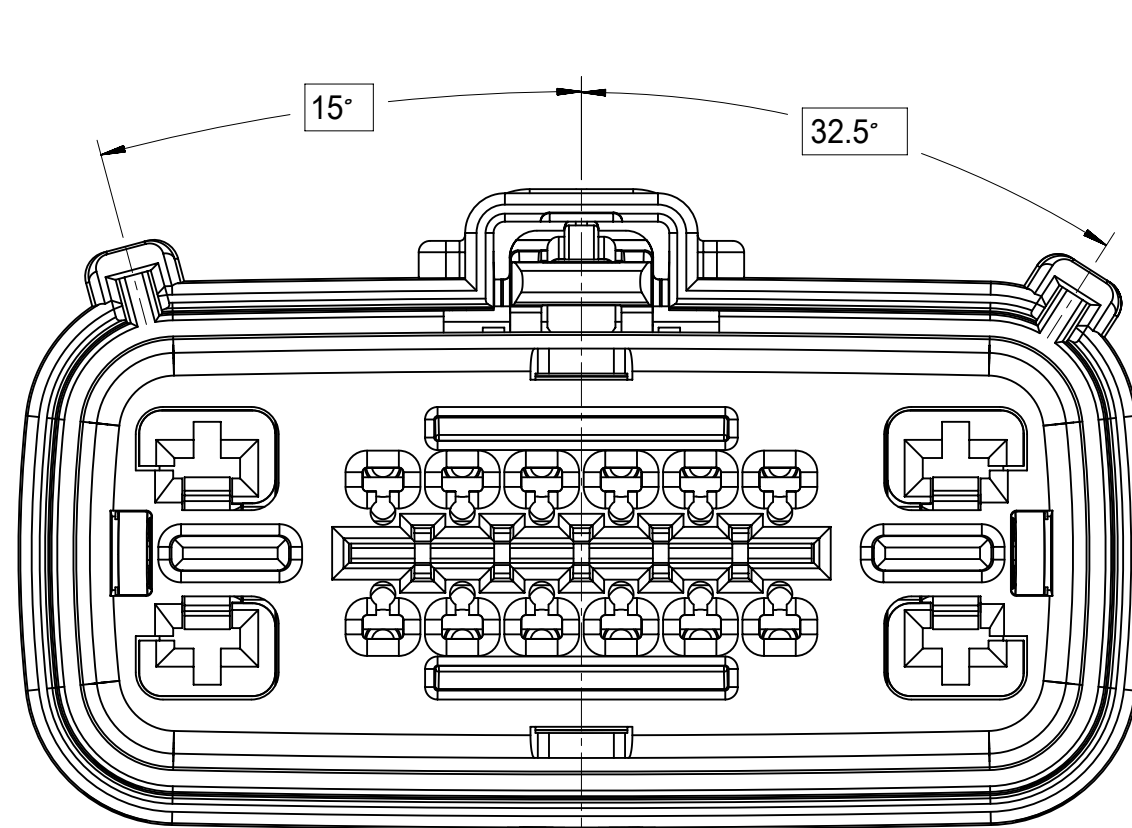

KEY G

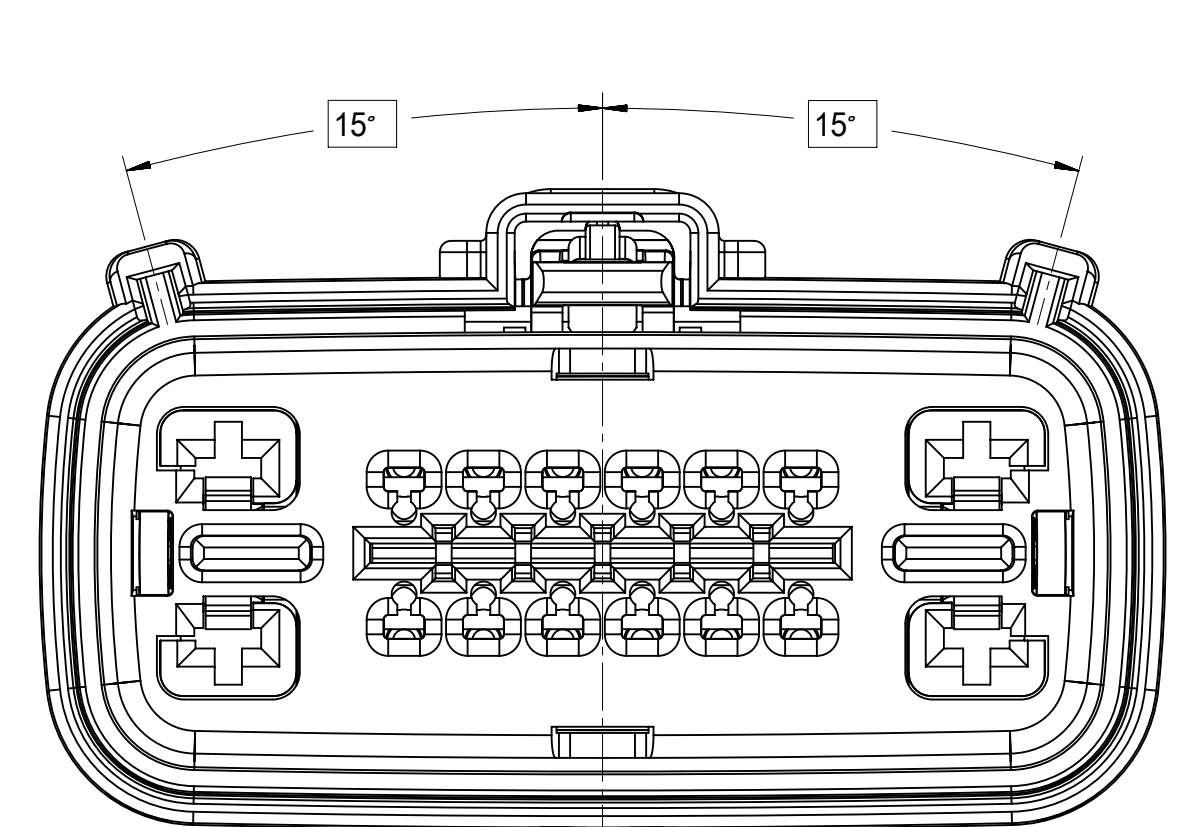

KEY D







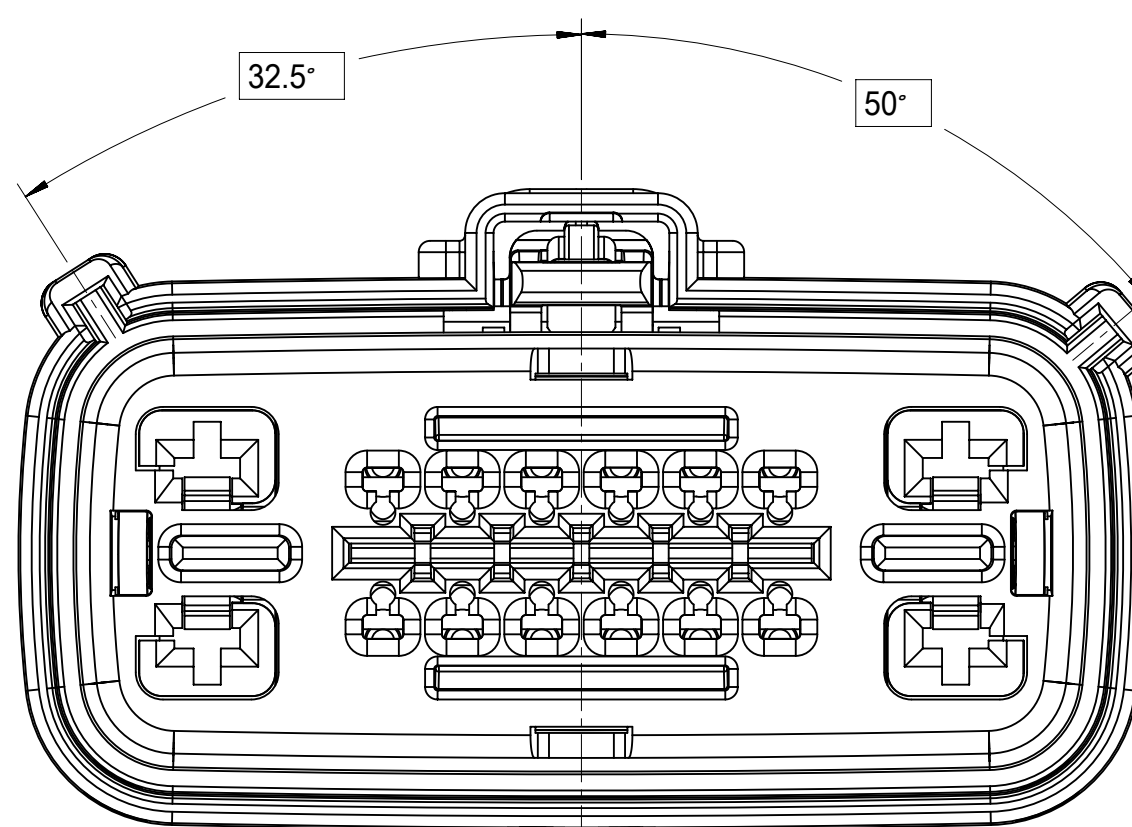


KEY H

SYMBOLS	THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION														
	DIMENSION UNITS		SCALE	CURRENT REV DESC:				molex MX150 16 WAY HYBRID RECPT SEALED ASSEMBLY							
A = 0	mm		3:1												
F = 0	GENERAL TOLERANCES (UNLESS SPECIFIED)														
E = 0	ANGULAR TOL ± 3.0°			EC NO: 619601 DRWN: HKLIANG 2019/07/25 CHK'D: MVANSLAMBROU 2019/08/02 APPR: MVANSLAMBROU 2019/08/02				PRODUCT CUSTOMER DRAWING							
S = 0	4 PLACES		±												
T = 0	3 PLACES		±												
C = 0	2 PLACES		± 0.1	INITIAL REVISION: DRWN: TYE 2014/09/12 APPR: VKOSHY 2014/09/22				DOCUMENT NUMBER		DOC TYPE	DOC PART	REVISION			
X = 0	1 PLACE		± 0.3					SD-34985-8001		PSD	001	D2			
■ = 0	0 PLACES		±	THIRD ANGLE PROJECTION		DRAWING		SERIES		MATERIAL NUMBER		CUSTOMER		SHEET NUMBER	
□ = 0	DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS														
▽ = 0				A1-SIZE		34985				GENERAL MARKET		3 OF 4			

SHEET DESCRIPTION


RECEPTACLE CONNECTOR ASSEMBLY

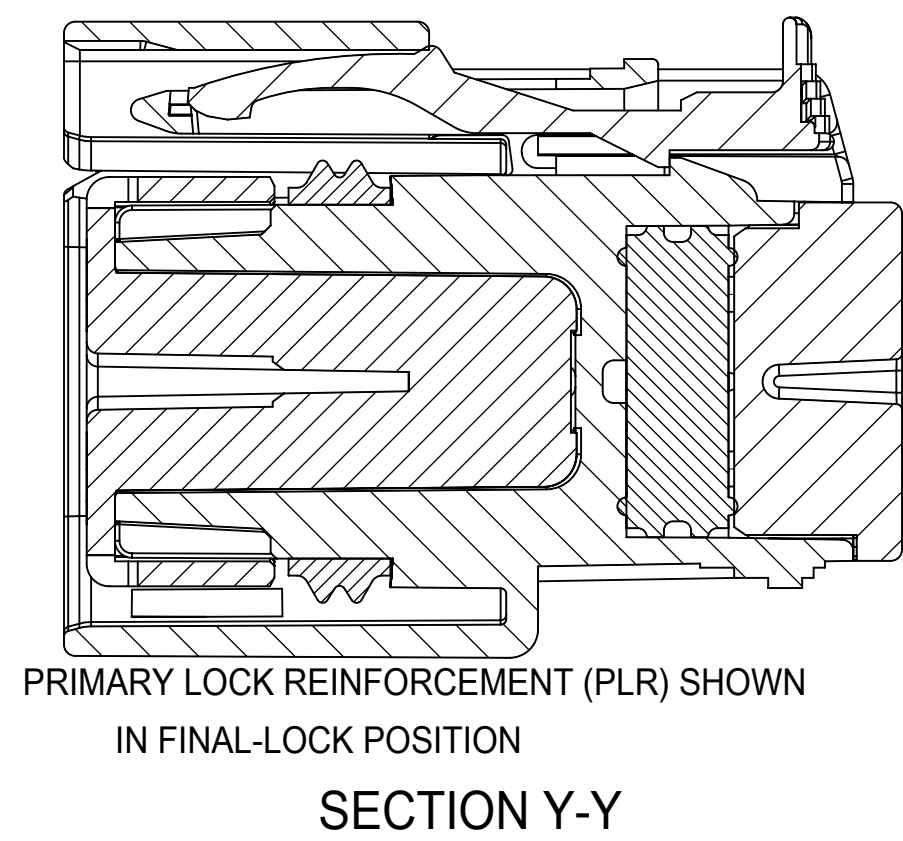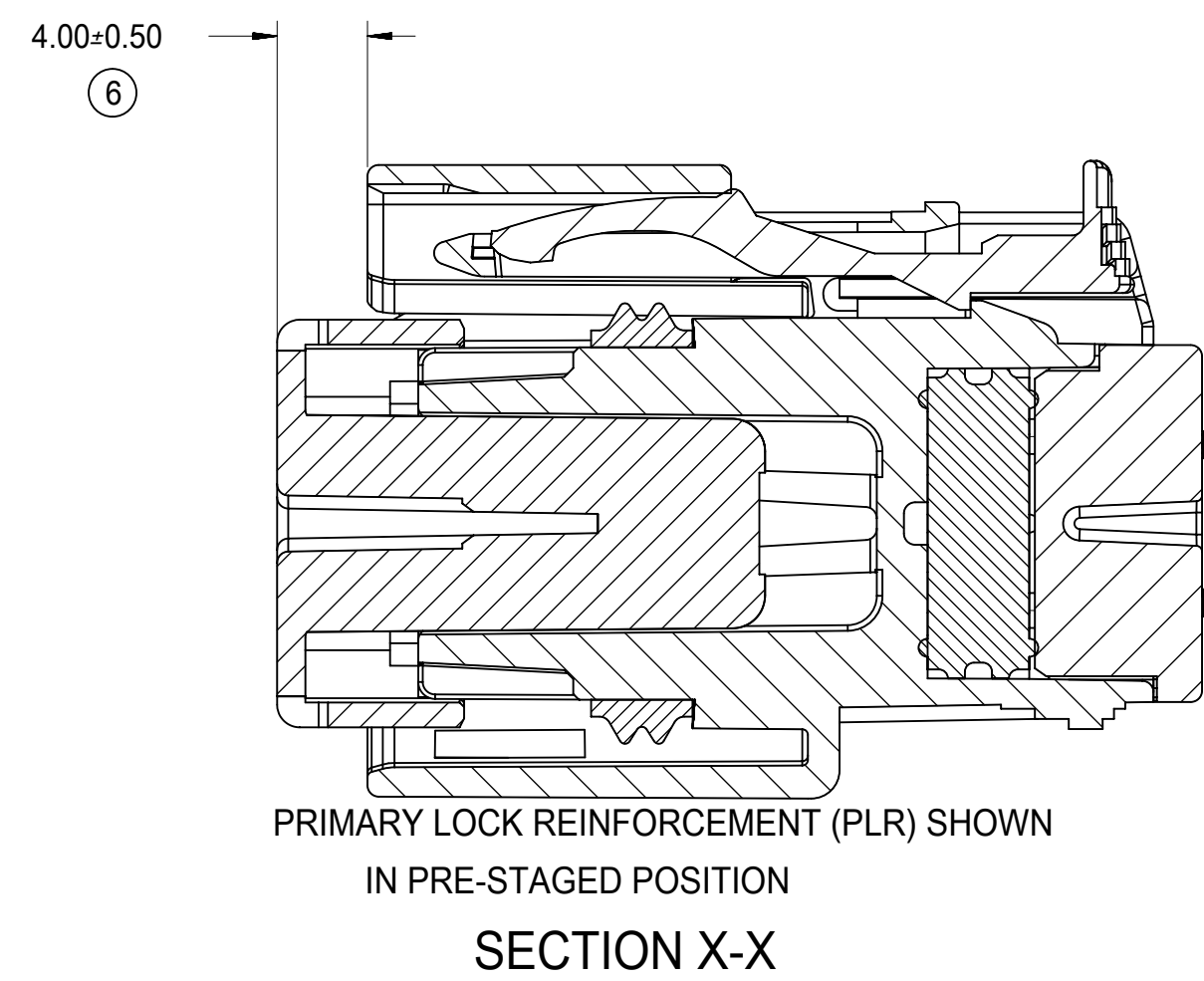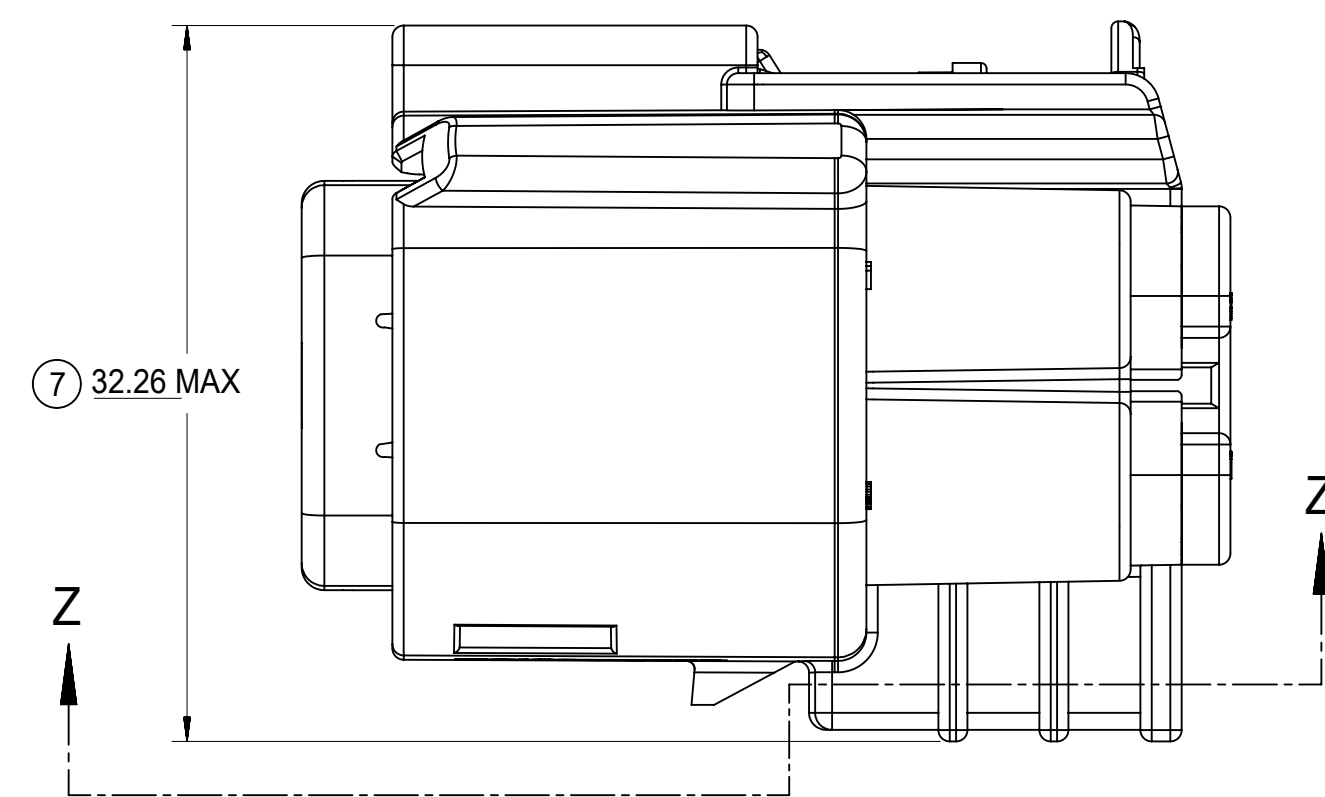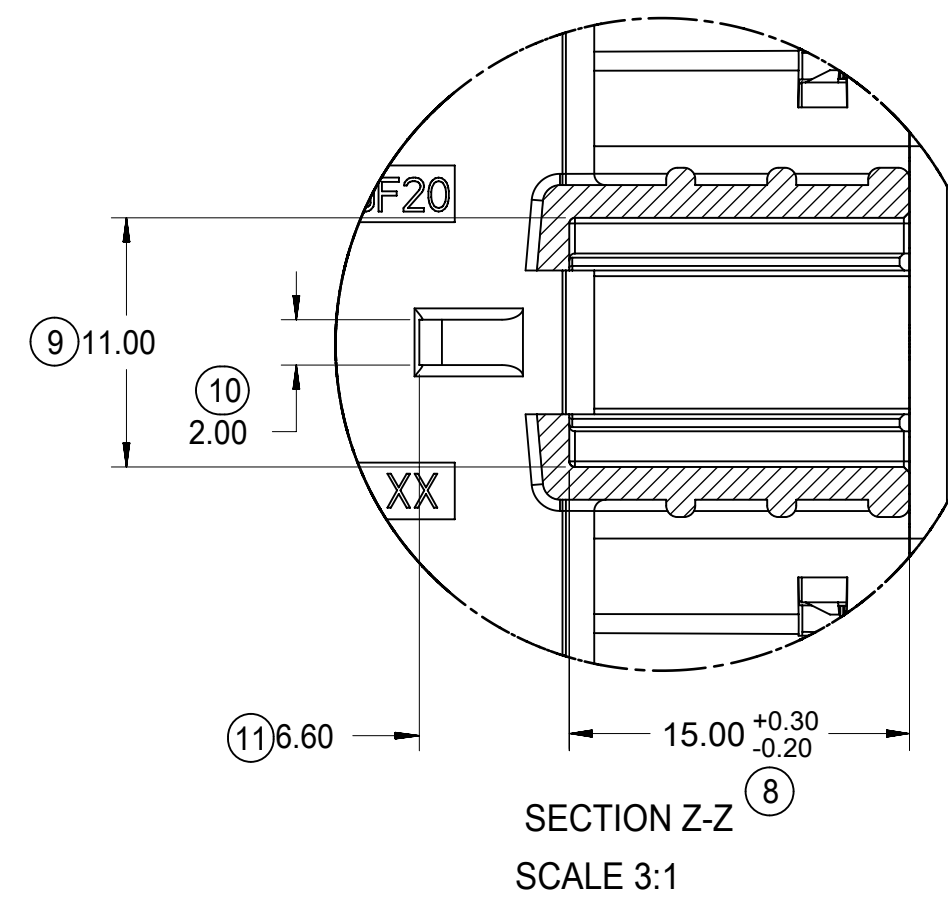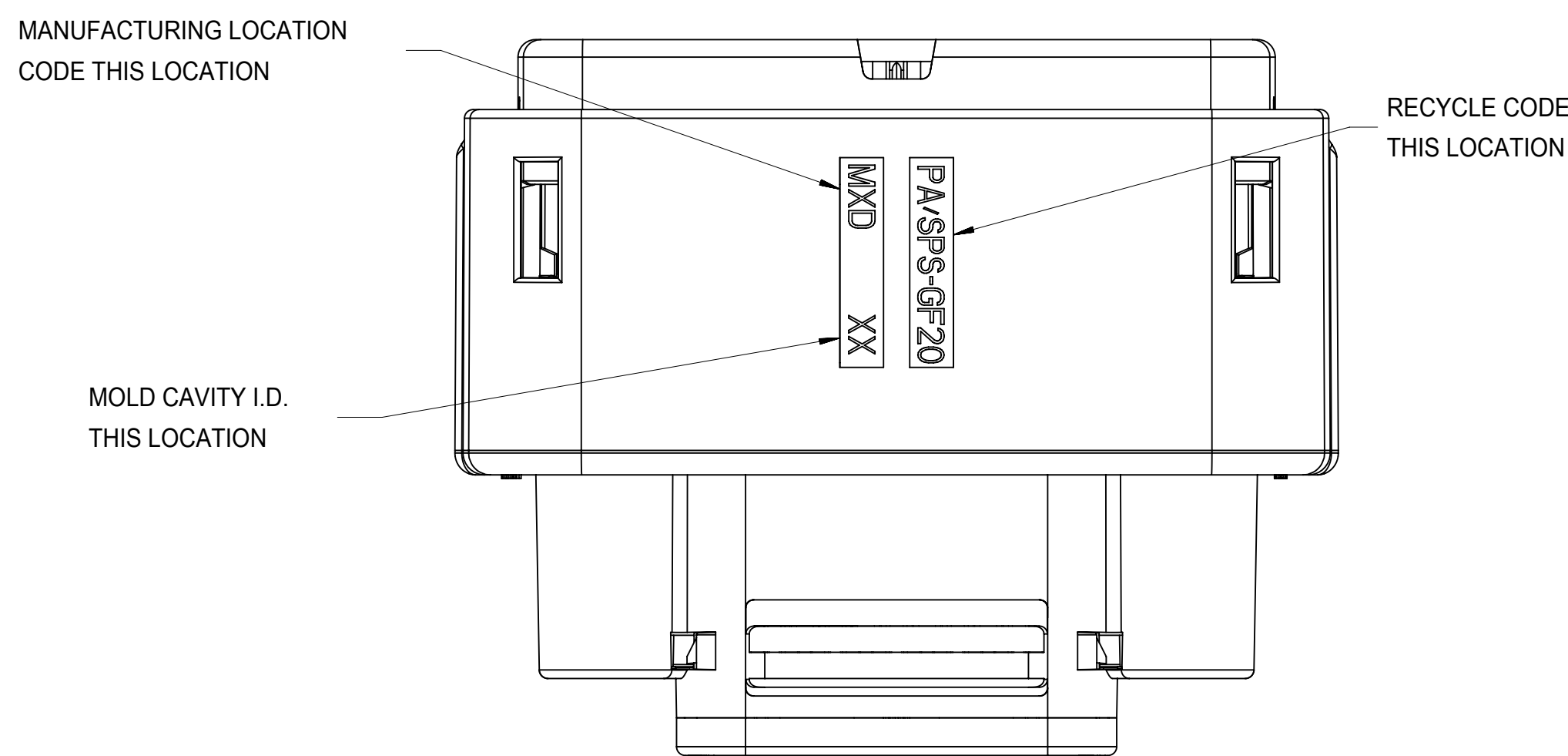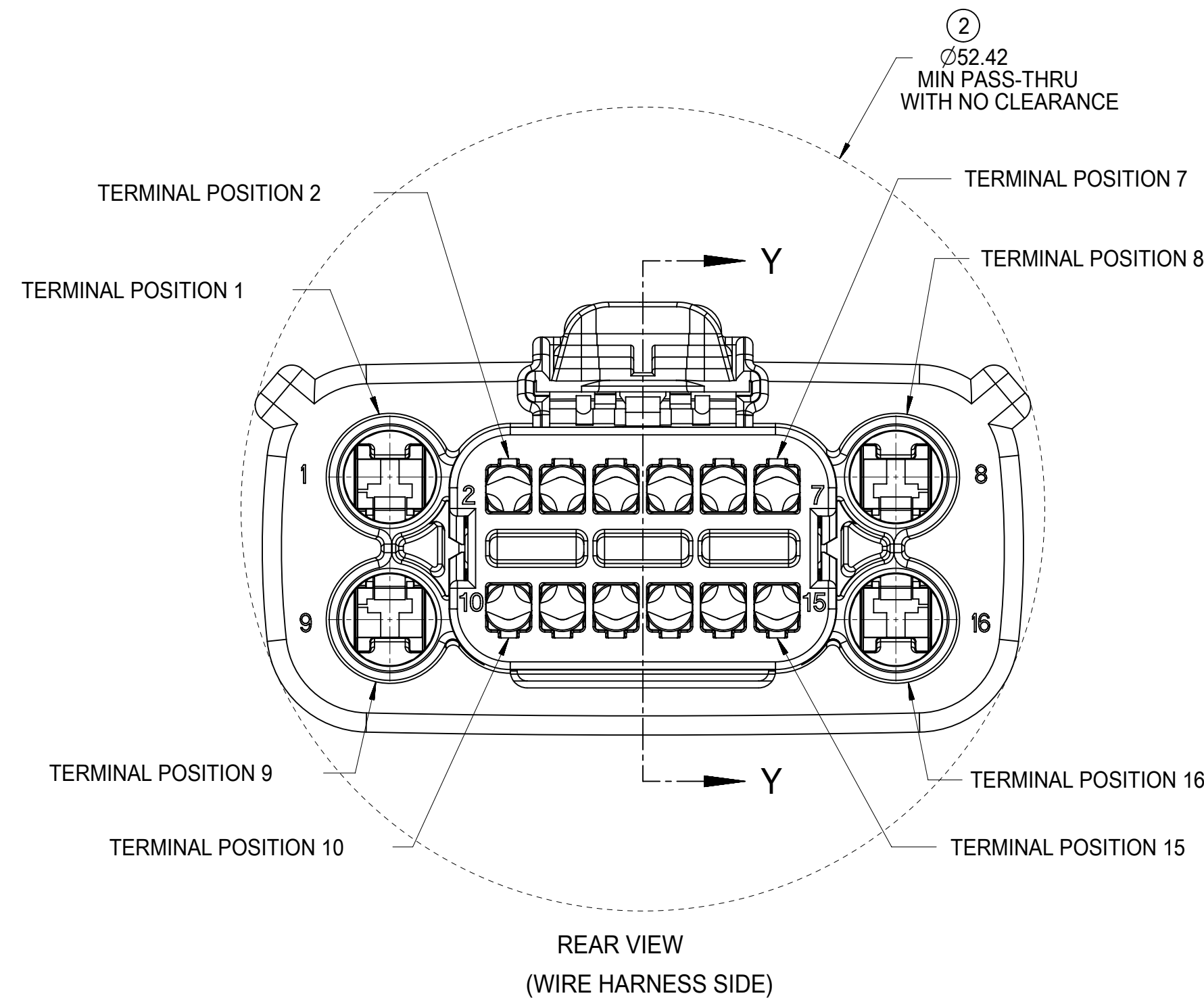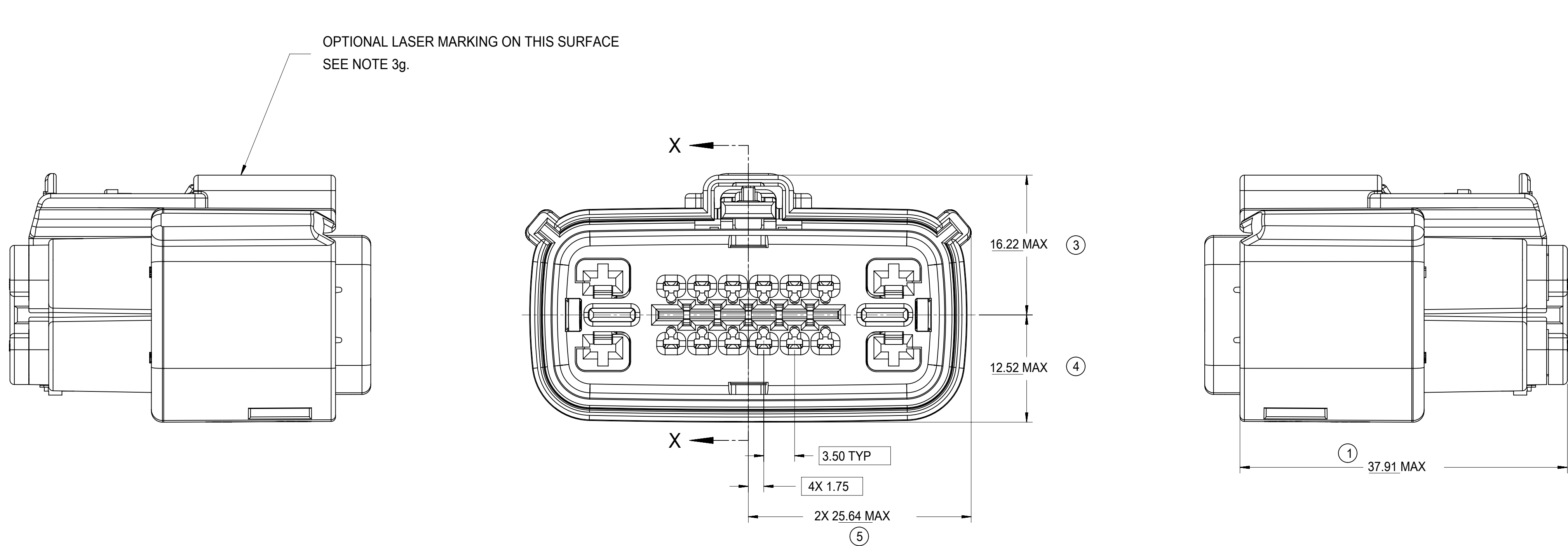

SYMBOLS	THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO MOLEX ELECTRONIC TECHNOLOGIES, LLC AND SHOULD NOT BE USED WITHOUT WRITTEN PERMISSION														
	DIMENSION UNITS		SCALE	CURRENT REV DESC:				molex MX150 16 WAY HYBRID RECPT SEALED ASSEMBLY							
	mm	3:1													
	= 0	GENERAL TOLERANCES (UNLESS SPECIFIED)		EC NO: 619601 DRWN: HKLIANG 2019/07/25 CHK'D: MVANSLAMBROU 2019/08/02 APPR: MVANSLAMBROU 2019/08/02 INITIAL REVISION: DRWN: TYE 2014/09/12 APPR: VKOSHY 2014/09/22				PRODUCT CUSTOMER DRAWING							
	= 0	ANGULAR TOL ± 3.0 °													
	= 0	4 PLACES	±												
	= 0	3 PLACES	±												
	= 0	2 PLACES	± 0.1												
	= 0	1 PLACE	± 0.3					DOCUMENT NUMBER	DOC TYPE	DOC PART	REVISION				
	= 0	0 PLACES	±					SD-34985-8001	PSD	001	D2				
	= 0	DRAFT WHERE APPLICABLE MUST REMAIN WITHIN DIMENSIONS		THIRD ANGLE PROJECTION		DRAWING		SERIES		MATERIAL NUMBER		CUSTOMER		SHEET NUMBER	
	= 0					A1-SIZE		34985				GENERAL MARKET		4 OF 4	

DOCUMENT STATUS	P1	RELEASE DATE	2019/08/02 15:55:47
-----------------	----	--------------	---------------------

MX150 16 WAY HYBRID RECEPTACLE SEALED ASSEMBLY MAT SEAL (WITHOUT CLIPSLOT, 2.8mm CAVITIES OPEN)
BOM AND PIN OUT SHEET

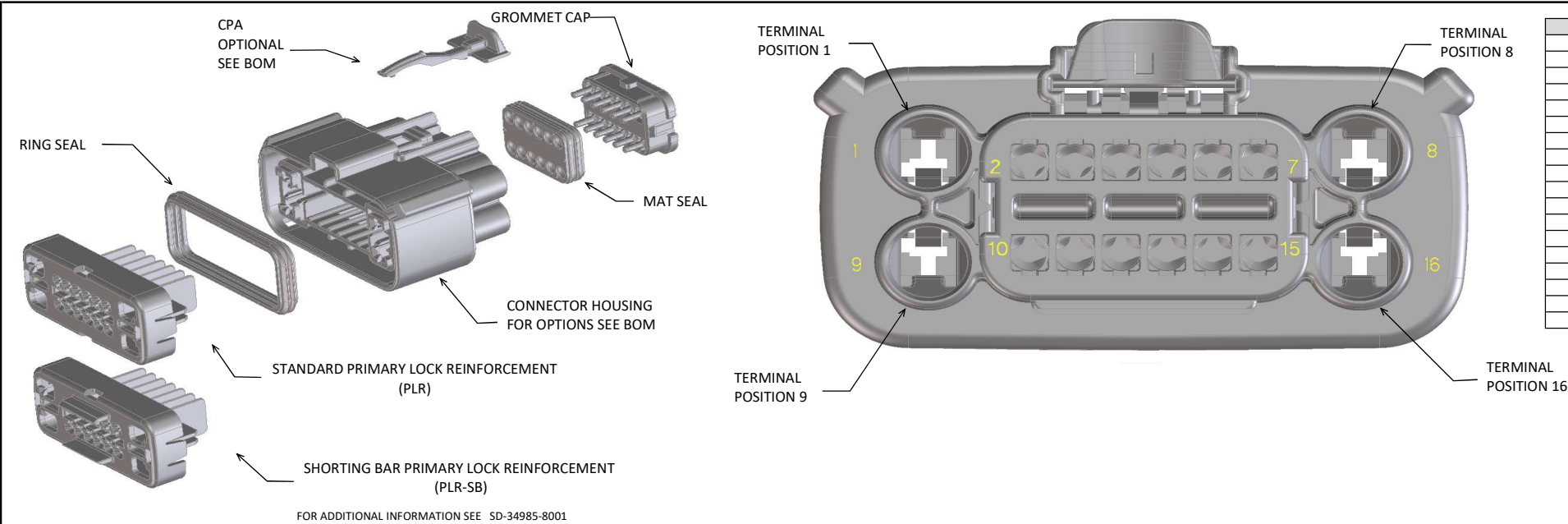

ABBREVIATION	DESCRIPTION	COLOR	MATERIAL
A-BLK	HOUSING, KEYING OPTION A	BLACK	SPS/NYLON GF20
B-LG	HOUSING, KEYING OPTION B	LIGHT GRAY	SPS/NYLON GF20
C-DG	HOUSING, KEYING OPTION C	DARK GRAY	SPS/NYLON GF20
D-SG	HOUSING, KEYING OPTION D	STONE GRAY	SPS/NYLON GF20
A-YW	HOUSING, KEYING OPTION A	YELLOW	SPS/NYLON GF20
C-BR	HOUSING, KEYING OPTION C	BROWN	SPS/NYLON GF20
D-GR	HOUSING, KEYING OPTION D	GREEN	SPS/NYLON GF20
E-BLK	HOUSING, KEYING OPTION E	BLACK	SPS/NYLON GF20
F-LG	HOUSING, KEYING OPTION F	LIGHT GRAY	SPS/NYLON GF20
G-BR	HOUSING, KEYING OPTION G	BROWN	SPS/NYLON GF20
G-DG	HOUSING, KEYING OPTION G	DARK GRAY	SPS/NYLON GF20
H-YW	HOUSING, KEYING OPTION H	YELLOW	SPS/NYLON GF20
GC	GROMMET CAP	BLACK	SPS/NYLON GF20
PLR	STANDARD PLR	NATURAL	SPS/NYLON GF20
PLR-SB	SHORTING BAR PLR	NATURAL	PBT GF15
CPA	CPA	RED	PBT GF30
M	MAT SEAL	ROYAL BLUE	INHERENTLY LUBRICATED SILICONE
R	RING SEAL	GREEN	INHERENTLY LUBRICATED SILICONE

ASSEMBLY DESCRIPTION	ASSEMBLY PART NUMBER	COMPONENT						BLOCKED TERMINALS																STATUS	COMMENTS	OPTIONAL ATTATCHMENTS SOLD SEPERATELY	
		THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT.						CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION																		BACKSHELL WITH RIBS	BACKSHELL WITHOUT RIBS
		HOUSING KEY/COLOR	GROMMET CAP	PLR	CPA	MAT SEAL	RING SEAL	1	2	3	4	5	6	7	8	9	10	11	12	13	14	15	16				
KEY A, BLACK, W/O CPA	34985-1601	A-BLK	GC	PLR		M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-1602	B-LG	GC	PLR		M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY C, BROWN, W/O CPA	34985-1603	C-BR	GC	PLR		M	R																	NOT RECOMMENDED	SEE 34985-2121	NOT AVAILABLE	NOT AVAILABLE
KEY D, GREEN, W/O CPA	34985-1604	D-GR	GC	PLR		M	R																	NOT RECOMMENDED	SEE 34985-2157	NOT AVAILABLE	NOT AVAILABLE
KEY A, YELLOW, W/O CPA	34985-1605	A-YW	GC	PLR		M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-1606	A-BLK	GC	PLR	CPA	M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-1607	B-LG	GC	PLR	CPA	M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY C, BROWN, W/CPA	34985-1608	C-BR	GC	PLR	CPA	M	R																	NOT RECOMMENDED	SEE 34985-2160	NOT AVAILABLE	NOT AVAILABLE
KEY D, GREEN, W/CPA	34985-1609	D-GR	GC	PLR	CPA	M	R																	NOT RECOMMENDED	SEE 34985-2184	NOT AVAILABLE	NOT AVAILABLE
KEY A, YELLOW, W/O CPA	34985-1610	A-YW	GC	PLR		M	R														14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1611	A-BLK	GC	PLR		M	R		2															SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-1612	B-LG	GC	PLR		M	R		2															SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY C, BROWN, W/O CPA	34985-1613	C-BR	GC	PLR		M	R		2															NOT RECOMMENDED		NOT AVAILABLE	NOT AVAILABLE
KEY D, GREEN, W/O CPA	34985-1614	D-GR	GC	PLR		M	R		2															NOT RECOMMENDED		NOT AVAILABLE	NOT AVAILABLE
KEY A, YELLOW, W/O CPA	34985-1615	A-YW	GC	PLR		M	R					6	7				10	11			14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-1616	A-BLK	GC	PLR	CPA	M	R		2															SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-1617	B-LG	GC	PLR	CPA	M	R		2															SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY C, BROWN, W/CPA	34985-1618	C-BR	GC	PLR	CPA	M	R		2															NOT RECOMMENDED		NOT AVAILABLE	NOT AVAILABLE
KEY D, GREEN, W/CPA	34985-1619	D-GR	GC	PLR	CPA	M	R		2															NOT RECOMMENDED		NOT AVAILABLE	NOT AVAILABLE
KEY A, YELLOW, W/O CPA	34985-1620	A-YW	GC	PLR		M	R					6					10	11			14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1621	A-BLK	GC	PLR		M	R		2													15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-1622	B-LG	GC	PLR		M	R		2													15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY C, BROWN, W/O CPA	34985-1623	C-BR	GC	PLR		M	R		2													15		NOT RECOMMENDED		NOT AVAILABLE	NOT AVAILABLE
KEY D, GREEN, W/O CPA	34985-1624	D-GR	GC	PLR		M	R		2													15		NOT RECOMMENDED		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-1625	B-LG	GC	PLR		M	R												12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-1626	A-BLK	GC	PLR	CPA	M	R		2													15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-1627	B-LG	GC	PLR	CPA	M	R		2													15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY C, BROWN, W/CPA	34985-1628	C-BR	GC	PLR	CPA	M	R		2													15		NOT RECOMMENDED		NOT AVAILABLE	NOT AVAILABLE
KEY D, GREEN, W/CPA	34985-1629	D-GR	GC	PLR	CPA	M	R		2													15		NOT RECOMMENDED		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-1630	B-LG	GC	PLR		M	R					6	7				10	11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1641	A-BLK	GC	PLR		M	R		2	3	4	5	6	7			10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1651	A-BLK	GC	PLR		M	R		2	3			6											SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1661	A-BLK	GC	PLR		M	R			3			6											SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1671	A-BLK	GC	PLR		M	R						6											SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY E, BLACK, W/ SHRT BAR, W/O CPA	34985-1701	E-BLK	GC	PLR-SB		M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ SHRT BAR, W/O CPA	34985-1702	F-LG	GC	PLR-SB		M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY G, BROWN, W/ SHRT BAR, W/O CPA	34985-1703	G-BR	GC	PLR-SB		M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY H, YELLOW, W/ SHRT BAR, W/O CPA	34985-1704	H-YW	GC	PLR-SB		M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY H, YELLOW, W/ SHRT BAR, W/CPA	34985-1706	H-YW	GC	PLR-SB	CPA	M	R												12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY H, YELLOW, W/ SHRT BAR, W/CPA	34985-1707	H-YW	GC	PLR-SB	CPA	M	R		2											12	13		15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY H, YELLOW, W/ SHRT BAR, W/CPA	34985-1708	H-YW	GC	PLR-SB	CPA	M	R		2													15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY H, YELLOW, W/ SHRT BAR, W/CPA	34985-1709	H-YW	GC	PLR-SB	CPA	M	R			3			6	7			10	11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY H, YELLOW, W/ SHRT BAR, W/CPA	34985-1710	H-YW	GC	PLR-SB	CPA	M	R			3			6	7			10	11			14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY H, YELLOW, W/ SHRT BAR, W/CPA	34985-1711	H-YW	GC	PLR-SB	CPA	M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY H, YELLOW, W/ SHRT BAR, W/CPA	34985-1712	H-YW	GC	PLR-SB	CPA	M	R		2	3			6	7			10	11				15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1801	A-BLK	GC	PLR		M	R							7						13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1811	A-BLK	GC	PLR		M	R		2	3			6	7						13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1821	A-BLK	GC	PLR		M	R						6	7							13			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1831	A-BLK	GC	PLR		M	R		2	3			6					11						SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-1842	B-LG	GC	PLR		M	R				4								12					SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1843	A-BLK	GC	PLR		M	R			3			6						12					SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1844	A-BLK	GC	PLR		M	R				4								12					SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1845	A-BLK	GC	PLR		M	R		2								10		12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1846	A-BLK	GC	PLR		M	R		2	3							10		12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1847	A-BLK	GC	PLR		M	R		2		4			7								15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1879	A-BLK	GC	PLR		M	R					5	6											SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1880	A-BLK	GC	PLR		M	R					5	6							13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1882	A-BLK	GC	PLR		M	R						6								14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE

MX150 16 WAY HYBRID RECEPTACLE SEALED ASSEMBLY MAT SEAL (WITHOUT CLIPSLOT, 2.8mm CAVITIES OPEN)

BOM AND PIN OUT SHEET

ASSEMBLY DESCRIPTION	ASSEMBLY PART NUMBER	COMPONENT						BLOCKED TERMINALS																STATUS	COMMENTS	OPTIONAL ATTATCHMENTS SOLD SEPERATELY	
		THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT.						CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION																		BACKSHELL WITH RIBS	BACKSHELL WITHOUT RIBS
		HOUSING KEY/COLOR	GROMMET CAP	PLR	CPA	MAT SEAL	RING SEAL	1	2	3	4	5	6	7	8	9	10	11	12	13	14	15	16				
KEY A, BLACK, W/O CPA	34985-1883	A-BLK	GC	PLR		M	R			3			6				10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1884	A-BLK	GC	PLR		M	R						6				10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-1885	A-BLK	GC	PLR		M	R											11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-1886	B-LG	GC	PLR		M	R					5							13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-1887	B-LG	GC	PLR		M	R					5							13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1888	A-BLK	GC	PLR		M	R		2					7		10	11						SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1889	A-BLK	GC	PLR		M	R		2					7					13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1890	A-BLK	GC	PLR		M	R			3			6	7					13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1901	A-BLK	GC	PLR		M	R		2				7						12	13	14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1902	A-BLK	GC	PLR		M	R						7						12	13	14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1903	A-BLK	GC	PLR		M	R			3		5	6				11					15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1904	A-BLK	GC	PLR		M	R						6								14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1905	A-BLK	GC	PLR		M	R		2		4	5	6	7		10	11	12			14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1906	A-BLK	GC	PLR		M	R		2	3												15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1907	A-BLK	GC	PLR		M	R		2		4			7		10	11		13			15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1908	A-BLK	GC	PLR		M	R		2	3		5				10			13			15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1915	A-BLK	GC	PLR		M	R			3			6				11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1916	A-BLK	GC	PLR		M	R											12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1918	A-BLK	GC	PLR		M	R		2		4										15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1924	A-BLK	GC	PLR		M	R					5	6	7									SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1925	A-BLK	GC	PLR		M	R			3	4	5				10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1926	A-BLK	GC	PLR		M	R					5				10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1927	A-BLK	GC	PLR		M	R									10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1928	A-BLK	GC	PLR		M	R						6	7									SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1929	A-BLK	GC	PLR		M	R			3	4	5	6	7									SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1930	A-BLK	GC	PLR		M	R			3			6			10			13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1931	A-BLK	GC	PLR		M	R			3			6						13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-1932	B-LG	GC	PLR		M	R						6			10	11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1933	A-BLK	GC	PLR		M	R		2	3	4	5	6			10	11	12		14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1934	A-BLK	GC	PLR		M	R		2	3			6	7			11		13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1936	A-BLK	GC	PLR		M	R						6						13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1937	A-BLK	GC	PLR		M	R						6				11		13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1938	A-BLK	GC	PLR	CPA	M	R		2	3	4	5	6	7		10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1939	A-BLK	GC	PLR	CPA	M	R		2	3	4	5	6	7				12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1940	A-BLK	GC	PLR		M	R												13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1941	A-BLK	GC	PLR		M	R			3			6				11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1942	A-BLK	GC	PLR		M	R		2				6	7			11	12	13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1943	A-BLK	GC	PLR		M	R		2			5	6	7			11	12	13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1944	A-BLK	GC	PLR		M	R		2					7		10	11	12			15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1946	A-BLK	GC	PLR		M	R						6					12		14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1947	A-BLK	GC	PLR		M	R						6							14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-1949	B-LG	GC	PLR		M	R			3	4	5				10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-1950	B-LG	GC	PLR		M	R			3	4	5	6	7									SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-1951	B-LG	GC	PLR		M	R					5	6	7									SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-1952	B-LG	GC	PLR		M	R					5				10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1956	A-BLK	GC	PLR		M	R						6						13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1957	A-BLK	GC	PLR		M	R						6					12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1960	A-BLK	GC	PLR	CPA	M	R										11						SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1961	A-BLK	GC	PLR	CPA	M	R						6	7									SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1962	A-BLK	GC	PLR	CPA	M	R			3						10							SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1963	A-BLK	GC	PLR	CPA	M	R		2	3						10							SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1964	A-BLK	GC	PLR	CPA	M	R						6	7			11						SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1965	A-BLK	GC	PLR	CPA	M	R					5	6	7					13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1966	A-BLK	GC	PLR	CPA	M	R		2			5	6	7		10			13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1967	A-BLK	GC	PLR	CPA	M	R		2	3	4	5	6	7			11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1968	A-BLK	GC	PLR	CPA	M	R		2	3	4	5					11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1969	A-BLK	GC	PLR	CPA	M	R		2	3	4	5				10		12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1970	A-BLK	GC	PLR		M	R		2							10	11		13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1971	A-BLK	GC	PLR		M	R			3	4			7		10	11		13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1972	A-BLK	GC	PLR		M	R												13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1973	A-BLK	GC	PLR		M	R												12	13	14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1974	A-BLK	GC	PLR	CPA	M	R												12				SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1975	A-BLK	GC	PLR	CPA	M	R		2		4								12				SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1976	A-BLK	GC	PLR	CPA	M	R					5				10		12					SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1979	A-BLK	GC	PLR		M	R				3	4	6	7		10	11		13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1980	A-BLK	GC	PLR		M	R										11		13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1984	A-BLK	GC	PLR	CPA	M	R				4			7									SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-1985	B-LG	GC	PLR		M	R						6	7									SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-1986	B-LG	GC	PLR		M	R									10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-1988	A-BLK	GC	PLR		M	R						6						12	13	14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-1989	A-BLK	GC	PLR	CPA	M	R		2	3		5	6			10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY H, YELLOW, W/ SHRT BAR, W/CPA	34985-1991	H-YW	GC	PLR-SB	CPA	M	R		2	3			6	7		10	11	12	13	14	15		SALEABLE		NOT AVAILABLE</		

MX150 16 WAY HYBRID RECEPTACLE SEALED ASSEMBLY MAT SEAL (WITHOUT CLIPSLOT, 2.8mm CAVITIES OPEN)

BOM AND PIN OUT SHEET

ASSEMBLY DESCRIPTION	ASSEMBLY PART NUMBER	COMPONENT							BLOCKED TERMINALS																STATUS	COMMENTS	OPTIONAL ATTATCHMENTS SOLD SEPERATELY		
		THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT.							CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION																		BACKSHELL WITH RIBS	BACKSHELL WITHOUT RIBS	
		HOUSING KEY/COLOR	GROMMET CAP	PLR	CPA	MAT SEAL	RING SEAL	1	2	3	4	5	6	7	8	9	10	11	12	13	14	15	16						
KEY H, YELLOW, W/ SHRT BAR, W/CPA	34985-2012	H-YW	GC	PLR-SB	CPA	M	R		2	3			6	7			10	11			14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2014	A-BLK	GC	PLR		M	R							7			10	11						SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2015	A-BLK	GC	PLR	CPA	M	R				2						10	11	12	13	14			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2016	A-BLK	GC	PLR	CPA	M	R			2							10	11	12	13				SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2017	A-BLK	GC	PLR	CPA	M	R			2							10	11						SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2018	A-BLK	GC	PLR	CPA	M	R										10	11	12	13				SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2019	A-BLK	GC	PLR		M	R				3	4	5	6	7		10	11	12	13	14			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2020	A-BLK	GC	PLR		M	R					4	5	6	7		10	11	12	13	14			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2021	A-BLK	GC	PLR		M	R				3	4			7		10	11			14			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2022	A-BLK	GC	PLR		M	R				3	4			7		10	11	12	13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2023	A-BLK	GC	PLR		M	R		2	3	4	5	6				10	11	12	13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2024	A-BLK	GC	PLR		M	R				3	4		6	7		10	11	12	13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2025	A-BLK	GC	PLR		M	R				3						10	11			13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2026	A-BLK	GC	PLR		M	R		2			4		6			10			12	13			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2027	A-BLK	GC	PLR		M	R		2	3		4		6	7		10	11	12	13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2028	A-BLK	GC	PLR		M	R		2					6	7		10	11	12	13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2030	A-BLK	GC	PLR		M	R		2	3														SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2031	A-BLK	GC	PLR	CPA	M	R				3													SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2032	A-BLK	GC	PLR		M	R					4	5							13				SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2033	A-BLK	GC	PLR		M	R							6	7		10	11	12	13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2035	A-BLK	GC	PLR		M	R			2			5	6			10	11	12	13		15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2036	A-BLK	GC	PLR		M	R		2						7		10	11	12	13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2038	A-BLK	GC	PLR	CPA	M	R		2				5	6			10				14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2039	A-BLK	GC	PLR	CPA	M	R						5	6							14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2040	A-BLK	GC	PLR		M	R					4						11			13	14		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2041	A-BLK	GC	PLR		M	R		2			4	5				10			12		14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2042	A-BLK	GC	PLR		M	R						5									15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2043	A-BLK	GC	PLR		M	R				3	4								13			15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2044	A-BLK	GC	PLR		M	R					4									13	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2046	A-BLK	GC	PLR		M	R					4									13			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2047	A-BLK	GC	PLR		M	R		2				5		7		10	11	12	13				SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2048	A-BLK	GC	PLR		M	R					4	5								14			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2049	A-BLK	GC	PLR		M	R							6			10	11				14		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-2051	B-LG	GC	PLR		M	R						5	6	7		10	11	12	13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2052	A-BLK	GC	PLR		M	R			2		4						11			13	14		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2053	A-BLK	GC	PLR		M	R				3			6					11				15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2054	A-BLK	GC	PLR		M	R															15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2060	A-BLK	GC	PLR		M	R					4	5									14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2061	A-BLK	GC	PLR		M	R															14		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2062	A-BLK	GC	PLR	CPA	M	R				3	4	5	6	7		10	11	12	13	14			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2063	A-BLK	GC	PLR	CPA	M	R					4	5	6	7		10	11	12	13	14			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2067	A-BLK	GC	PLR		M	R			2								11				14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2068	A-BLK	GC	PLR		M	R					4	5							12				SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2069	A-BLK	GC	PLR		M	R					4	5							12			15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2073	A-BLK	GC	PLR		M	R				3							11				15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2074	A-BLK	GC	PLR	CPA	M	R				3	4	5	6			10	11			13			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2075	A-BLK	GC	PLR		M	R							6	7		10	11			14			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2076	A-BLK	GC	PLR		M	R			2				6				11			14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2077	A-BLK	GC	PLR		M	R		2			4								13		15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2078	A-BLK	GC	PLR		M	R				3	4	5		7							15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2079	A-BLK	GC	PLR		M	R				3						10	11			13	14	15	SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2080	A-BLK	GC	PLR	CPA	M	R			2		4	5				10			12	13			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2081	A-BLK	GC	PLR	CPA	M	R			2		4								12	13			SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2082	A-BLK	GC	PLR		M	R			2				6						12	13	14	15	SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2083	A-BLK	GC	PLR		M	R						5	6	7		10	11	12	13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2084	A-BLK	GC	PLR		M	R		2				5					11	12	13		15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2085	A-BLK	GC	PLR		M	R		2				5					11			13		15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2086	A-BLK	GC	PLR		M	R		2				5				10	11			13		15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2087	A-BLK	GC	PLR		M	R		2	3	4	5	6	7			10	11	12		14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2088	A-BLK	GC	PLR		M	R		2	3	4	5	6	7			10	11			13	14	15	SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-2089	A-BLK	GC	PLR	CPA	M	R		2	3		5		7			10	11	12	13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2090	A-BLK	GC	PLR		M	R		2	3	4		6	7			10	11	12	13		15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2091	A-BLK	GC	PLR		M	R		2	3	4			7			10	11	12	13	14	15		SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2092	A-BLK	GC	PLR		M	R				3			6				11				14	15	SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2093	A-BLK	GC	PLR		M	R					4	5							12		14	15	SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2094	A-BLK	GC	PLR		M	R				3			6	7			11				14	15	SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2095	A-BLK	GC	PLR		M	R							6	7						13	14	15	SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2096	A-BLK	GC	PLR		M	R															14	15	SALEABLE			NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-2097																												



MX150 16 WAY HYBRID RECEPTACLE SEALED ASSEMBLY MAT SEAL (WITHOUT CLIPSLOT, 2.8mm CAVITIES OPEN)
BOM AND PIN OUT SHEET

ASSEMBLY DESCRIPTION	ASSEMBLY PART NUMBER	COMPONENT						BLOCKED TERMINALS																STATUS	COMMENTS	OPTIONAL ATTATCHMENTS SOLD SEPERATELY	
		THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT.						CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION																		BACKSHELL WITH RIBS	BACKSHELL WITHOUT RIBS
		HOUSING KEY/COLOR	GROMMET CAP	PLR	CPA	MAT SEAL	RING SEAL	1	2	3	4	5	6	7	8	9	10	11	12	13	14	15	16				
KEY A, BLACK, W/O CPA	34985-2132	A-BLK	GC	PLR		M	R			3		5					10	11	12					SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2138	A-BLK	GC	PLR		M	R		2			5					10							SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2140	A-BLK	GC	PLR		M	R		2	3	4						10	11	12	13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2142	A-BLK	GC	PLR		M	R										10	11		13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2143	A-BLK	GC	PLR		M	R										10	11						SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2144	A-BLK	GC	PLR		CPA	M	R		2	3	4					10	11	12					SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-2145	B-LG	GC	PLR		M	R		2	3	4	5	6	7			10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2146	A-BLK	GC	PLR		CPA	M	R			3		6				10	11	12		14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2147	A-BLK	GC	PLR	CPA	M	R		2	3	4	5		7										SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2148	A-BLK	GC	PLR	CPA	M	R						6				10	11	12		14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2149	A-BLK	GC	PLR		M	R			3		5					10	11						SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2150	A-BLK	GC	PLR		CPA	M	R																OBSOLETE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2151	A-BLK	GC	PLR		M	R			3			6				10	11	12		14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2152	A-BLK	GC	PLR		M	R		2	3	4	5		7										SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2153	A-BLK	GC	PLR		M	R						6				10	11	12		14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2154	A-BLK	GC	PLR	CPA	M	R		2	3	4	5	6				10	11	12		14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2155	A-BLK	GC	PLR		M	R		2		4						10							SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2156	A-BLK	GC	PLR		M	R		2		4						10	11						SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY D, STONE GRAY, W/O CPA	34985-2157	D-SG	GC	PLR		M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2158	A-BLK	GC	PLR		M	R		2	3	4	5												SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2159	A-BLK	GC	PLR		M	R		2					7				11			14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY C, DARK GRAY, W/CPA	34985-2160	C-DG	GC	PLR	CPA	M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, YELLOW, W/CPA	34985-2161	A-YW	GC	PLR	CPA	M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2162	A-BLK	GC	PLR	CPA	M	R															15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-2163	B-LG	GC	PLR	CPA	M	R		2	3	4	5	6	7							14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-2164	B-LG	GC	PLR		M	R		2	3	4	5	6	7							14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2165	A-BLK	GC	PLR	CPA	M	R				4	5	6	7					12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2166	A-BLK	GC	PLR	CPA	M	R							7						13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2167	A-BLK	GC	PLR	CPA	M	R		2	3							10	11		13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2168	A-BLK	GC	PLR	CPA	M	R													13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-2169	B-LG	GC	PLR	CPA	M	R		2	3							10							SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY C, DARK GRAY, W/CPA	34985-2170	C-DG	GC	PLR	CPA	M	R			3	4		6	7			10	11		13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY C, DARK GRAY, W/O CPA	34985-2171	C-DG	GC	PLR		M	R			3	4		6	7			10	11		13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-2172	B-LG	GC	PLR		M	R			3							10							SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2173	A-BLK	GC	PLR	CPA	M	R						6	7					12					SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2174	A-BLK	GC	PLR	CPA	M	R		2		4	5		7					12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-2175	B-LG	GC	PLR	CPA	M	R													13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2176	A-BLK	GC	PLR	CPA	M	R							7					12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-2177	B-LG	GC	PLR	CPA	M	R			3							10	11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-2178	A-BLK	GC	PLR		M	R			3		5							12					SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-2179	B-LG	GC	PLR	CPA	M	R			3							10							SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-2180	B-LG	GC	PLR	CPA	M	R		2	3								11	12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-2181	B-LG	GC	PLR	CPA	M	R		2	3			6	7			10	11	12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-2182	B-LG	GC	PLR	CPA	M	R		2	3														SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-2183	A-BLK	GC	PLR	CPA	M	R		2																		



MX150 16 WAY HYBRID RECEPTACLE SEALED ASSEMBLY MAT SEAL (WITHOUT CLIPSLOT, 2.8mm CAVITIES OPEN)
BOM AND PIN OUT SHEET

ASSEMBLY DESCRIPTION	ASSEMBLY PART NUMBER	COMPONENT						BLOCKED TERMINALS																STATUS	COMMENTS	OPTIONAL ATTATCHMENTS SOLD SEPERATELY		
		THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT.						CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION																		BACKSHELL WITH RIBS	BACKSHELL WITHOUT RIBS	
		HOUSING KEY/COLOR	GROMMET CAP	PLR	CPA	MAT SEAL	RING SEAL	1	2	3	4	5	6	7	8	9	10	11	12	13	14	15	16					
KEY B, LIGHT GRAY, W/O CPA	34985-4028	B-LG	GC	PLR		M	R		2				5	6	7				11						SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4029	A-BLK	GC	PLR		M	R										10		12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4030	A-BLK	GC	PLR		M	R											11			14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-4031	A-BLK	GC	PLR	CPA	M	R														14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-4032	B-LG	GC	PLR		M	R			2			5	6	7									SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4033	A-BLK	GC	PLR		M	R			2		4	5	6							14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4034	A-BLK	GC	PLR		M	R			2	3	4	5								14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4035	A-BLK	GC	PLR		M	R			2	3							11			14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-4036	A-BLK	GC	PLR	CPA	M	R			2					7		10			13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4037	A-BLK	GC	PLR		M	R			2					7									SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4038	A-BLK	GC	PLR		M	R			2	3						10	11	12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4039	A-BLK	GC	PLR		M	R				3								12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4040	A-BLK	GC	PLR		M	R				3	4		6	7				12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-4041	A-BLK	GC	PLR	CPA	M	R								7		10	11	12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4042	A-BLK	GC	PLR		M	R								7							15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-4043	A-BLK	GC	PLR	CPA	M	R						6	7								15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-4044	A-BLK	GC	PLR	CPA	M	R						6	7			10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4045	A-BLK	GC	PLR		M	R			2								11	12					SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4046	A-BLK	GC	PLR		M	R			2							10	11	12					SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4047	A-BLK	GC	PLR		M	R			2							10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4048	A-BLK	GC	PLR		M	R			2	3			6	7		10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4049	A-BLK	GC	PLR		M	R												12		14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4050	A-BLK	GC	PLR		M	R			2	3									13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-4051	A-BLK	GC	PLR	CPA	M	R										10							SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4052	A-BLK	GC	PLR		M	R			2	3			6	7		10			13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4053	A-BLK	GC	PLR		M	R			2	3	4	5	6	7			11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4054	A-BLK	GC	PLR		M	R			2	3	4	5	6	7		10	11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4055	A-BLK	GC	PLR		M	R					4					10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/CPA	34985-4056	B-LG	GC	PLR	CPA	M	R			2	3								12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4057	A-BLK	GC	PLR		M	R			2							10	11						SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4058	A-BLK	GC	PLR		M	R			2							10	11			14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4059	A-BLK	GC	PLR		M	R			2	3						10	11	12	13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4060	A-BLK	GC	PLR		M	R				3						10	11	12	13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4061	A-BLK	GC	PLR		M	R			2	3						10					15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4062	A-BLK	GC	PLR		M	R				3						10					15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-4063	B-LG	GC	PLR		M	R			2										13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY B, LIGHT GRAY, W/O CPA	34985-4064	B-LG	GC	PLR		M	R			2							10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, YELLOW, W/CPA	34985-4065	A-YW	GC	PLR	CPA	M	R					4			7				12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4066	A-BLK	GC	PLR		M	R				3	4					10				14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/CPA	34985-4067	A-BLK	GC	PLR	CPA	M	R							6			10			12		14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4068	A-BLK	GC	PLR		M	R				3	4	5	6	7							15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4069	A-BLK	GC	PLR		M	R			2	3	4	5	6	7		10			12		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4070	A-BLK	GC	PLR		M	R			2		4		6	7		10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4071	A-BLK	GC	PLR		M	R			2	3		5				10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE	
KEY A, BLACK, W/O CPA	34985-4072	A-BLK	GC	PLR																								



MX150 16 WAY HYBRID RECEPTACLE SEALED ASSEMBLY MAT SEAL (WITHOUT CLIPSLOT, 2.8mm CAVITIES OPEN)
BOM AND PIN OUT SHEET

ASSEMBLY DESCRIPTION	ASSEMBLY PART NUMBER	COMPONENT						BLOCKED TERMINALS																STATUS	COMMENTS	OPTIONAL ATTATCHMENTS SOLD SEPERATELY	
		THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT.						CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION																		BACKSHELL WITH RIBS	BACKSHELL WITHOUT RIBS
		HOUSING KEY/COLOR	GROMMET CAP	PLR	CPA	MAT SEAL	RING SEAL	1	2	3	4	5	6	7	8	9	10	11	12	13	14	15	16				
KEY A, BLACK, W/O CPA	34985-4118	A-BLK	GC	PLR		M	R				4	5	6								14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4119	A-BLK	GC	PLR		M	R					5	6								14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4120	A-BLK	GC	PLR		M	R				4	5	6									15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4121	B-LG	GC	PLR		M	R					5	6	7					12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4122	B-LG	GC	PLR		M	R						6	7								15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4123	B-LG	GC	PLR		M	R				4	5						11	12	13		15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4124	B-LG	GC	PLR		M	R						6	7			10	11			14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4125	B-LG	GC	PLR		M	R					5	6	7			10	11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4126	B-LG	GC	PLR		M	R					5	6	7				11	12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4127	B-LG	GC	PLR		M	R					5	6								14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4128	B-LG	GC	PLR		M	R		2		4	5	6	7			10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4129	B-LG	GC	PLR		M	R				4	5	6	7				11				14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4130	B-LG	GC	PLR		M	R		2		4	5	6									14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4131	B-LG	GC	PLR		M	R					5	6	7				11				14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4132	B-LG	GC	PLR		M	R		2		4	5	6	7			10	11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4133	B-LG	GC	PLR		M	R					5	6				10			13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4134	B-LG	GC	PLR		M	R							7				11				14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4135	B-LG	GC	PLR		M	R															14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4136	B-LG	GC	PLR		M	R							7			10	11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4137	B-LG	GC	PLR		M	R				4											14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4138	B-LG	GC	PLR		M	R				4			7				11				14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4139	B-LG	GC	PLR		M	R				4			7			10	11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4140	B-LG	GC	PLR		M	R										10	11	12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4141	B-LG	GC	PLR		M	R															15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-4142	A-BLK	GC	PLR	CPA	M	R		2		4			7			10		12			15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4143	A-BLK	GC	PLR		M	R				4	5		7					12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4144	A-BLK	GC	PLR		M	R					3	5	6			10			13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4145	A-BLK	GC	PLR		M	R						3				10				13	14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4146	A-BLK	GC	PLR		M	R		2			5	6									14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4147	A-BLK	GC	PLR		M	R				3	4	5	6	7			10	11					SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4148	A-BLK	GC	PLR		M	R		2				6				10	11	12					SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4149	A-BLK	GC	PLR		M	R					4	6	7			10							SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4150	A-BLK	GC	PLR		M	R				3	4		6	7				11	12		14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4151	A-BLK	GC	PLR		M	R		2			4	5	6			10	11				14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4152	A-BLK	GC	PLR		M	R		2			4	5	6								14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4153	A-BLK	GC	PLR		M	R		2			4										14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4154	A-BLK	GC	PLR		M	R					4	5	6			10	11				14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4155	A-BLK	GC	PLR		M	R					4										14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-4156	A-BLK	GC	PLR	CPA	M	R										10	11	12		13	14	15	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/CPA	34985-4157	A-BLK	GC	PLR	CPA	M	R																	SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-4158	B-LG	GC	PLR	CPA	M	R		2				6	7			10	11	12	13	14	15		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/CPA	34985-4159	B-LG	GC	PLR	CPA	M	R						6				10	11	12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY B, LIGHT GRAY, W/O CPA	34985-4160	B-LG	GC	PLR		M	R											11	12	13				SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4161	A-BLK	GC	PLR		M	R										10					14		SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4162	A-BLK	GC	PLR		M	R							7			10	11	12	13	14			SALEABLE		NOT AVAILABLE	NOT AVAILABLE
KEY A, BLACK, W/O CPA	34985-4163	A-BLK	GC	PLR		M	R		2																		

MX150 16 WAY HYBRID RECEPTACLE SEALED ASSEMBLY MAT SEAL (WITH CLIPSLOT, 2.8mm CAVITIES OPEN)
BOM AND PIN OUT SHEET

FOR ADDITIONAL INFORMATION SEE SD-34985-8001

ABBREVIATION	DESCRIPTION	COLOR	MATERIAL
A-BLK-CLIP	HOUSING, KEYING OPTION A WITH CLIPSLOT	BLACK	SPS/NYLON GF20
B-LG-CLIP	HOUSING, KEYING OPTION B WITH CLIPSLOT	LIGHT GRAY	SPS/NYLON GF20
C-DG-CLIP	HOUSING, KEYING OPTION C WITH CLIPSLOT	DARK GRAY	SPS/NYLON GF20
D-SG-CLIP	HOUSING, KEYING OPTION D WITH CLIPSLOT	STONE GRAY	SPS/NYLON GF20
A-YW-CLIP	HOUSING, KEYING OPTION A WITH CLIPSLOT	YELLOW	SPS/NYLON GF20
E-BLK-CLIP	HOUSING, KEYING OPTION E WITH CLIPSLOT	BLACK	SPS/NYLON GF20
F-LG-CLIP	HOUSING, KEYING OPTION F WITH CLIPSLOT	LIGHT GRAY	SPS/NYLON GF20
G-DG-CLIP	HOUSING, KEYING OPTION G WITH CLIPSLOT	DARK GRAY	SPS/NYLON GF20
H-YW-CLIP	HOUSING, KEYING OPTION H WITH CLIPSLOT	YELLOW	SPS/NYLON GF20
GC	GROMMET CAP	BLACK	SPS/NYLON GF20
PLR	STANDARD PLR	NATURAL	SPS/NYLON GF20
PLR-SB	SHORTING BAR PLR	NATURAL	PBT GF15
CPA	CPA	RED	PBT GF30
M	MAT SEAL	ROYAL BLUE	INHERENTLY LUBRICATED SILICONE
R	RING SEAL	GREEN	INHERENTLY LUBRICATED SILICONE

ASSEMBLY DESCRIPTION	ASSEMBLY PART NUMBER	COMPONENT						BLOCKED TERMINALS																STATUS	COMMENTS	OPTIONAL ATTACHMENTS SOLD SEPERATELY	
		THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT.						CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION																		BACKSHELL WITH RIBS	BACKSHELL WITHOUT RIBS
		HOUSING KEY/COLOR	GROMMET CAP	PLR	CPA	MAT SEAL	RING SEAL	1	2	3	4	5	6	7	8	9	10	11	12	13	14	15	16				
KEY E, BLACK, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1713	E-BLK-CLIP	GC	PLR-SB		M	R																	SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1841	A-BLK-CLIP	GC	PLR		M	R																	SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/CPA	34985-1848	A-BLK-CLIP	GC	PLR	CPA	M	R		2															SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/CPA	34985-1849	A-BLK-CLIP	GC	PLR	CPA	M	R																	SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1850	A-BLK-CLIP	GC	PLR		M	R		2					7							14			SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1851	F-LG-CLIP	GC	PLR-SB		M	R		2	3			6	7						13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1852	F-LG-CLIP	GC	PLR-SB		M	R						6											SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1853	F-LG-CLIP	GC	PLR-SB		M	R		2	3			6							13				SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1854	F-LG-CLIP	GC	PLR-SB		M	R						6							13				SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1855	F-LG-CLIP	GC	PLR-SB		M	R		2				6				10	11	12					SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1856	F-LG-CLIP	GC	PLR-SB		M	R						6						12					SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1857	F-LG-CLIP	GC	PLR-SB		M	R						6					11	12					SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1858	F-LG-CLIP	GC	PLR-SB		M	R		2	3			6				10							SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1859	F-LG-CLIP	GC	PLR-SB		M	R						6				10							SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1860	F-LG-CLIP	GC	PLR-SB		M	R		2	3	4	5	6				10							SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1861	A-BLK-CLIP	GC	PLR		M	R		2	3	4							11	12		14			SALEABLE		349521611	NOT AVAILABLE
KEY E, BLACK, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1862	E-BLK-CLIP	GC	PLR-SB		M	R		2													15		SALEABLE		349521611	NOT AVAILABLE
KEY E, BLACK, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1875	E-BLK-CLIP	GC	PLR-SB		M	R										10	11			14			SALEABLE		349521611	NOT AVAILABLE
KEY E, BLACK, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1876	E-BLK-CLIP	GC	PLR-SB		M	R						6	7			10	11			14			SALEABLE		349521611	NOT AVAILABLE
KEY E, BLACK, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1877	E-BLK-CLIP	GC	PLR-SB		M	R														14	15		SALEABLE		349521611	NOT AVAILABLE
KEY E, BLACK, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1878	E-BLK-CLIP	GC	PLR-SB		M	R														14			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1881	A-BLK-CLIP	GC	PLR		M	R						6	7						13				SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1891	A-BLK-CLIP	GC	PLR		M	R		2	3			6											SALEABLE		349521611	NOT AVAILABLE
KEY E, BLACK, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1892	E-BLK-CLIP	GC	PLR-SB		M	R		2	3											14	15		SALEABLE		349521611	NOT AVAILABLE
KEY E, BLACK, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1893	E-BLK-CLIP	GC	PLR-SB		M	R										10	11			14	15		SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1894	F-LG-CLIP	GC	PLR-SB		M	R												12	13	14			SALEABLE		349521611	NOT AVAILABLE
KEY H, YELLOW, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1895	H-YW-CLIP	GC	PLR-SB		M	R																	SALEABLE		349521611	NOT AVAILABLE
KEY H, YELLOW, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1896	H-YW-CLIP	GC	PLR-SB		M	R														14			SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1897	F-LG-CLIP	GC	PLR-SB		M	R						6	7			10	11	12	13	14			SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1898	F-LG-CLIP	GC	PLR-SB		M	R						6				10	11	12	13	14			SALEABLE		349521611	NOT AVAILABLE
KEY H, YELLOW, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1899	H-YW-CLIP	GC	PLR-SB		M	R						6	7			10	11			14			SALEABLE		349521611	NOT AVAILABLE
KEY H, YELLOW, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-1900	H-YW-CLIP	GC	PLR-SB		M	R						6				10	11			14			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1909	A-BLK-CLIP	GC	PLR		M	R			2	3							11	12		14			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1910	A-BLK-CLIP	GC	PLR		M	R		2					7				11	12					SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1911	A-BLK-CLIP	GC	PLR		M	R		2									11						SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1912	A-BLK-CLIP	GC	PLR		M	R		2	3							10	11			14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1913	A-BLK-CLIP	GC	PLR		M	R		2	3				7			10	11	12		14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1914	A-BLK-CLIP	GC	PLR		M	R			3							10							SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1917	A-BLK-CLIP	GC	PLR		M	R		2					7						13		15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1919	A-BLK-CLIP	GC	PLR		M	R						6											SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1920	A-BLK-CLIP	GC	PLR		M	R					5	6					11				15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1921	A-BLK-CLIP	GC	PLR		M	R											11	12	13				SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1922	A-BLK-CLIP	GC	PLR		M	R		2										12		13			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1923	A-BLK-CLIP	GC	PLR		M	R			3	4		6	7			10	11	12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1935	A-BLK-CLIP	GC	PLR		M	R		2					7						13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1945	A-BLK-CLIP	GC	PLR		M	R			3							10	11						SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1948	A-BLK-CLIP	GC	PLR		M	R		2					7							14			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1953	A-BLK-CLIP	GC	PLR		M	R		2				6				10	11	12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1954	A-BLK-CLIP	GC	PLR		M	R				3	4		7							14			SALEABLE		349521611	NOT AVAILABLE
KEY H, YELLOW, W/ CLIPSLOT, W/ SHRT BAR, W/CPA	34985-1955	H-YW-CLIP	GC	PLR-SB	CPA	M	R																	SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1958	A-BLK-CLIP	GC	PLR		M	R		2					6					12					SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1959	A-BLK-CLIP	GC	PLR		M	R					5	6							13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1977	A-BLK-CLIP	GC	PLR		M	R				3						10	11		13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-1978	A-BLK-CLIP	GC	PLR		M	R				3						10			13	14	15		SALEABLE		349521611</	



MX150 16 WAY HYBRID RECEPTACLE SEALED ASSEMBLY MAT SEAL (WITH CLIPSLOT, 2.8mm CAVITIES OPEN)
BOM AND PIN OUT SHEET

ASSEMBLY DESCRIPTION	ASSEMBLY PART NUMBER	COMPONENT						BLOCKED TERMINALS																STATUS	COMMENTS	OPTIONAL ATTACHMENTS SOLD SEPERATELY			
		THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT.						CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION																		BACKSHELL WITH RIBS	BACKSHELL WITHOUT RIBS		
		HOUSING KEY/COLOR	GROMMET CAP	PLR	CPA	MAT SEAL	RING SEAL	1	2	3	4	5	6	7	8	9	10	11	12	13	14	15	16						
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2050	A-BLK-CLIP	GC	PLR		M	R													12	13	14	15		SALEABLE		349521611	NOT AVAILABLE	
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2055	A-BLK-CLIP	GC	PLR		M	R				3	4		6					10	11	12	13		15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2056	A-BLK-CLIP	GC	PLR		M	R					3	4	6	7				10	11	12	13		15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2057	A-BLK-CLIP	GC	PLR		M	R												10	11			14			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2058	A-BLK-CLIP	GC	PLR		M	R							6	7				10	11	12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2059	A-BLK-CLIP	GC	PLR		M	R			2					7					11	12	13				SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2064	A-BLK-CLIP	GC	PLR		M	R							6	7						12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2065	A-BLK-CLIP	GC	PLR		M	R			2				6	7						12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2066	A-BLK-CLIP	GC	PLR		M	R					3	4	5	7				10	11		13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2070	A-BLK-CLIP	GC	PLR		M	R								7				10	11	12		14			SALEABLE		349521611	NOT AVAILABLE
KEY B, LIGHT GRAY, W/ CLIPSLOT, W/O CPA	34985-2071	B-LG-CLIP	GC	PLR		M	R																			SALEABLE		349521611	NOT AVAILABLE
KEY B, LIGHT GRAY, W/ CLIPSLOT, W/O CPA	34985-2072	B-LG-CLIP	GC	PLR		M	R			2	3	4	5	6	7				10	11	12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY B, LIGHT GRAY, W/ CLIPSLOT, W/O CPA	34985-2103	B-LG-CLIP	GC	PLR		M	R						4													SALEABLE		349521611	NOT AVAILABLE
KEY B, LIGHT GRAY, W/ CLIPSLOT, W/O CPA	34985-2104	B-LG-CLIP	GC	PLR		M	R					4										13				SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2105	A-BLK-CLIP	GC	PLR		M	R			2			5	6							12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2108	A-BLK-CLIP	GC	PLR		M	R			2	3	4			7				10	11	12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2109	A-BLK-CLIP	GC	PLR		M	R			2											12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2114	A-BLK-CLIP	GC	PLR		M	R					3	4	5	7				10	11	12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2122	A-BLK-CLIP	GC	PLR		M	R					4										14	15			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2123	A-BLK-CLIP	GC	PLR		M	R			2	3		5	6					10	11	12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2124	A-BLK-CLIP	GC	PLR		M	R					4							10				14	15		SALEABLE		349521611	NOT AVAILABLE
KEY H, YELLOW, W/ CLIPSLOT, W/CPA	34985-2127	H-YW-CLIP	GC	PLR	CPA	M	R			2	3												15			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2128	A-BLK-CLIP	GC	PLR		M	R			2	3		5	6						11			14	15		SALEABLE		349521611	NOT AVAILABLE
KEY H, YELLOW, W/ CLIPSLOT, W/ SHRT BAR, W/CPA	34985-2129	H-YW-CLIP	GC	PLR-SB	CPA	M	R			2													15			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2130	A-BLK-CLIP	GC	PLR		M	R			2				6	7				10	11	12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, YELLOW, W/ CLIPSLOT, W/O CPA	34985-2133	A-YW-CLIP	GC	PLR		M	R			2													15			SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2134	F-LG-CLIP	GC	PLR-SB		M	R					4	5	6	7				10	11	12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2135	F-LG-CLIP	GC	PLR-SB		M	R			2	3			6	7							14	15			SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2136	F-LG-CLIP	GC	PLR-SB		M	R							6	7							14	15			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2137	A-BLK-CLIP	GC	PLR		M	R			2	3		5	6						11				15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2139	A-BLK-CLIP	GC	PLR		M	R			2	3	4	5	6	7				10	11	12	13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY B, LIGHT GRAY, W/ CLIPSLOT, W/O CPA	34985-2141	B-LG-CLIP	GC	PLR		M	R					4		6								13				SALEABLE		349521611	NOT AVAILABLE
KEY E, BLACK, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2201	E-BLK-CLIP	GC	PLR-SB		M	R																			SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2202	F-LG-CLIP	GC	PLR-SB		M	R			2	3			6	7							13	14	15		SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2203	F-LG-CLIP	GC	PLR-SB		M	R							6												SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2204	F-LG-CLIP	GC	PLR-SB		M	R			2	3			6								13				SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2205	F-LG-CLIP	GC	PLR-SB		M	R							6							12					SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2206	F-LG-CLIP	GC	PLR-SB		M	R			2				6					10	11	12					SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2207	F-LG-CLIP	GC	PLR-SB		M	R							6															



MX150 16 WAY HYBRID RECEPTACLE SEALED ASSEMBLY MAT SEAL (WITH CLIPSLOT, 2.8mm CAVITIES OPEN)
BOM AND PIN OUT SHEET

ASSEMBLY DESCRIPTION	ASSEMBLY PART NUMBER	COMPONENT						BLOCKED TERMINALS																STATUS	COMMENTS	OPTIONAL ATTACHMENTS SOLD SEPERATELY		
		THE PRESENCE OF AN ABBREVIATION INDICATES THE PRESENCE OF THAT COMPONENT.						CAVITY WITH A NUMBER INDICATES BLOCKED TERMINAL POSITION CAVITY WITHOUT A NUMBER INDICATES OPEN TERMINAL POSITION																		BACKSHELL WITH RIBS	BACKSHELL WITHOUT RIBS	
		HOUSING KEY/COLOR	GROMMET CAP	PLR	CPA	MAT SEAL	RING SEAL	1	2	3	4	5	6	7	8	9	10	11	12	13	14	15	16					
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2264	A-BLK-CLIP	GC	PLR		M	R			2				6					11						SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2265	A-BLK-CLIP	GC	PLR		M	R			2									11		13				SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2266	A-BLK-CLIP	GC	PLR		M	R			2							10	11	12	13					SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2267	A-BLK-CLIP	GC	PLR		M	R			2	3	4	5					11		13					SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2268	A-BLK-CLIP	GC	PLR		M	R				3				7		10	11					15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2269	A-BLK-CLIP	GC	PLR		M	R								7				12	13	14	15			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2270	A-BLK-CLIP	GC	PLR		M	R								7							15			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2271	A-BLK-CLIP	GC	PLR		M	R										10		12	13					SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2272	A-BLK-CLIP	GC	PLR		M	R								7		10	11	12	13					SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2273	A-BLK-CLIP	GC	PLR		M	R			2	3				7			11	12						SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2274	A-BLK-CLIP	GC	PLR		M	R			2	3										14				SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2275	F-LG-CLIP	GC	PLR-SB		M	R										10	11					15		SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2276	F-LG-CLIP	GC	PLR-SB		M	R							6	7		10	11					15		SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2277	F-LG-CLIP	GC	PLR-SB		M	R							6	7		10	11				14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2278	A-BLK-CLIP	GC	PLR		M	R											11		13	14	15			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2279	A-BLK-CLIP	GC	PLR		M	R										10	11	12	13					SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2280	A-BLK-CLIP	GC	PLR		M	R			2			5	6	7		10	11							SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2283	A-BLK-CLIP	GC	PLR		M	R							6				11					15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2284	A-BLK-CLIP	GC	PLR		M	R				3			6	7		10	11					15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2285	A-BLK-CLIP	GC	PLR		M	R								7		10	11							SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2286	A-BLK-CLIP	GC	PLR		M	R						5	6	7		10	11					15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2287	A-BLK-CLIP	GC	PLR		M	R			2															SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2288	A-BLK-CLIP	GC	PLR		M	R			2							10	11			13				SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2289	A-BLK-CLIP	GC	PLR		M	R			2	3	4	5	6											SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2290	A-BLK-CLIP	GC	PLR		M	R				3	4	5	6			10	11	12	13					SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2291	A-BLK-CLIP	GC	PLR		M	R				3		5				10								SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2292	A-BLK-CLIP	GC	PLR		M	R			2	3						10	11	12	13					SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2293	A-BLK-CLIP	GC	PLR		M	R				3	4	5				10	11	12	13	14	15			SALEABLE		349521611	NOT AVAILABLE
KEY A, YELLOW, W/ CLIPSLOT, W/CPA	34985-2294	A-YW-CLIP	GC	PLR	CPA	M	R			2									12				15		SALEABLE		349521611	NOT AVAILABLE
KEY A, YELLOW, W/ CLIPSLOT, W/CPA	34985-2295	A-YW-CLIP	GC	PLR	CPA	M	R			2	3												15		SALEABLE		349521611	NOT AVAILABLE
KEY A, YELLOW, W/ CLIPSLOT, W/CPA	34985-2300	A-YW-CLIP	GC	PLR	CPA	M	R			2												14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2301	A-BLK-CLIP	GC	PLR		M	R			2		4		6			10		12	13					SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2302	A-BLK-CLIP	GC	PLR		M	R				3			6	7								15		SALEABLE		349521611	NOT AVAILABLE
KEY B, LIGHT GRAY, W/ CLIPSLOT, W/CPA	34985-2303	B-LG-CLIP	GC	PLR	CPA	M	R			2	3											14	15		SALEABLE		349521611	NOT AVAILABLE
KEY B, LIGHT GRAY, W/ CLIPSLOT, W/CPA	34985-2304	B-LG-CLIP	GC	PLR	CPA	M	R			2	3							11	12	13	14	15			SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2305	A-BLK-CLIP	GC	PLR		M	R					3			7		10	11	12	13	14	15			SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2306	F-LG-CLIP	GC	PLR-SB		M	R							6	7		10					14	15		SALEABLE		349521611	NOT AVAILABLE
KEY F, LIGHT GRAY, W/ CLIPSLOT, W/ SHRT BAR, W/O CPA	34985-2307	F-LG-CLIP	GC	PLR-SB		M	R				2	3		6	7		10					14	15		SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2308	A-BLK-CLIP	GC	PLR		M	R								7										SALEABLE		349521611	NOT AVAILABLE
KEY A, BLACK, W/ CLIPSLOT, W/O CPA	34985-2309	A-BLK-CLIP	GC	PLR		M	R			2												14			SALEABLE		349521611	NOT AVAILABLE
KEY H, YELLOW, W/ CLIPSLOT, W/ SHRT BAR, W/CPA																												

CO-000024580
DATE:4/25/2025
DOCUMENT NO.: SD-34985-8002
REVISION: W22
PAGE: 10 OF 10