

Han-Fast Lock 10mm² m.Pin Ag Ro 2300St.

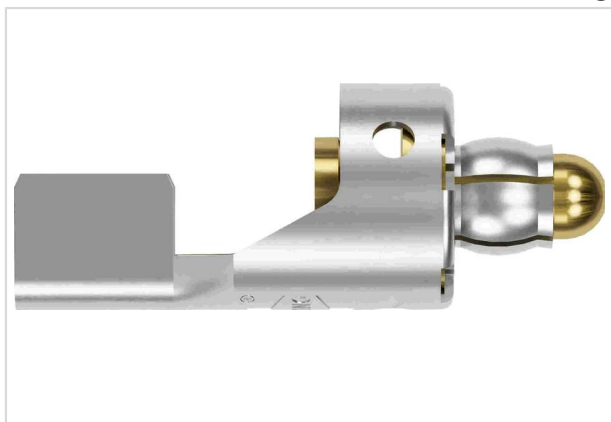


Image is for illustration purposes only. Please refer to product description.

Part number	09 08 000 6124
Specification	Han-Fast Lock 10mm ² m.Pin Ag Ro 2300St.
HARTING eCatalogue	https://harting.com/09080006124

Identification

Category	Contacts
Series	Han-Fast [®] Lock
Type of contact	PCB contact
Description of the contact	With pin

Version

Pack contents	2300 pieces on reel
---------------	---------------------

Technical characteristics

Conductor cross-section	10 mm ²
Rated current	≤60 A
Contact resistance	≤2 mΩ
Stripping length	7.5 mm

Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
Material (locking)	Copper alloy
Surface (locking)	Passivated
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50



Pushing Performance
Since 1945

Material properties

REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	b51e5b97-eeb5-438b-8538-f1771d43c17d
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076 CSA-C22.2 No. 182.3 ECBT8.E235076
----------	--

Commercial data

Packaging size	1
Net weight	9,080 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140014831
eCl@ss	27460201 PCB connector (board connector)
ETIM	EC002637
UNSPSC 24.0	39121415