


**10212020**

1/2in x 5/16in - Chain sprockets ISO

**2D Technical Drawing**

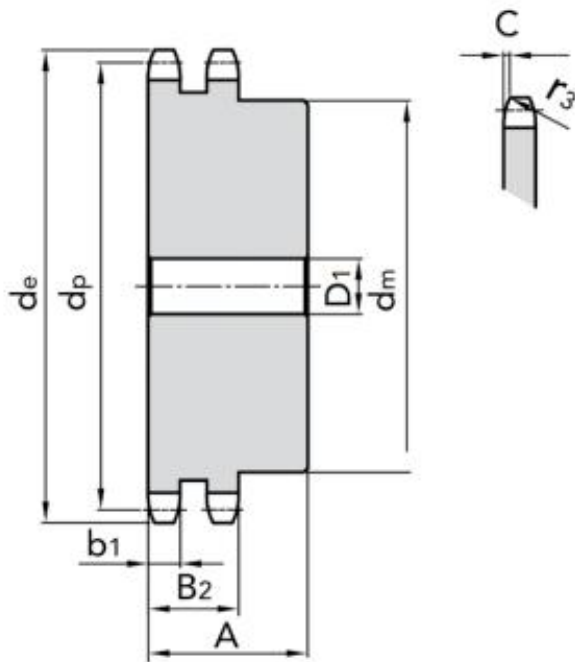

**Dynamic 3D View**

### Technical Specifications

|                                  |            |
|----------------------------------|------------|
| Number of teeth (T)              | 20         |
| de (DE) mm                       | 85.67      |
| dp (DP) mm                       | 81.19      |
| Part number (CODE)               | 10212020   |
| dm (DM) mm                       | 66         |
| D1 (D1) mm                       | 14         |
| A (A) mm                         | 35         |
| Tooth radius r3 (R3) mm          | 13         |
| Radius width C (C) mm            | 1.3        |
| Sprockets tooth width b1 (B1) mm | 7          |
| Sprockets tooth width B2 (B2) mm | 21         |
| Weight (WEIGHT) kg               | 1.1        |
| Material (MAT)                   | STEEL C 45 |