


Part Number: 1905X35X

| Type | Size | Rating | Description |
|------|------|--------|--------------------------------|
| LED | M8 | 24VDC | Recessed Bezel Panel Indicator |

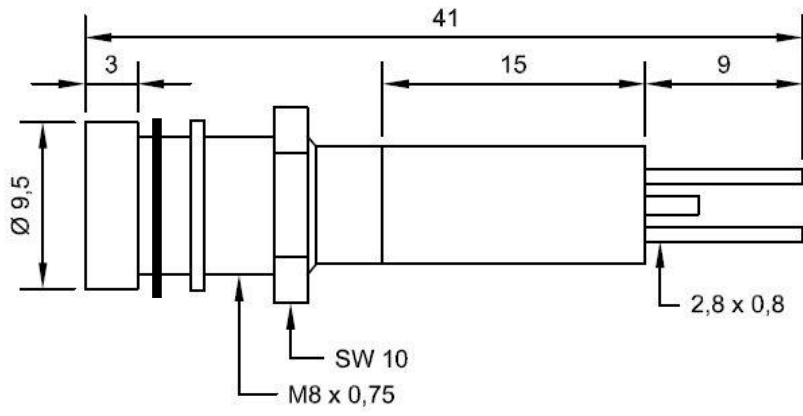

| Part # | Colour | Voltage(V) | Current(mA) | Intensity(mcd) |
|----------|--------|------------|-------------|----------------|
| 1905X353 | Red | 24Vdc | 20 | 80 |
| 1905X351 | Green | 24Vdc | 20 | 32 |
| 1905X352 | Yellow | 24Vdc | 20 | 32 |
| 1905X357 | Blue | 24Vdc | 20 | 60 |

Notes:

- 1 X = Chrome Bezel finish. 0 = Satin, 1 = Black, 2 = Matt
- 2 Electrical & optical data are measured at an ambient temperature of 25°C
- 3 Luminous intensity at DC
- 4 Storage temperature -25 °C to +80°C
- 5 Application temperature -20 °C to +60°C
- 6 Voltage tolerance ±10%
- 7 Due to component tolerances, colour temperature variations may be observed
- 8 The terminals are not qualified for soldering
- 9 Degree of protection IP67 when used with the supplied gasket
- 10 The plastic(polycarbonate) has limited chemical resistance
- 11 RoHS & REACH SVHC compliant