


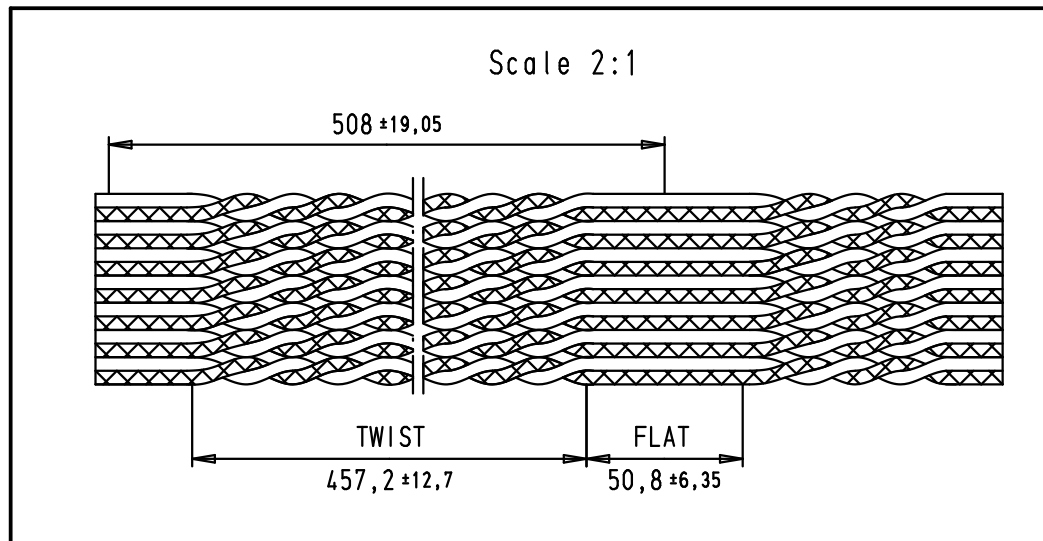

- Wire ————— Cu tinned
- Gauge ————— AWG 28/7
- Voltage rating ————— 300 Vr.m.s
- Conductor resistance ————— 221 mΩ/m
- Capacity unbalanced ————— 49 pF/m
- Impedance unbalanced ————— 105 Ω
- Signal delay ————— 5,2 ns/m
- Insulation material ————— PVC
- Temperature rating ————— -20°C to +105°C
- Flammability rating ————— UL: VW1
- Insulation resistance ————— 1000 MΩ/km



Colour code sequence (in 10 steps):  
brown, red, orange, yellow, green,  
blue, violet, grey, white, black

				Dot.	Name	 All Dim. in mm Orig. Size DIN A 4	SEK 18 Flat cable 14 poles, twisted pair, length per reel: 30,48 m colour coded, UL 20130, IEC 918	Maßstab/ Scale
			Detail.	25/10/05	JMDR			10:1
			Insp.					
			Stand.					
	33990	15/05/07	PK	HARTING EURL F-95972 Paris			 TB 09 18 014 7006	Blatt/ Page
	33247	25/10/05	JMDR					1 / 1
	Mod.	Dot.	Name				Sub.	