


## Technical data sheet

Article number:  
156-01153

**T50ROSEC4B**

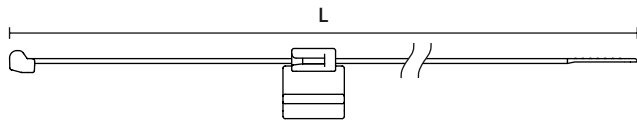

|                                      |                                                                                                                        |
|--------------------------------------|------------------------------------------------------------------------------------------------------------------------|
| <b>Product Group</b>                 | 2-piece fixing ties for edges                                                                                          |
| <b>Product Family</b>                | EdgeClip-Series, 1.0 - 3.0 mm, top fixing                                                                              |
| <b>Material</b>                      | Polyamide 6.6, UV-resistant (PA66W)                                                                                    |
| <b>Colour</b>                        | Black (BK)                                                                                                             |
| <b>Application Tool</b>              | ProCut 9 no battery, MK3PNSP2, EVOcut, MK7P, MK10-SB, MK20, EVO7, EVO7SP, EVO7i, EVO7iSP, EVO9, EVO9SP, EVO9i, EVO9iSP |
| <b>Bundle Ø max.</b>                 | 45.0 mm                                                                                                                |
| <b>Bundle Ø min.</b>                 | 4.0 mm                                                                                                                 |
| <b>Fixation Method</b>               | EdgeClip, top, assembled, 2 piece                                                                                      |
| <b>Flammability</b>                  | UL 94 V2                                                                                                               |
| <b>Height (H)</b>                    | 1.3 mm                                                                                                                 |
| <b>Length (L)</b>                    | 200.0 mm                                                                                                               |
| <b>Length (L2)</b>                   | 14.0 mm                                                                                                                |
| <b>Min.Tensile Strength</b>          | 225 N                                                                                                                  |
| <b>Operating Temperature</b>         | -40 °C to +85 °C, (+105 °C, 500 h)                                                                                     |
| <b>Package Content packed in</b>     | bag                                                                                                                    |
| <b>Pack Cont.</b>                    | 100 pcs.                                                                                                               |
| <b>Panel Thickness</b>               | 3.0 mm                                                                                                                 |
| <b>Panel Thickness min. (metric)</b> | 1.0 mm                                                                                                                 |
| <b>ROHS compliant</b>                | Yes                                                                                                                    |
| <b>Thickness (T)</b>                 | 1.2 mm                                                                                                                 |
| <b>Variant</b>                       | Outside Serrated                                                                                                       |
| <b>Width (W)</b>                     | 4.6 mm                                                                                                                 |

