



LED Traffic Light with integrated siren (2 tier)



Integrated siren with high sound output up to 80 dB

- High visibility LED Traffic Light with integrated siren
- Unmistakable signalling even in direct sunlight thanks to clear lenses
- Sound output up to 80 dB
- Simple mounting thanks to integrated mounting bracket
- The optical signal also offers very good sideways visibility

i TECHNICAL SPECIFICATIONS:


Dimensions (D x W x H):	1 tier: 136 mm x 85 mm x 226 mm 2 tier: 136 mm x 85 mm x 311 mm 3 tier: 136 mm x 85 mm x 396 mm
Housing:	PC/ABS, grey
Lens:	PC, transparent
Fixing:	Wall mounting
Installation position:	Vertical
Connection:	Screwable connection with wire protection max. 1.5 mm ²
Cable entry:	Cable diameter max. 13 mm
Duty cycle:	100 % ED
Tone type:	Continuous tone
Tone frequency:	50 Hz
Sound output:	> 80 dB

Life duration up to 50,000 hrs


ORDER SPECIFICATIONS:

Voltage	24 V \equiv	115 bis 230 V \sim
Current Consumption LED	80 mA (red/yellow) 160 mA (green)	35 mA
Siren	35 mA	35 mA
red / green	494 160 55	494 160 68
red / yellow / green	494 180 55	494 180 68

Available from 3rd Quarter 2008

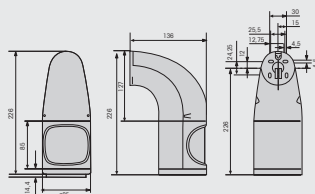

Connection diagram

 

Clear lenses ensure signalling effect even in direct sunlight

In preparation

2 tier, with fixing bow 3 tier, with fixing bow

CE C UL US

380 g 410 g

IP 65

+50°C -30°C

> 80 dB