



ENGLISH

## Datasheet

# RS Chrome Ceiling & In Wall Speaker 6W

RS Stock 406-0876




## Description


These ceiling speakers are designed to be as discreet as possible. Measuring only 10cm in diameter, they are easily hidden amongst ceiling down-lighters. Easy to fit, push the springs into the hole and the speaker snaps into place.

Model No:	SPL6/T
Power Handling	6w
Rated Input	100v
Transformer tapings	6,3,1.5w
SPL (1w/1m)	85dB
Max. SPL (rated/1m)	92dB
Frequency Response	120Hz-20kHz
Dimensions (dia x depth)	100 x 95.5mm
Cutout size (Ø mm)	92mm
Material	ABS plastic with metal grille
Weight (inc. packaging)	0.7kg
Colour	Gold (suffix 'G'), Chrome (suffix 'C') Black (suffix 'B'), White (suffix 'W')


## Dimensions: (mm)

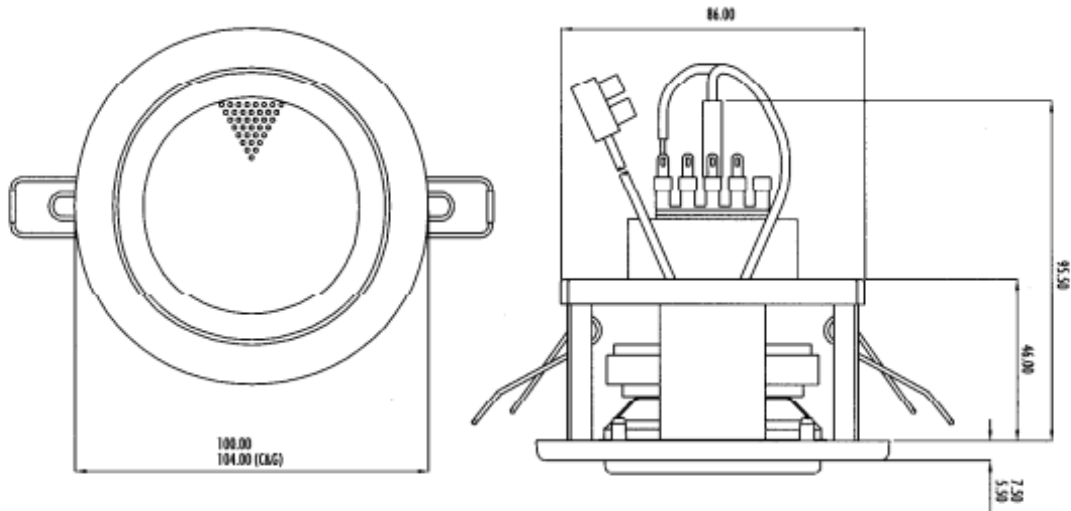


## Installation Guide

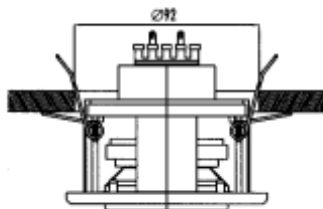

Step 1. Cut a hole 92mm diameter in the ceiling, then place the springs on the sides of the speaker into the hole.

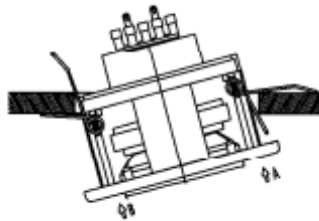

Step 2. Push up of A.

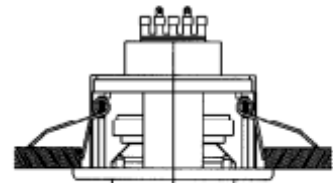

Step 3. Push up of B to complete the installation.