

Rex - digital time switches

MicroRex Plus 2



6 037 70

According to EN 60730-1 and EN 60730-2-7

Digital weekly DIN rail mounting time switch

1 program consists of 1 ON and 1 OFF time and the allocation of any day of the week or a combination of days and the selected channel (2 channel version)

Example:

- | | | |
|---------------------|------------------|-------|
| 1. prog.: ON 07:00h | OFF 08:15h Mo-Fr | CH1 |
| 2. prog.: ON 16:00h | OFF 20:15h Mo-SU | CH2 |
| 3. prog.: ON 10:00h | OFF 15:15h Fr | CH1+2 |

Additional features:

- manual override (ON/OFF): permanent ON or OFF
- automatic override (ON/OFF): actual program will be inversed (ON->OFF, OFF->ON) till next programmed ON time
- running reserve of 3 years
- exchangeable battery

Pack	Cat.Nos	MicroRex D21 Plus
	6 037 70	1 channel 230 V, 50/60 Hz GB version
	6 037 78	
	6 037 72	
	6 037 72	ES version
		MicroRex D22 Plus
	6 037 71	2 channels 230 V, 50/60 Hz GB version
	6 037 79	
	6 037 73	
	6 037 73	ES version


Rex - digital time switches

MicroRex Plus 2

Type	MicroRex D21 plus 2	MicroRex D22 plus 2
No. of modules (17,5 mm)	2	2
Channels	1	2
Running reserve	3 years	
Switching step	1 min	
Shortest switching step	1 min	
Accuracy	+/- 1 sec/day	
Switching capacity		
• Resistive 230 V~ cos φ = 1	16 A~	
• Incandescent lamps 230 V~	5 A~	
• Inductive 230 V~ cos φ = 0.6	10 A~	
Contacts	1 SPDT	2 SPDT
No. of programs	28	14/channel
Operating temperature	-10 ... +55 °C	
Protection	IP20	

■ Wiring diagram

MicroRex D21 Plus 2

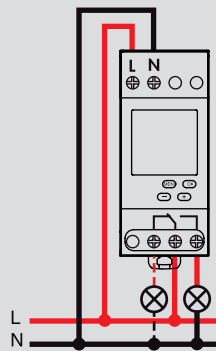

MicroRex D22 Plus 2

