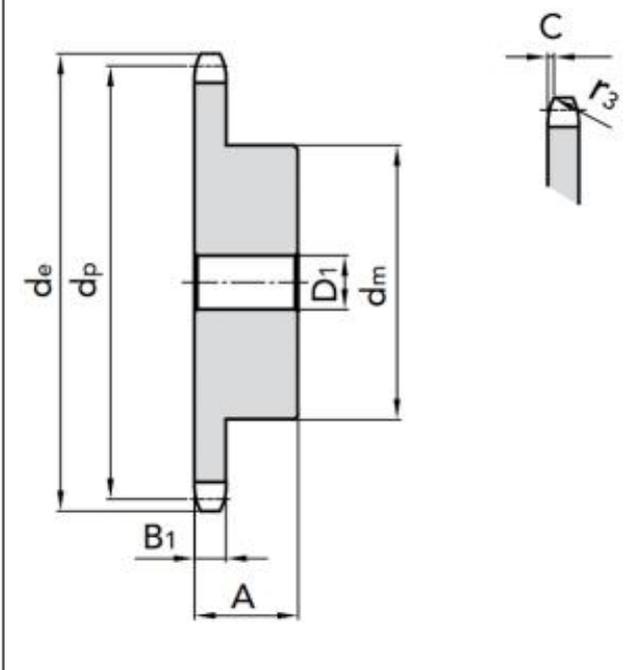


**10112012**

1/2in x 5/16in - Chain sprockets ISO

**2D Technical Drawing**

**Dynamic 3D View**

**Technical Specifications**

Number of teeth (T)	12
de (DE) mm	53.56
dp (DP) mm	49.07
Part number (CODE)	10112012
dm (DM) mm	33
D1 (D1) mm	10
A (A) mm	28
Tooth radius r3 (R3) mm	13
Radius width C (C) mm	1.3
Sprockets tooth width B1 (B1) mm	7.2
Weight (WEIGHT) kg	0.21
Material (MAT)	STEEL C 45