

# WorkForce WF-7110DTW

## DATASHEET



This business printer with Wi-Fi and Ethernet connectivity is ideal for printing A3 documents on a regular basis. It helps increase office efficiency with its fast business-quality print speeds of up to 18ppm<sup>1</sup>, 5.6cm LCD screen and two 250-sheet front-loading paper trays. You can also cut printing costs with XXL black ink which delivers a yield of up to 2,200 pages<sup>2</sup>.

### A3 duplex printing

This A3 business printer offers A3 duplex printing for more convenient office printing. As well as the front loading paper trays, the rear speciality paper path means you can print on a wide range of thicker paper, envelopes or labels to suit your business needs.

### Mobile printing

Epson Connect<sup>3</sup> allows you to print important office documents from smartphones and tablets. You can also print from anywhere in the world by emailing files directly to the printer. In addition, this printer is also Google Cloud Print and Apple AirPrint compatible. For added versatility, Wi-Fi Direct™ allows easy printing from wireless devices without having to connect to a wireless router.

### New printhead


PrecisionCore, Epson's most advanced printhead technology, powers the industry-leading output quality and durability that Epson is renowned for, at the high speeds required for office, commercial and industrial printing.

### Durable ink

Epson's DURABrite Ultra Ink is ideal for producing laser-like business documents. Documents are water, smudge and highlighter resistant, while its quick-drying properties make it perfect for duplex printing. Available in 27XXL, 27XL and standard sizes, these high-capacity, individual ink cartridges offer great savings, with a 50% lower cost-per-page than competitive lasers<sup>4</sup>.

## KEY FEATURES

- **A3 duplex printer**  
Print A3-sized business documents
- **Fast print speeds**  
Business-quality 18ppm printing<sup>1</sup>
- **Connectivity**  
Wi-Fi, Wi-Fi Direct and Ethernet
- **Dual paper trays**  
Two A3 250-sheet capacity trays
- **Epson Connect**  
Freedom to print from anywhere

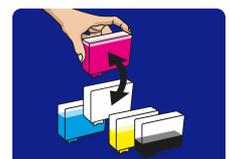

## PRODUCT SPECIFICATIONS

### TECHNOLOGY

Printing Method	PrecisionCore™ Print Head
Minimum Droplet Size	2.8 pl
Ink Technology	DURABrite™ Ultra
Nozzle Configuration	800 Nozzles black, 256 Nozzles per colour
Category	Office
All-in-One Functions	Print

### PRINT

Printing Speed ISO/IEC 24734	18 Pages/min Monochrome, 10 Pages/min Color
Maximum Printing Speed	32 Pages/min Monochrome (plain paper), 20 Pages/min Color (plain paper)
Printing Resolution	4,800 x 2,400 dpi
Max Duty cycle	20,000 Pages per month
Colours	Black, Cyan, Yellow, Magenta

For detailed information on printing speeds please visit <http://www.epson.eu/testing>.

### PAPER / MEDIA HANDLING

Paper Formats	A3+, A3, A4, A5, A6, B4, B5, C4 (Envelope), C6 (Envelope), DL (Envelope), No. 10 (Envelope), Letter, 9 x 13 cm, 10 x 15 cm, 13 x 18 cm, 16:9, User defined, Legal
Duplex	Yes
Paper Tray Capacity	500 Sheets Standard, 500 Sheets maximum
Number of paper trays	2
Compatible Paper Weight	64 g/m <sup>2</sup> - 256 g/m <sup>2</sup>
Output Tray Capacity	125 Sheets

### CONNECTIVITY

Interfaces	Hi-Speed USB - compatible with USB 2.0 specification, Ethernet interface (100 Base-TX / 10 Base-T), Wireless LAN IEEE 802.11b/g/n, Wi-Fi Direct
WLAN Security	WEP 64 Bit, WEP 128 Bit, WPA PSK (TKIP), WPA PSK (AES)
Mobile and Cloud printing services	Epson Connect (iPrint, Email Print, Remote Print Driver), Apple AirPrint, Google Cloud Print

### GENERAL

Energy Use	1.5 W (sleep mode), 22 W (printing), 5.8 W (Ready), 0.3 W (Power off), ENERGY STAR® qualified
Product dimensions	567 x 424 x 304 mm (Width x Depth x Height)
Product weight	15.58 kg

### OTHER

Warranty	12 months On site service Optional warranty extension available
----------	--

## LOGISTICS INFORMATION

SKU	C11CC99301
EAN code	8715946529707
Dimensions Single Carton	720 x 570 x 405 mm
Carton Weight	18.46 Kg
Multiple Order Quantity	1 Units
Country of Origin	Indonesia
Pallet Size Euro	10 Units
Pallet Size Block	10 Units



For more information please contact:

Telephone: 01952 607111 (UK)+  
01 436 7742 (Republic of Ireland)  
E-mail: [enquiries@epson.co.uk](mailto:enquiries@epson.co.uk)  
Chat: [etalk.epson-europe.com](http://etalk.epson-europe.com)  
Fax: 0871 222 6740  
+ Local call rate.

Web: [www.epson.co.uk](http://www.epson.co.uk)  
[www.epson.ie](http://www.epson.ie)

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners. Product information is subject to change without prior notice.

## WorkForce WF-7110DTW

### WHAT'S IN THE BOX

- CD Manual
- Driver and utilities (CD)
- Individual Ink Cartridges
- Main unit
- Power Code
- Quick Start Guide
- Software (CD)
- Warranty document

### INK CARTRIDGE COMPATIBILITY



### INK YIELD DATA

	Alarm clock 27XL	Alarm clock 27XXL	Alarm clock 27
●	1,100 pages*	2,200 pages*	350 pages*
● ● ●	1,100 pages*		300 pages*

\* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

1 - Determined in accordance with ISO/IEC 24734 showing the average of ESAT from the Office Category Test for default A4 simplex and duplex. For more information, please visit [www.epson.eu/testing](http://www.epson.eu/testing) 2 - Approx. page yield based on ISO/IEC 24711/24712. Actual yield will vary depending on images printed and usage conditions. For more information visit [www.epson.eu/pageyield](http://www.epson.eu/pageyield) 3 - Epson iPrint requires a wireless connection and the Epson printing app. Epson Email print and Epson Remote Print Driver require a connection to the internet. For more information, supported languages and devices, please visit [www.epsonconnect.eu](http://www.epsonconnect.eu) 4 - For more information, please visit [www.epson.eu/inkjetsaving](http://www.epson.eu/inkjetsaving)

**EPSON®**