



Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) SVHC > Threshold: Pb (2.5% in 3440316) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

 TE Part # 211400-1 CPC PLUG ASSEMBLY SIZE 13-7	 TE Part # 211768-1 CPC PLUG ASSEMBLY SIZE 17-9	 TE Part # 208470-1 CMC PLUG ASSEMBLY, SZ 28	 TE Part # 206150-1 CPC PLUG ASSEMBLY SIZE 23-37
 TE Part # 206429-1 CPC PLUG ASSY, 11-4, REV SEX	 TE Part # 208718-1 CMC PLUG ASSEMBLY, SZ 14-5	 TE Part # 206837-1 CPC PLUG ASSEMBLY SIZE 23-24	 TE Part # 213850-1 CPC PLUG ASSEMBLY SIZE 23-37
 TE Part # 206044-1 CPC PLUG ASSEMBLY SIZE 17-14	 TE Part # 213848-1 CPC PLUG ASSEMBLY SIZE 23-37	 TE Part # 208457-1 CMC PLUG ASSEMBLY, SZ 28-24	 TE Part # 58541-2 PRO-CRIMPER HAND TOOL DIE
 TE Part # 796094-2 SLD CPC PLUG ASY, 11-4, STD SEX	 TE Part # 601967-1 CRIMPING TOOL M22520/1-01	 TE Part # 788157-2 SLD CPC PLUG ASSY, 13-9, STD SEX	 TE Part # 206708-1 CPC PLUG ASSEMBLY SIZE 13-9
 TE Part # 200893-2 INSERTION TOOL CONT	 TE Part # 208718-2 CMC PLUG ASSEMBLY, SZ 14-5	 TE Part # 1-601967-6 POSITIONER TYPE II CONTACTS	 TE Part # 1977878-1 SLD CPC PLUG ASY, 11-4, STD SEX, UV RESIST

Customers Also Bought



TE Part #104482-8
18 SHORT PT RCPT HSG DR .100CL



TE Part #2-35108-1
TERMINAL,PIDG R 12-10 8



TE Part #2309409-1
DDR4 SODIMM 260P 5.2H STD




TE Part #3-641127-3
03P MTA100 HDR ASSY FL/RA LF




TE Part #2176410-3
MPT35 6R2 1%



TE Part #2294415-1
INDUSTRIAL MINI I/O HDR TYPE I TRAY

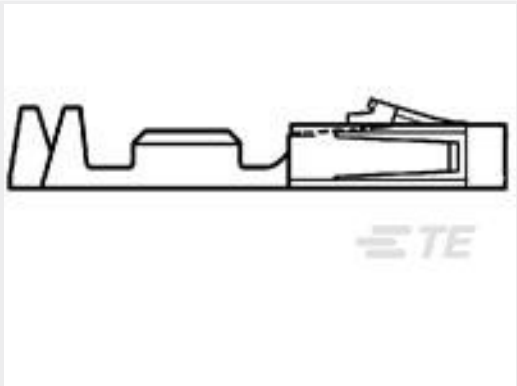


TE Part #1-104479-1
SHORT POINT RECP CONT LP

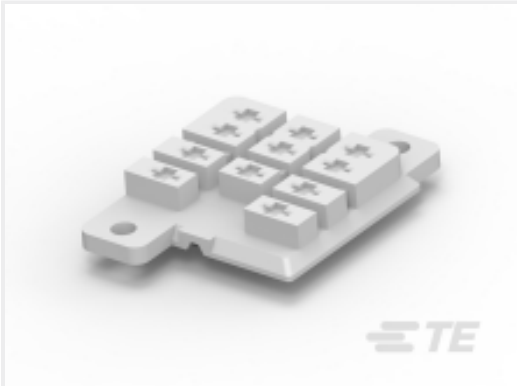

TE Part #1419106-4
27E046=SOCKET,KU,11,PCB,NYL,NAT



 TE Part #66358-4
III+ SKT,18-14,30AU/FL,STRIP



TE Part #224155-1
EXTR TL, HIGH CURRENT TYPE XII

Documents

Product Drawings
CONTACT PIN ASSY.

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_202725-1_G.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_202725-1_G.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_202725-1_G.3d_stp.zip

English

Customer View Model

ENG_CVM_202725-1_F.3d_igs.zip

English



Customer View Model

[ENG_CVM_202725-1_F.3d_stp.zip](#)

English

Customer View Model

[ENG_CVM_202725-1_F.2d_dxf.zip](#)

English

3D PDF

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[AMP Circular Connectors for Commercial Signal & Power Applications](#)

English

Signal Contacts

English

[M_SERIES_PIN_AND_SOCKET_CONNECTORS](#)

English

Product Specifications

[Application Specification](#)

Japanese

[Application Specification](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English

[Application and Maintenance for Crimping Die Assemblies](#)

English

[Instruction Sheet \(U.S.\)](#)

Japanese

[Instruction Sheet \(U.S.\)](#)

English

[Instruction Sheet \(U.S.\)](#)

English