

Datasheet

SP-NO PCB Off-(On) Push Button Switch


RS Stock number 734-6744



Specifications:

Mechanical Life:	60,000 make-and-break cycles
Contact Resistance:	20m Ω max. initial @ 2-4VDC, 100mA for both silver and gold plated contacts.
Insulation Resistance:	1,000M Ω min.
Dielectric Strength:	1,000 RMS @ sea level
Operating Temperature:	-30°C to 85°C
Case:	Diallyl phthalate (DAP) (UL94V-0)
Actuator:	Brass, chrome plated
Bushing:	Brass, nickel plated
Housing:	Stainless steel
Switch Support:	Brass, tin plated
Terminals/Contact:	Brass, with silver or gold plated
RoHS:	2002/95/EC

**Dimensions – inch
mm**

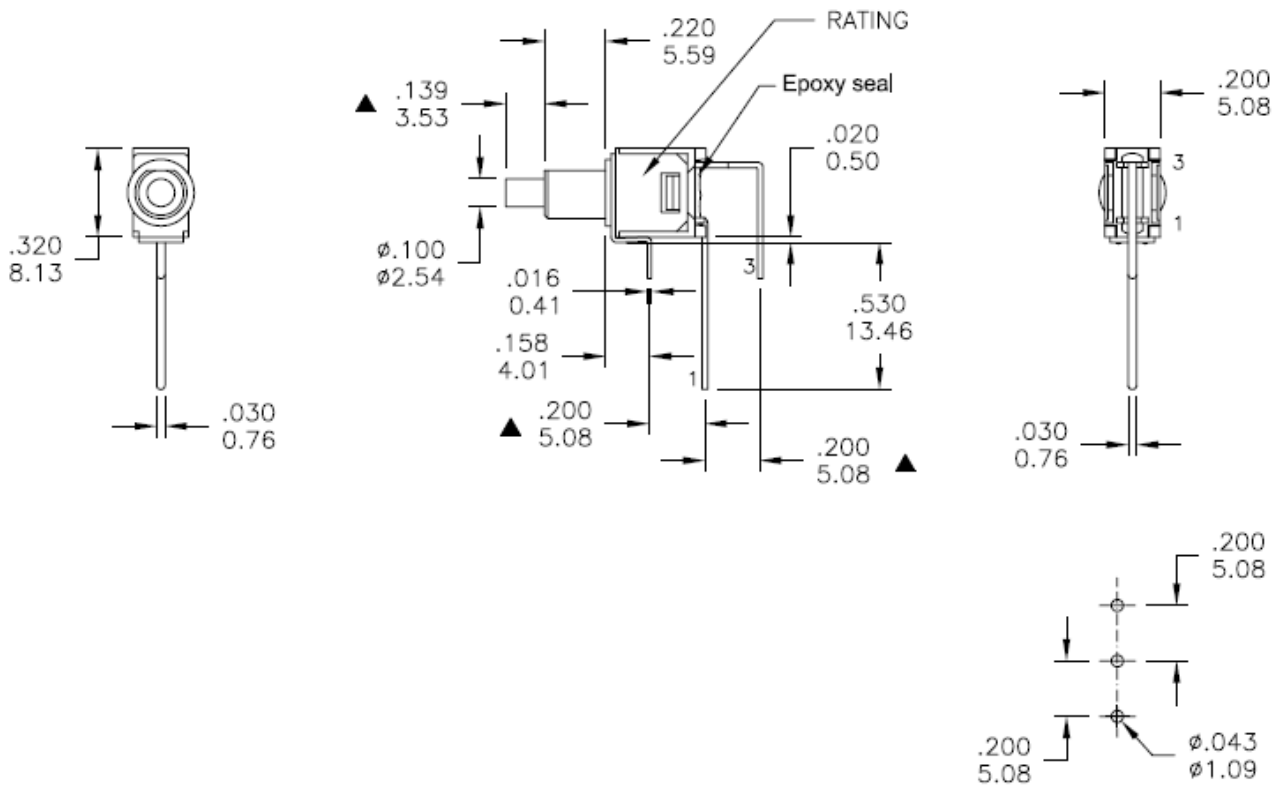

Model No.	POS.1	POS.2
Term. Comm.	OPEN	1-3
SCHEMATIC		

SWITCH FUNCTION

P.C. MOUNTING