


solenoid coil VACS-C-C1-1A

Part number: 8025335

FESTO

Type C connection pattern, to EN 175 301, 24 V AC/50-60 Hz

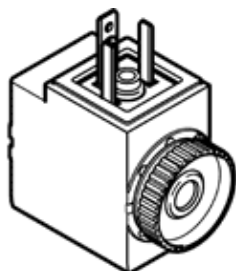

Data sheet

Feature	Value
Assembly position	Any
Duty cycle	100 %
Insulation class	H
Characteristic coil data	24 V AC: 50/60 Hz, pick-up power 2.5 VA, holding power 1.8 VA
Permissible voltage fluctuation	+/- 10 %
Authorisation	c UL us - Recognized (OL)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Protection class	IP65
Ambient temperature	-10 ... 50 °C
Electrical connection	to EN 175301-803 Plug pattern type C to EN 175301-803
Mounting type	With knurled nut
Materials note	Conforms to RoHS
Material housing	PA Steel
Material solenoid coil	Copper Steel Thermoplastic
Material winding	Copper