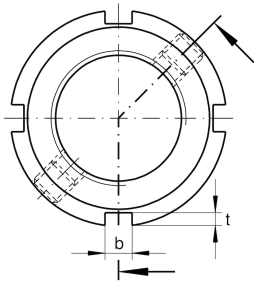
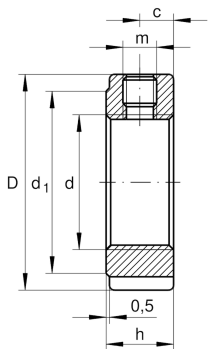
**ZMA30/52** **Precision locknut**

Precision locknuts ZMA, locking pegs, radially arranged, heavy series

Technical information**Main Dimensions & Performance Data**

d	M30X1,5	Thread
D	52 mm	Outside diameter
h	22 mm	Height
M _A	5 Nm	Mounting torque set screw
F _{aB}	270,000 N	Breaking load, axial
M _L	70 Nm	Breakawag
M _{AL}	32 Nm	Mounting torque reference
M _M	1.1 kg*cm ²	Mass moment of inertia
≈m	0.233 kg	Weight

Dimensions

d ₁	47 mm	Plant diameter outside
t	2 mm	Hight retaining slot
b	5 mm	Width retaining slot
c	11 mm	Distance bore
m	M6	Threaded - threaded pin