



No.390, Yong He Road,
Shanghai 200072, China

TECHNICAL DATA SHEET CABLE ASSEMBLY

PART NUMBER : R284C0351019

Issue : NA

Date : NA


Customer : Radio Spares

Specification : NA

Issue : NA

Date : N/A

All dimensions are in mm

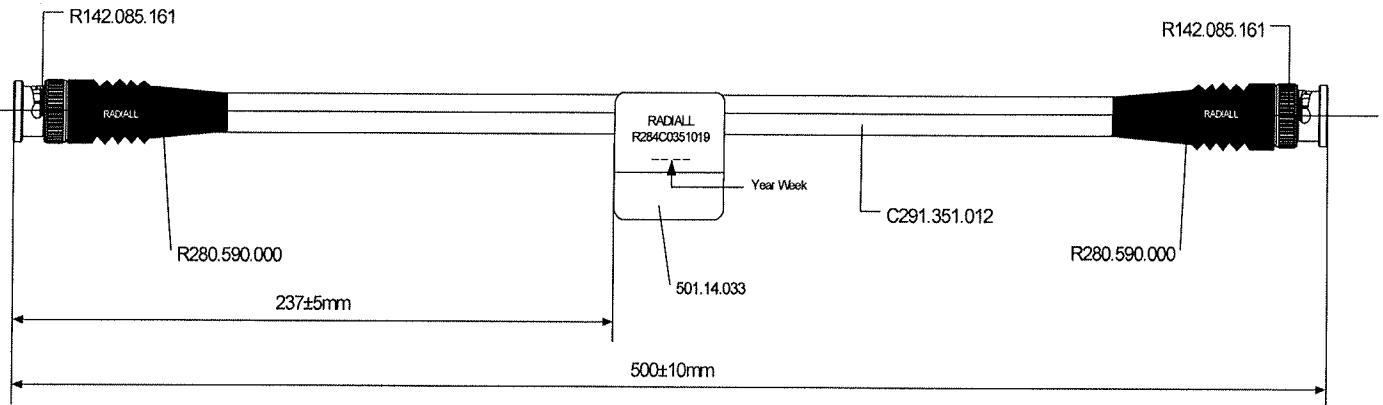

Connectors designation :

Connector 1 : BNC Straight Plug Crimp Type
Cable 6/75+93 (R142.085.161)

Connector 2 : BNC Straight Plug Crimp Type
Cable 6/75+93 (R142.085.161)

Cable designation :

Flexible Cable 6/75S (KX6A)
C291.351.012

Nominal length :

Lg: 500 mm

Cable colour :

Green

Outer diameter :

6.10 mm

Accessories :

Plastic Boots (R280.590.000)

ELECTRICAL CHARACTERISTICS :

High Frequency

Characteristic impedance : 75 ± 2 Ohms

Frequency range : DC-1GHz

Insertion Loss : 0.38 dB max @ 1GHz & 20° C

VSWR. : TBT

Low Frequency

Insulation Resistance : 5000 MOhms min

Voltage Rating : 500 Veff max

MECHANICAL CHARACTERISTICS :

Recommend min. bend radius : 15 mm

Cable crush resistance : NA

Life (connectors) : 100 cycles

ENVIRONMENTAL CHARACTERISTICS :

Operating temperature range : -35° C to +70° C

Remark : NA

Attachment : R142.085.161-TDS ,
C291.351.012 (KX6A)-TDS

Cable Assembly is RoHS compliant.

CUSTOMER'S APPROVAL

Service or
Company's stamp

Name
Date

Willy	A	2007-5-16	Creation	Garet Xie
Name	Issue	Date	Modification	Checked by