


# push-in Y-connector NPQM-Y-Q4-E-P10

Part number: 558798

FESTO

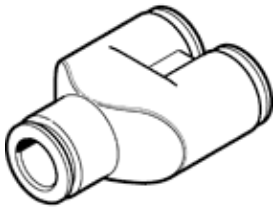

## Data sheet

Feature	Value
Size	Standard
Nominal size	3.5 mm
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-20 ... 70 °C
Product weight	13.5 g
Pneumatic connection, port 1	For tubing outside diameter 4 mm
Pneumatic connection, port 2	For tubing outside diameter 4 mm
Materials note	Conforms to RoHS
Material housing	Nickel-plated brass
Material of tubing seal	NBR