

## 电缆插头外壳 - KGG-MC 1,5/ 3 - 1834356


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



电缆插头外壳，针距: 3.81 mm，位数: 3，尺寸a: 13.82 mm，颜色: 绿色

RoHS

### 关键商业数据

包装单位	10 STK
最小订货量	10 STK
GTIN	 4 017918 051877
GTIN	4017918051877
海关税则号	8538900000
Sales Key	AAAEHA

### 技术数据

#### 尺寸

宽度 [ w ]	14.5 mm
高度 [ h ]	35.6 mm
间距	3.81 mm
尺寸a	13.82 mm

#### 概述

产品范围	KGG-MC 1,5
位数	3
绝缘材料组	I
绝缘材料	ABS
阻燃等级，符合UL 94	HB

#### 标准和规范

阻燃等级，符合UL 94	HB
--------------	----

Environmental Product Compliance

# 电缆插头外壳 - KGG-MC 1,5/ 3 - 1834356


## 技术数据

### Environmental Product Compliance

China RoHS	环保使用期限：无限期 = EFUP-e
	无超标的有害物质

## 产品图

尺寸图

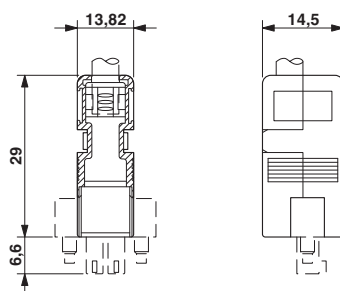

## 分类

### eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27261200
eCl@ss 6.0	27261200
eCl@ss 7.0	27440202
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

### ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC000879
ETIM 5.0	EC000437
ETIM 6.0	EC000437

### UNSPSC

UNSPSC 6.01	30211810
UNSPSC 7.0901	39121409
UNSPSC 11	39121409
UNSPSC 12.01	39121409
UNSPSC 13.2	31261501

## 认证

认证

# 电缆插头外壳 - KGG-MC 1,5/ 3 - 1834356

## 认证

---

认证

EAC

---

防爆认证

---

## 认证详情

EAC		B.01742
-----	---	---------

## 附件

附件

插头外壳

抗弯折保护套管 - CUC-DST-ABK-CP6,5 - 1419790



抗弯折保护套管，保护等级: IP20，颜色: 黑色

## 端子标识

标记卡 - SBS10:UNBEDRUCKT - 1007248



标记卡，卡，白色，未标记，适用的打印机：CMS-P1-PLOTTER，打孔，安装方式: 卡接到高型标记槽，卡接到扁平式标记槽，适用的模块宽度：10 mm，标识区域大小: 6 x 10,1 mm