
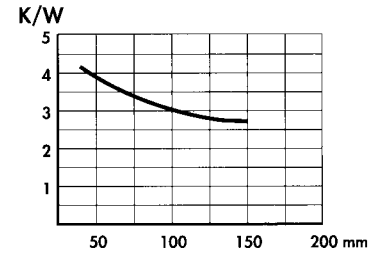


Strangkühlkörper Extruded Heatsinks Dissipateurs extrudés

SK 185

37,5 50 75 100 1000 mm



TO 3 9/66 CB

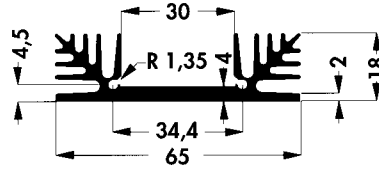

SK 48

37,5 50 75 100 1000 mm



TO 3 9/66 CB SSR 1 SSR 3

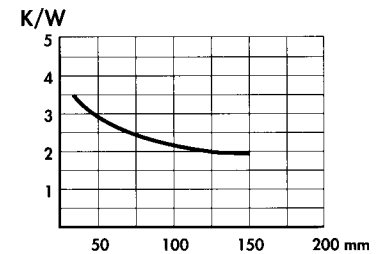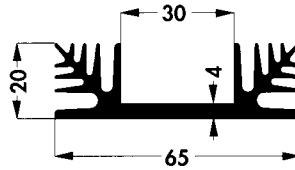

SK 79

37,5 50 75 100 1000 mm

TO 3 9/66 CB

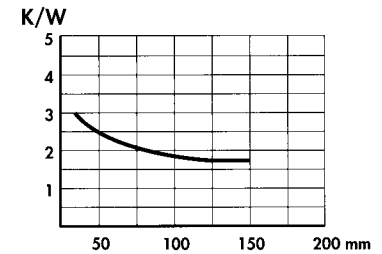
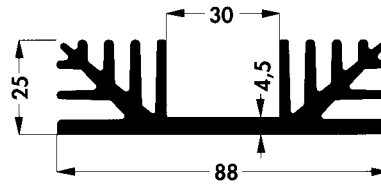


RS 189-8549 ; RS 189-8555 ;
RS 189-8561 ; RS 189-8870 ;

SK 08

37,5 50 75 100 1000 mm

TO 3 9/66 CB

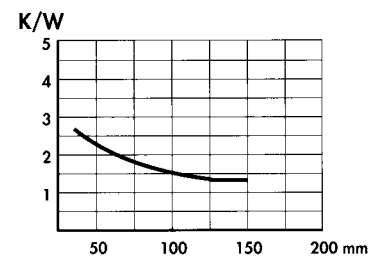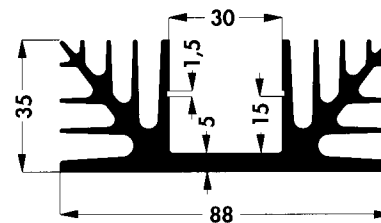

mit Führungsnuten für Abdeckplatten oder Platinen

with slots for cover plates or P.C.B.'s.



avec rainures pour tôles de protection ou cartes imprimées

RS 189-8202 ; RS 189-8218 ;
RS 189-8230 ; RS 189-8246 ;

SK 88

37,5 50 75 100 1000 mm

TO 3

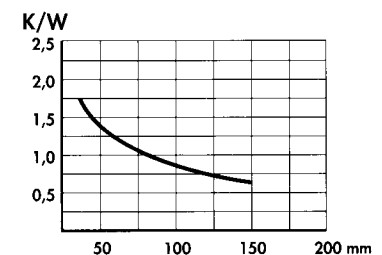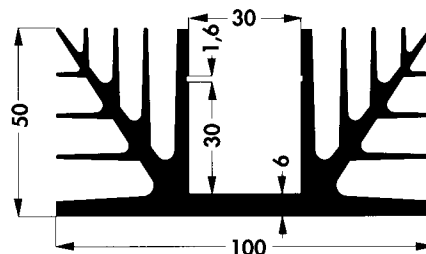

mit Führungsnuten für Abdeckplatten oder Platinen

with slots for cover plates or P.C.B.'s.

avec rainures pour tôles de protection ou cartes imprimées