

## 特点

- 比标准白炽灯泡更亮
- 快速容易安装
- 明亮的彩色强光
- 非常低的功耗—非常节能
- 温度范围
- IP 等级: IP65 –防尘和防增压喷水
- 工作寿命: 30,000 小时

## RS Pro , 面板安装红色 LED 指示灯, 22mm 开孔, IP65 , 24 V 交流 / 直流

RS 库存号: 763-7909



RS 认证产品为您提供所有产品类别的专业品质部件。我们的产品系列经过工程师测试、提供与杰出品牌相当的质量、而无需支付高昂的价格。

## 商品描述属性 1

RS Pro LEDtec 系列 LED 指示灯使用多芯片技术，可提供红色，绿色，黄色，蓝色和白色的明亮均匀颜色。这些指示灯的面板锁紧螺母固定背面和螺钉夹接线端子易于安装和连接。此 LED 指示灯系列可现代高效地替代传统 22mm 指示灯。

## 一般规格

指示灯颜色	红色
灯类型	LED
亮度	$\geq 60 \text{cd/m}^2$
应用	自动设备、电话、状况面板、仪表板灯

## 电气规格

电压类型	交流 / 直流
额定电压	24V 交流 / 直流
频率	交流 50Hz - 60Hz 交流
Terminal	螺钉
绝缘耐受	2.5 千伏（交流）1minute
绝缘电阻	$> 2 \text{M}\Omega$
使用寿命	30000 小时

## 机械规格

开孔直径	22mm
安装类型	面板安装

## 操作环境规格

工作温度范围:	-25°C 至 155°C
相对湿度	<=98%

## 保护类别


ip 等级	IP65
-------	------

## 认证

合规性 / 认证	rohs
符合标准	CE





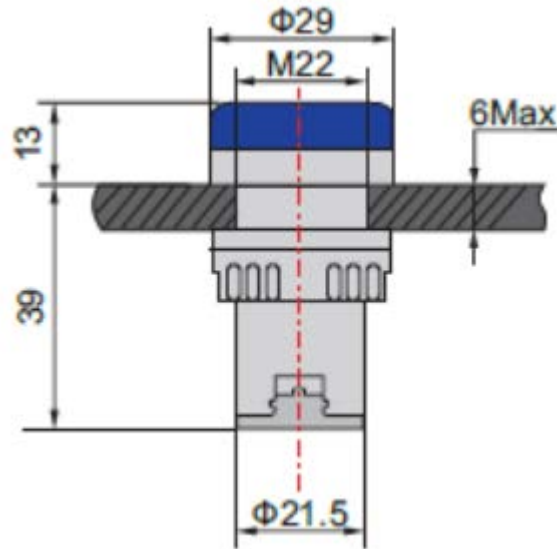

RS Stock Number	Colour	Voltage	Cut out Diameter	Illumination Type	IP Rating	Terminal Type	Mounting Type
791-8579	White	12V	22mm	LED	IP65	Screw	Panel Mount
791-8573	Red	12V	22mm	LED	IP65	Screw	Panel Mount
791-8582	Green	12V	22mm	LED	IP65	Screw	Panel Mount
791-8585	Blue	12V	22mm	LED	IP65	Screw	Panel Mount
791-8589	Yellow	12V	22mm	LED	IP65	Screw	Panel Mount
763-7905	White	24V	22mm	LED	IP65	Screw	Panel Mount
763-7909	Red	24V	22mm	LED	IP65	Screw	Panel Mount
763-7918	Green	24V	22mm	LED	IP65	Screw	Panel Mount
763-7911	Blue	24V	22mm	LED	IP65	Screw	Panel Mount
763-7915	Yellow	24V	22mm	LED	IP65	Screw	Panel Mount
763-7924	White	110V	22mm	LED	IP65	Screw	Panel Mount
763-7927	Red	110V	22mm	LED	IP65	Screw	Panel Mount
763-7921	Green	110V	22mm	LED	IP65	Screw	Panel Mount
763-7930	Blue	110V	22mm	LED	IP65	Screw	Panel Mount
763-7933	Yellow	110V	22mm	LED	IP65	Screw	Panel Mount
763-7937	White	230V	22mm	LED	IP65	Screw	Panel Mount
763-7946	Red	230V	22mm	LED	IP65	Screw	Panel Mount
763-7949	Green	230V	22mm	LED	IP65	Screw	Panel Mount
763-7943	Blue	230V	22mm	LED	IP65	Screw	Panel Mount
763-7952	Yellow	230V	22mm	LED	IP65	Screw	Panel Mount