





AUXILIARY SWITCH CHANGEOVER CONTACTS
TYPE HP (14MM) ACCESSORY FOR 3VA-BREAKER



Model		
product brand name		SENTRON
Product designation		auxiliary switch
General technical data		
Thermal current	A	10
Overvoltage category		III
Voltage		
Insulation voltage / Rated value	V	690
Surge voltage resistance / Rated value	kV	6
Operating voltage		
• at AC / at 50 Hz / Rated value / minimum	V	600
• at DC / Rated value / minimum	V	250
Wire stripping length	mm	15
Connectable conductor cross-section / maximum	mm ²	2.5
Tightening torque / with screw-type terminals / maximum	N·m	0.5
Height	mm	56
Width		

• Note		2 slots (14 mm)
Depth	mm	30
Net weight	g	40
Degree of pollution		3

General Product Approval	EMC	Declaration of Conformity	Test Certificates
 CCC	 VDE		 EG-Konf.

[sonstig](#)

[Typprüfbescheinigung/Werkszeugnis](#)

other

[sonstig](#)

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/3VA99880AA11>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/3VA99880AA11/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA99880AA11

CAX-Online-Generator


<http://www.siemens.com/cax>

Tender specifications

<http://ausschreibungstexte.siemens.com/tiplv>

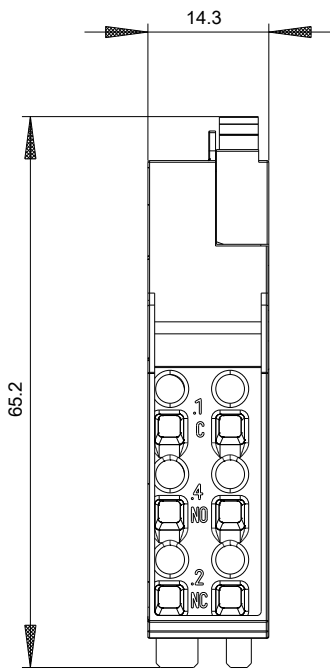

last modified:

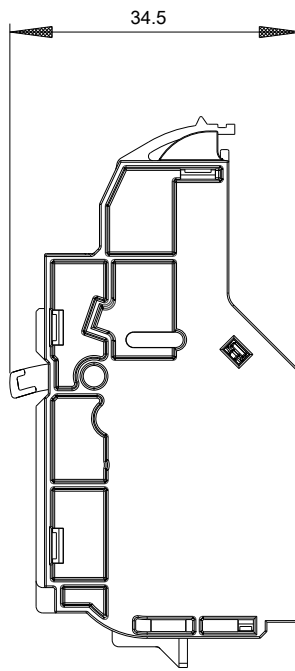

20.07.2015