


# connecting cable

## NEBV-S1WA25-K-2.5-N-LE25-S9

Part number: 575423

FESTO

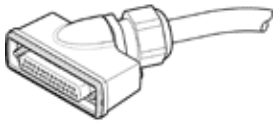

### Data sheet

Feature	Value
Mounting type	4-40UNC
Assembly position	Any
Product weight	500 g
Electrical connection	Plug socket Sub-D 25-pin
Operating voltage range DC	≤ 30 V
Acceptable current load at 40°C	2.6 A
Cable length	2.5 m
Cable attribute	For static applications
Min. cable bending radius	122 mm
Cable diameter	10.2 mm
Cable diameter tolerance	± 0,25 mm
Cable structure	25x0,34
Protection class	IP65 IP67 in assembled condition
Ambient temperature	-5 ... 80 °C
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material cable sheath	PVC
Material housing	PA66-GF30
Material electrical contact	Bronze Gold plated