

# Straight Blade Devices

## 2 Pole, 3 Wire Grounding

15 and 20 Ampere, 125 Volts  
INSULGRIP® Flanged Inlets and Flanged Receptacles



NEMA 5-15P  
15A 125V  
UL CSA




NEMA 5-20P  
20A 125V  
UL CSA

### Flanged Inlets—Phillips/Slotted Screws


Description	Catalog Numbers
Nylon casing, back wired. <b>NEW</b>	HBL5278C <b>HBL5378C</b>
Same as above, except with combination Robertson/slotted head screws. <b>NEW</b>	<b>HBL5278CCN</b>
Weather proof, gray nylon, with lift cover and boot, slotted screws.	<b>HBL61CM64</b> -
Nickel plated brass flange, phenolic body, miniature style, for molded on connectors only, slotted screws.	<b>HBL5240*</b> -

Discontinued when stock is exhausted

\* Specially designed to accept "molded-on" connector bodies. Cat. 5240 will not accept standard size connector bodies listed in this catalog, or molded connectors having a "rejection obstruction" as required by Underwriters Laboratories Inc. standard #817 cord sets and power supply cords" effective 7/1/81.

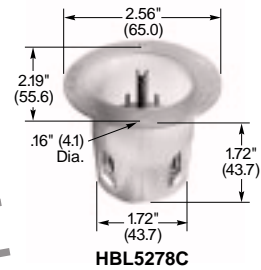

**HBL5278C**

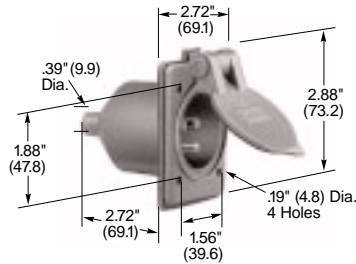

**HBL61CM64**



15A only



NEMA 5-15R  
15A 125V  
UL CSA




NEMA 5-20R  
20A 125V  
UL Listed


### Flanged Receptacles—Phillips/Slotted Screws

Description	Catalog Numbers
Nylon casing, back wired. <b>NEW</b>	HBL5279C <b>HBL5379C</b>
Nickel plated brass flange, phenolic body, covered terminals, slotted screws.	<b>HBL5279</b> -
Nickel plated brass flange, brown phenolic, slotted screws. (Mounting screws packed separately.)	<b>HBL5256</b> -
Weather proof, gray nylon, with lift cover and boot, slotted screws.	- <b>HBL61CM65</b>


See page A-43 for accessories.

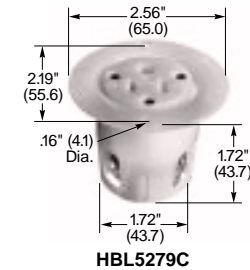

**HBL5279C**

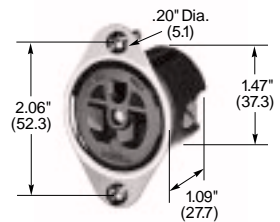

**HBL5256**

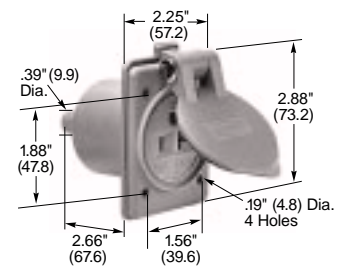

**HBL61CM65**

# Straight Blade Devices

## 2 Pole, 3 Wire Grounding

15 and 20 Ampere, 250 Volts

### Connectors and Flanged Receptacles



**IP20**  
SUITABILITY




NEMA 6-15R  
15A 250V  
UL CSA




NEMA 6-20R  
20A 250V  
UL Listed

#### Connector Bodies

Description	Cord Dia.	Catalog Numbers
Insulgrip® connector, black and white nylon, Phillips/slotted screws.	.230-.720" (5.8-18.3)	<b>NEW</b> HBL5669C
Valise® connector, yellow nylon, slotted screws.	.220-.660" (5.6-16.8)	HBL5669VY HBL5469VY

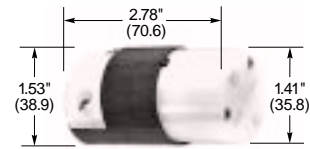

HBL5669C

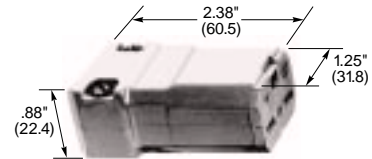

HBL5669VY




NEMA 6-15R  
15A 250V  
UL CSA




NEMA 6-20R  
20A 250V  
UL Listed

#### Flanged Receptacles


Description	Catalog Numbers
Nylon casing, Phillips/slotted screws.	<b>NEW</b> HBL5679C HBL5479C
Nickel plated brass flange, brown phenolic housing, slotted screws. (Mounting screws packed separately.)	HBL5656

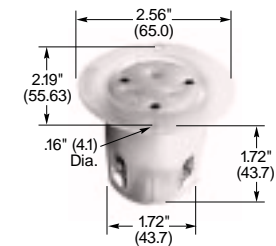

HBL5679C

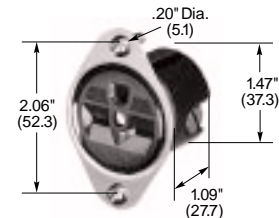

HBL5656

 

**IP20**  
SUITABILITY




NEMA 6-15R  
15A 250V  
UL CSA



NEMA 6-20R  
Canadian  
20A 250V  
UL CSA

#### Connector Bodies with Robertson/Slotted Screws

Description	Cord Dia.	Catalog Numbers
Insulgrip connector, black and white nylon.	.230-.720" (5.8-18.3)	<b>NEW</b> HBL5669CCN HBL6394CCN
Valise connector, yellow nylon	.220-.660" (5.6-16.8)	HBL5669VYCN

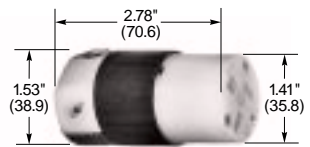

HBL6394CCN

Note: See page A-43 for accessories.