




隣接ポートに干渉しにくい、USB-IF認証のAtoC変換ケーブル。

AD-USB33CAF

USB 5Gbps Type-C変換ケーブル（AtoC・7cm・USB-IF認証品）

JANコード 4969887774700

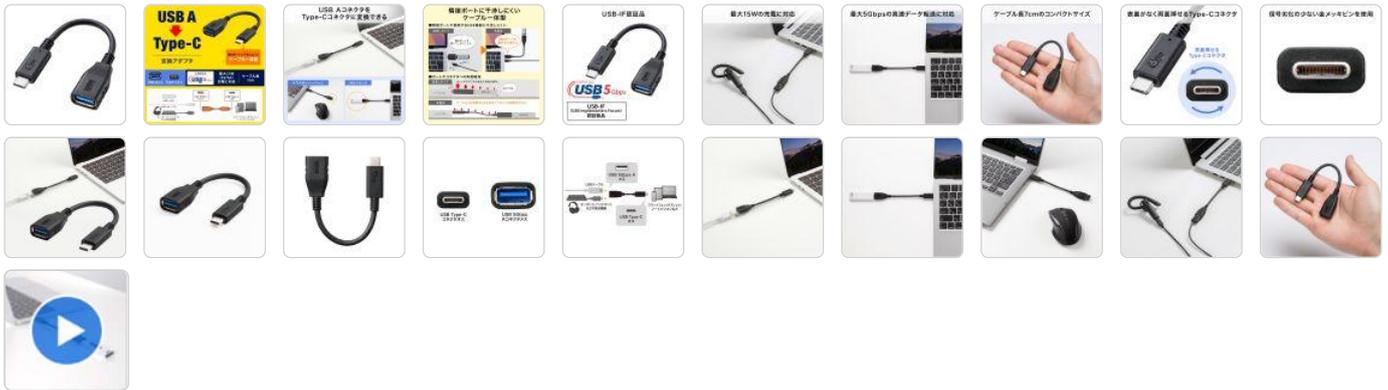

仕様

コネクタ形状	USB5GbpsAコネクタメス - Type-Cコネクタオス
ケーブル長	0.07m
ケーブル径	4.2mm
重量	13g

特長

最大5Gbpsの高速データ転送に対応し、大容量ファイルの移動もスムーズに行えます。

ケーブル長は約7cmと短く、モバイル利用や持ち運びにも最適です。

USB-AからType-Cへの変換が可能で、幅広いデバイスに対応します。

USB-IF（USB Implementers Forum）で認証された製品です。

隣接ポートに干渉しにくい小型設計で、複数のデバイスを同時に接続する際も快適に使えます。

最大15W（5V/3A）の充電に対応しています。※USB Power Delivery非対応。

外部ノイズを防ぐ3重シールド構造で、安定したデータ通信が可能です。

錆にも強く、経年変化による信号劣化の少ない金メッキピンを使用しています。
※DisplayPort Alternate Modeには対応していないため、映像出力はできません。

対応情報

対応機種	USB Type-C (TM) ポートを搭載のパソコン、タブレット、スマートフォン、USB-A端子を持つ周辺機器。
------	---

**A USB-IF certified AtoC conversion cable that is less likely to interfere with adjacent ports.
AD-USB33CAF**

Specification

- Connector Shape : USB 5Gbps A female connector - Type-C male connector
- Cable length : 0.07m
- Cable diameter : 4.2mm
- Weight : 13g

Features

- It supports high-speed data transfer of up to 5Gbps, allowing you to transfer large files smoothly.
 - The cable is only about 7cm long, making it ideal for mobile use and carrying around.
 - It can convert from USB-A to Type-C, making it compatible with a wide range of devices.
 - This product is certified by USB-IF (USB Implementers Forum).
 - The compact design minimizes interference with adjacent ports, allowing for comfortable use even when connecting multiple devices simultaneously.
 - Supports charging up to 15W (5V/3A). *USB Power Delivery is not supported.
 - The triple shielding structure prevents external noise, enabling stable data communication.
 - The gold-plated pins are rust-resistant and have minimal signal degradation over time.
- *DisplayPort Alternate Mode is not supported, so video output is not possible.