

ALPHA

3470IDG100P30-13

EAN 4031582476156

Swivel castor, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, bolt hole. Wheel centre made of Aluminium, Tread: heat resisting silicone rubber, damping, self-lubricating bushing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

Technical Data

Wheel diameter	100 mm
Wheel width	35 mm
Centre hole	13 mm
Offset	41 mm
Swivel Interference	182 mm
Overall height	128 mm
Temperature	- 30 / + 250 °C
Standard	EN_12532
Weight	0.791 kg
Swivel Radius	91 mm
Hardness of tread	Shore A 75
Load capacity	80 kg
Load capacity (static)	160 kg

Dimensions

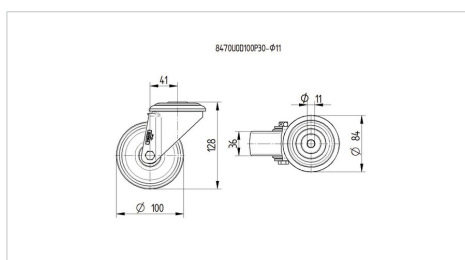

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ● ●