

START Panel Flat 600x600

START Panel Flat 600x600 HE 4300Lm 830

0047214



Product features

- Edge lit LED flat panel. Low Flicker, 35 W, Warm White, 3000 K, 4300 lumens, high efficacy, 123 lm/W, 50000 hours lifetime (L70), PMMA opal diffuser, aluminium frame, steel body, electronic non dimmable driver. (HxWxD) 9.5 x 595 x 595 mm



PRODUCT OVERVIEW

IPC Code	0047214
Product name	START Panel Flat 600x600 HE 4300Lm 830
Technology	LED
Housing	Aluminium
Mount	Surface/Recessed/Suspended
General application	Office
Certifications	EUNEW008
ETIM Class	EC002892
Fixture luminous flux (lm)	4,150
Luminaire efficacy (lm/W)	119
Colour temperature (K)	3000
CRI (Ra)	80
Colour Variation Initial (SDCM)	5
Beam Angle (°)	120
Glare control	N/A
Photobiological Risk Group	RG0
Total power consumption (W)	35
Electrical protection	Class II
Control gear type	Electronic (constant current)
Dimmable	No
LED Flickering Rate	Ultra low (5% or less)
Average life (Nominal) (h)	50000
Housing colour	RAL9003
IP rating	IP40/20
IK rating	IK03
Product EAN number	5410288472140
Lamps	No

PHOTOMETRY


START Panel Flat 600x600

START Panel Flat 600x600 HE 4300Lm 830
0047214

0.5	1.48	E:0°	5717
	1.62	E:C90	201
		E:C0	474
1.0	2.97	E:0°	1429
	3.03	E:C90	125
		E:C0	119
1.5	4.45	E:0°	938
	4.55	E:C90	91
		E:C0	55
2.0	5.93	E:0°	387
	6.07	E:C90	21
		E:C0	31
2.5	7.41	E:0°	229
	7.58	E:C90	20
		E:C0	18
3.0	8.90	E:0°	189
		E:C90	14
	9.10	E:C0	13

Distance [m] Core diameter [m] Illuminance [lx]

— C0 - C180 (Half beam angle: 113.0°)
— C90 - C270 (Half beam angle: 112.0°)

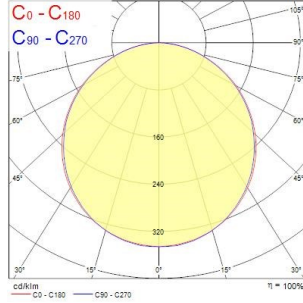

TECHNICAL DRAWINGS

