

## TruCheck 2, 1.5 - 30 N·m



TruCheck™ 2 is a cost effective torque wrench checker that has been redesigned to incorporate improved features whilst maintaining ease of use.

The TruCheck™ 2 aims to cut the cost of purchasing a torque wrench checking system and remove the reservations over the complexity of using such equipment.

**Part number:** 43518

**EAN Bar Code:** 5060207566667

**NATO number:** -

**Accuracy:** -

**Operates between:**

**1.50 - 30.00 N·m**



## TECHNICAL SPECIFICATIONS

- Weight: 1.4 kg
- Accuracy:  $\pm 1\%$  torque reading accuracy ( $\pm 2\%$  when below 10% of range for the 1,100 N·m TruCheck™ 2 model)
- Display: LCD Display
- Temp Range - Operating: 0°C to +50°C
- Temp Range - Storage: -20°C to +70°C
- Auto Reset Hold Time: 1,2 or 3 seconds
- Power Consumption: 0.5W
- Environment: IP 40
- Electromagnetic Compatibility (EMC) Directive: Designed to comply with EN 61326-1
- Requires two Hexagon Socket Head Cap Screws ISO 4762 - M10 - 12.9 to fix in position (not included)

## FEATURES

- Inbuilt Micro USB 2.0 port enables power from any USB power source. Plus versions allows for both power and data transfer simultaneously
- Allows torque tool performance to be monitored and tools kept in peak condition.
- Limited settable options. Ideal for non-expert users with click type torque wrenches
- Supplied with 10 mm male hexagon, 1/4" and 3/8" female square drive adapter
- If you order a UKAS accredited calibration certificate (available at extra cost) this certificate will be provided in place of the traceable calibration certificate
- Software can be updated remotely, without the need to return the product to Norbar
- Supplied with traceable calibration certificate in clockwise direction. A counter-clockwise calibration is available at additional cost

## DIMENSIONS & WEIGHT

**Tool Weight:** 5.00


**Packed Weight:** 5.50

**Dimensions:** 100 x 60 x 30 mm

**Packed Length:** 620.00

**Packed Height:** 520.00

**Packed Width:** 270.00

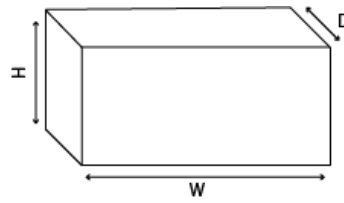

---

NORBAR TORQUE TOOLS LTD. Wildmere Road, Banbury, Oxfordshire,  
OX16 3JU, United Kingdom  
Registered Office as above - Registered in England No. 380480 - VAT No.  
GB 119 1060 05

- Tel: + 44 (0) 1295 270333
- Enquiries: + 44 (0) 1295 753600
- After Sales : + 44 (0) 1295 753635
- Fax: + 44 (0) 1295 753609
- Email: [enquiry@norbar.com](mailto:enquiry@norbar.com)
- Repairs: [repairs@norbar.com](mailto:repairs@norbar.com)