



TENSATOR LIMITED
DANBURY COURT, LINFORD WOOD
MILTON KEYNES, BUCKS, MK14 6TS, UK

tel: +44 (0) 1908 684 600
fax: +44 (0) 1908 684 700

info@tensator.com
www.tensator.com

Post & Rope

Proudly offering the full
Lawrence Metal product line

LAWRENCE
EST. 1881

UK	USA	UAE	Poland	Germany	France
+44 1908 684600	+1 631 666 0300	+971 4 2997228	+48 71 359 3800	+49 69 3003 890-0	+33 1 43 09 85 00

Post and Rope Stanchions by Lawrence

LAWRENCE
EST. 1881

For over a century the Lawrence name has been recognised as the hallmark of the finest quality design, manufacturing and customer service for the world's hospitality industry.

The Lawrence brand can be traced back to a small metal-fabricating shop founded in 1881 in New York City. Surviving two world wars, including a temporary closure in the 1940s when all metals were diverted to the war effort, the brand forged its reputation as the world's premier manufacturer of decorative crowd control stanchions under the name Lawrence Metal Products.

In 2006, Tensator acquired the company and the world famous Lawrence brand. Today, more than 130 years later, Tensator is proud to offer the full and finest range of Lawrence post and rope stanchions throughout its global network of companies and sales partners.

Over the years, Lawrence stanchions have seen off more than their fair share of look-a-like competitors, but, with heritage dating back to 1881, why would you take a chance on a "here today, gone tomorrow" provider, when you can have the real deal for a lot less than you might think.

As track records go, we think over 130 years of producing the finest quality products is pretty hard to beat. So for quality you can rely upon, at affordable prices, buy your own piece of history; buy Lawrence from Tensator.




How to Order


1. Select post design




2. Select post colour

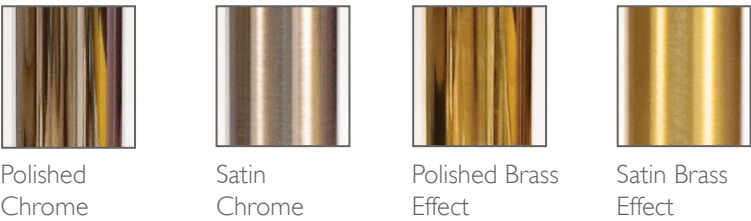

3. Pick rope colour, style and length

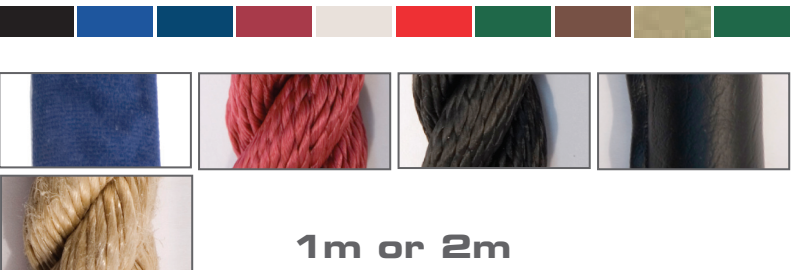


4. Choose colour of snap end connectors

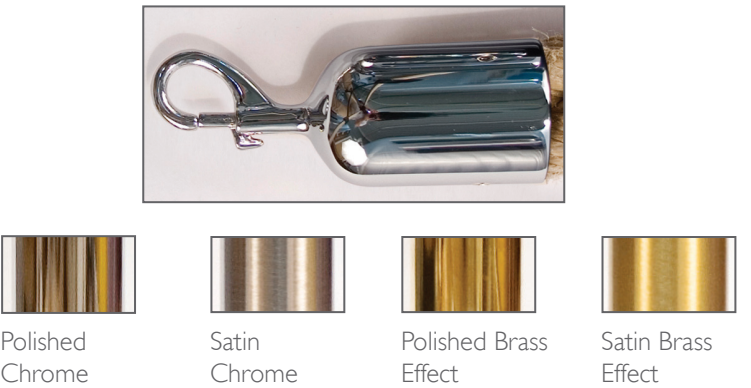

5. Select accessories



Classic Post

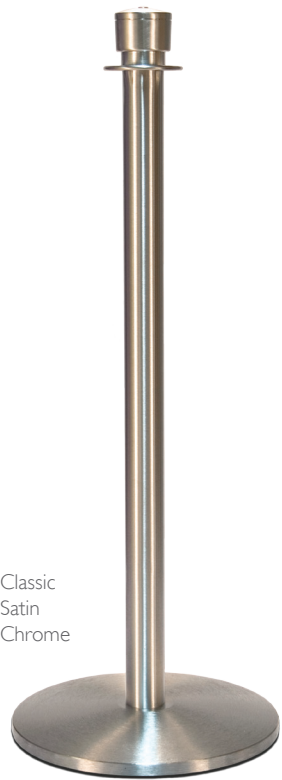


Height	905 mm/35.63"
Base dia	345mm/13.50"

The classic top post design is our best selling stanchion. This sleek and stylish post measures 905mm high with a post head measuring 54mm high.

- Available in Polished Chrome, Satin Chrome, Polished Brass Effect or Satin Brass Effect finishes as standard
- Additional colours and finishes available on request
- Universal base (to match post colour) as standard
- Alternative base options including more permanent surface fixed and sturdy removable posts are available and installed on request
- Push-in pip to accommodate sign holders
- Forged universal 4 way loop
- Maximum rope length is 2m
- Order code: 310U

Colour Switch

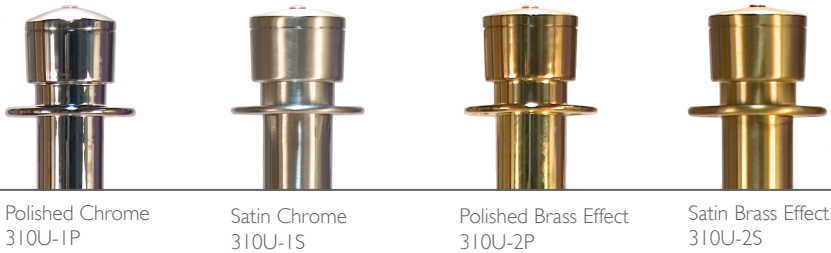

Sphere Post




Height	955 mm/35.63"
Base dia	345mm/13.50"

The elegant sphere ball-top post design is favoured by high-status locations around the world. Measuring 955mm high, with a 120mm post head, the Sphere Post is a prestigious post choice.

- Available in Polished Chrome, Satin Chrome, Polished Brass Effect or Satin Brass Effect finishes as standard
- Additional colours and finishes available on request
- Universal base as standard (to match post colour)
- Alternative base options including more permanent surface fixed and sturdy removable posts available and installed on request
- Forged universal 4 way loop
- Please note that the Sphere Post is not compatible with sign holders
- Maximum rope length is 2m
- Order code: 312U

Colour Switch

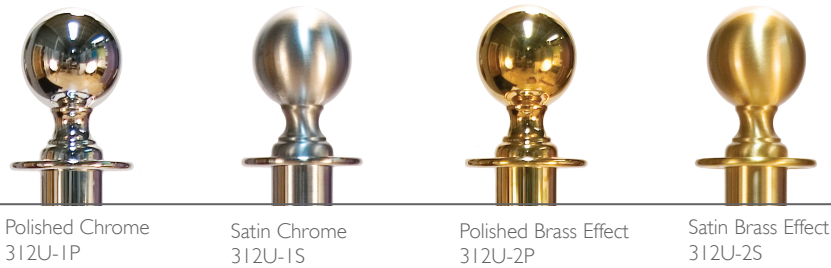

Contemporary Post




Height	855mm/33.66"
Base dia	345mm/13.50"

The Contemporary Post is both modern and modest, making it the ideal stanchion for everyday environments. At 855mm high and with a post head that measures just 20mm high, the Contemporary Post will not distract attention from buildings or exhibits on display.

- Available in Polished Chrome, Satin Chrome, Polished Brass Effect or Satin Brass Effect finishes as standard
- Additional colours and finishes available on request
- Universal base (to match post colour) as standard
- Alternative base options including more permanent surface fixed and sturdy removable posts are available and installed on request
- Push-in pip to accommodate sign holders
- Forged universal 4 way loop
- Maximum rope length is 2m
- Order code: 314U

Colour Switch

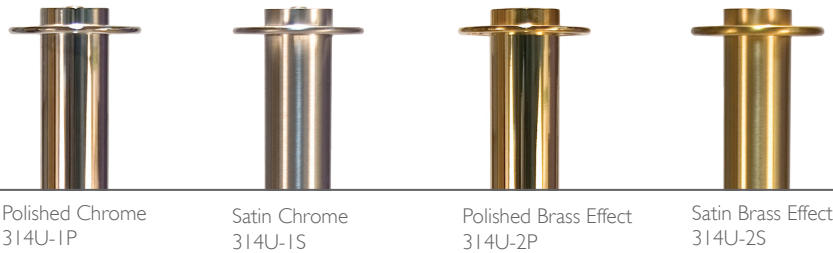

Rope Length

Rope is available in 1m and 2m length price breaks (with the exception of velour, which is sold in 2m lengths only). We can cut down rope lengths to match your exact requirements, and recommend the maximum rope length (distance between our posts) is 2m.

To create the optimum layout, we suggest the following:

- Take the tight measurement from the centre of one post to the centre of the other post
- Add 10% to the length, to allow sufficient hang
- Round up to a 1m or 2m rope length and specify the exact sizing when ordering

For example: The measurement is 1.2m, adding 10% would make it 1.3m. So order a 2m rope length, and specify that you require 1.3m when ordering.

To provide maximum flexibility should you ever need to reconfigure your layout, we advise you to buy ropes in a selection of 1m and 2m lengths.



Rope Styles and Colours

Tensator offers a selection of rope styles and colours, to match your corporate colours and best suit your environment.

Twisted Rope

A hardwearing yet stylish 25mm / 1" diameter rope; available in a choice of 4 colours. Available in 1m or 2m rope lengths. Order code: 443-**



48 Beige

- 33 Black
- 25 Royal Blue
- 43 Burgundy
- 48 Beige

Polyhemp Rope

For a study natural rope, which will complement any environment, opt for a 38mm / 1.5" diameter polyhemp rope. Available in 1m or 2m lengths. Order code: 545-**



50 Natural

- 50 Natural

Braided Rope

Our lowest priced durable 25mm / 1" diameter rope is available in a selection of 3 practical colours. Braided rope is available in 1m or 2m lengths. Order code: 446-**



33 Black

- 33 Black
- 23 Blue
- 21 Red

Velour Rope

Create a VIP queue with luxurious 38mm / 1.5" diameter velour rope. Velour rope is available in 2m lengths with a choice of 5 colour options. Order code: 541-**




43 Burgundy

- 33 Black
- 25 Royal Blue
- 43 Burgundy
- 48 Beige
- 29 Hunter Green

Naugahyde Rope

Our 38mm / 1.5" diameter Naugahyde rope features a leather like cover, but provides the durability and easy cleaning of vinyl. Available in 5 colour options and 1m or 2m rope lengths. Order code: 542-**

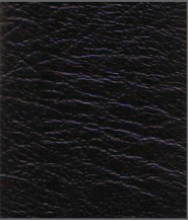

33 Black

- 33 Black
- 43 Burgundy
- 21 Red
- 29 Dark Green
- 47 Walnut Brown



Snap Ends

Our spring loaded snap ends are available in 4 colours, to enable you to elegantly match the snap end to your post colour. Please note each piece of rope requires two snap ends. The type of rope you select will determine the snap end size that you require; we offer 25mm / 1" and 38mm / 1.5" diameters in all 4 finishes.



 
Polished Chrome




Polished Chrome



Satin Chrome



Polished Brass Effect

 

Satin Brass Effect

	Polished Chrome	Satin Chrome	Polished Brass Effect	Satin Brass Effect
25mm / 1" Diameter	450-IP	450-IS	450-2P	450-2S
38mm / 1.5" Diameter	550-IP	550-IS	550-2P	550-2S

 
Accessories

Wall Plates

Wall Plates provide an alternative method to connect rope to a wall or other vertical surface (saving the expense of an additional post). Wall plates provide a discreet solution, perfect for when doorways or corridors require cordoning off. Wall plates are available in 4 finishes and can accept 2 snap ends on each plate.




Polished Chrome



Satin Chrome



 Polished Brass Effect




Satin Brass Effect

Polished Chrome	Satin Chrome	Polished Brass Effect	Satin Brass Effect
509-IP	509-IS	509-2P	509-2S

Signage

Add directional guidance to your queue layout with post top signage.

- Compatible with Classic and Contemporary Posts only
- Frame screws into top of post, when push-in pip is removed
- A novel way to inform, communicate and promote with the queue
- Choice of A3 or A4 sign holders
- Available in portrait or landscape orientation
- Frame width is 11mm all round
- Customised sign insert graphics are available to order
- Selection of 4 finish options to match post finishes

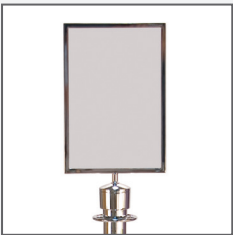

Polished Chrome



Satin Chrome



Polished Brass Effect



Satin Brass Effect

Finish	Size	Orientation	Order Code
Polished Chrome	A4	Portrait	RP-SHA4P-IP
Polished Chrome	A4	Landscape	RP-SHA4L-IP
Polished Chrome	A3	Portrait	RP-SHA3P-IP
Polished Chrome	A3	Landscape	RP-SHA3L-IP
Satin Chrome	A4	Portrait	RP-SHA4P-IS
Satin Chrome	A4	Landscape	RP-SHA4L-IS
Satin Chrome	A3	Portrait	RP-SHA3P-IP
Satin Chrome	A3	Landscape	RP-SHA3L-IP
Polished Brass Effect	A4	Portrait	RP-SHA4P-IP
Polished Brass Effect	A4	Landscape	RP-SHA4L-IP
Polished Brass Effect	A3	Portrait	RP-SHA3P-IP
Polished Brass Effect	A3	Landscape	RP-SHA3L-IP
Satin Brass Effect	A4	Portrait	RP-SHA4P-IP
Satin Brass Effect	A4	Landscape	RP-SHA4L-IP
Satin Brass Effect	A3	Portrait	RP-SHA3P-IP
Satin Brass Effect	A3	Landscape	RP-SHA3L-IP