


Masking frame 3VA13 (400 A), 3VA14 (630 A), 3VA23 (400 A), 3VA24 (630 A), 4-pole, fixed-mounted, plug-in design, drive: direct, front-mounted rotary operator, motorized operating mechanism, RCD: without, H: 450 mm W: 800 mm

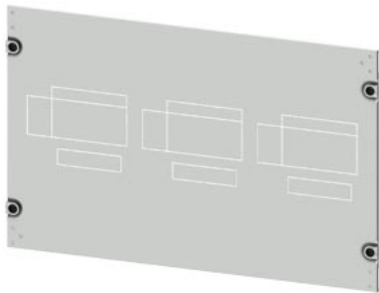

Model	
product brand name	SIVACON S4
design of the surface	powder-coated
net weight	3 kg
height	450 mm
width	800 mm
depth	10 mm
installation width for cabinet installation	800 mm
mounting height for device equipment can be used	450 mm
material	sheet-steel
reference code according to IEC 81346-2	UC

Approvals Certificates	
General Product Approval	other

[Miscellaneous](#)



[Confirmation](#)

Environment

[Environmental Con-
firmations](#)

[Environmental Con-
firmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ2045-8BA14>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8PQ2045-8BA14>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ2045-8BA14
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

