

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0451300210](#)
Status: **Active**
Overview: [Nano-Fit™ Power Connectors](#)
Description: Nano-Fit™-to-Nano-Fit™ Off-the-Shelf (OTS) Cable Assembly, Single Row, 1.0m Length, 2 Circuits, Black

Documents:

[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	45130
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Nano-Fit™-to-Nano-Fit™
Overview	Nano-Fit™ Power Connectors
Product Literature Order No	987651-6143
Product Name	Nano-Fit™ OTS
UPC	191128141949

Physical

Cable Length	1.0m
Circuits (Loaded)	2
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	High Conductivity Copper
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	14.261/g
Packaging Type	Bag
Pitch - Mating Interface	2.50mm
Plating min - Mating	0.381µm
Plating min - Termination	2.540µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.46mm
Wire Size AWG	20
Wire/Cable Type	UL 1061


Electrical

Current - Maximum per Contact	6.5A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers

Sales Drawing	2012341657-000
---------------	----------------

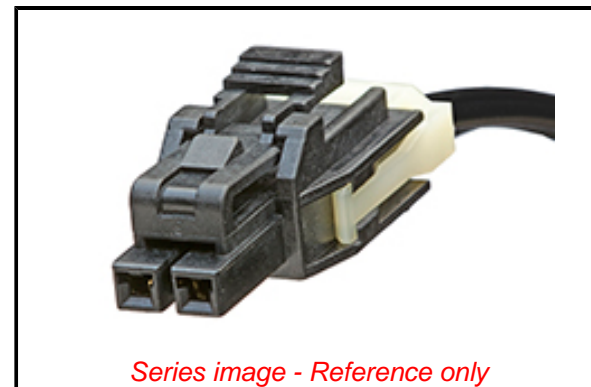

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[45130](#) Series

Mates With

Nano-Fit™ Headers [105309](#) , [105311](#) , [105313](#)