

For professionals from professionals

Bosch is your reliable partner for trade and industry. Since you are important to us, we also want to ensure that you are always kept up-to-date in future by providing you with information about our new professional blue products and special services. To enable us to do this, all you have to do is fill out this contact form and send it to the address stated on the back of this brochure.

Company _____
 Mr _____
 Ms _____
 Street, No. _____
 Postal code, City _____
 Telephone _____ Fax _____
 e-Mail _____

WR 05/09 GB

Yes, I would also like to receive information from Bosch by e-mail in future.

Position Owner/Manager Responsible for purchasing power tools Other position

How many power tools do you have at your company?

1-19 20-49 50-99 ≥ 100

Which sector does your company work in?

- | | |
|---|---|
| <input type="checkbox"/> Roofer/Carpenter | <input type="checkbox"/> Structural engineering |
| <input type="checkbox"/> Joiner/Cabinet maker | <input type="checkbox"/> Underground engineering |
| <input type="checkbox"/> Furniture manufacture/Furniture industry | <input type="checkbox"/> Other building trade |
| <input type="checkbox"/> Other woodworking | <input type="checkbox"/> Automobile trade/repair |
| <input type="checkbox"/> Painter/Decorator | <input type="checkbox"/> Automotive industry |
| <input type="checkbox"/> Floor fitter (tiles) | <input type="checkbox"/> Other vehicle construction |
| <input type="checkbox"/> Floor fitter (wood) | <input type="checkbox"/> Machine construction |
| <input type="checkbox"/> Electrical installation | <input type="checkbox"/> Locksmith |
| <input type="checkbox"/> Plumber | <input type="checkbox"/> Steelworking/Metalworking |
| <input type="checkbox"/> Heating/ventilation installation | <input type="checkbox"/> Other _____ |

Yes, I would like to receive information from Bosch in future.

I agree that the data collected by Robert Bosch GmbH and its sales organisation in Germany shall be saved and used to inform me about products and services. I can obtain information about the data stored about me from Robert Bosch GmbH, Power Tools, 71518 Backnang, Germany. This consent can be revoked from Robert Bosch GmbH at the above-mentioned address at any time.

Yes, I agree that selected, local Bosch specialist retailers shall inform me about products and services and that my data shall be passed on for this purpose.

Date/Signature _____

Woodworking tools for professionals from professionals

Saws



Routers, Planers, Sanders



Benchtop Tools



Cordless Screwdrivers



16189001817 - 04/11/10 - GB - Printed in Federal Republic of Germany - Informa en République Fédérale d'Allemagne - We reserve the right to change technical details without prior notice. No responsibility taken for printing errors.



Woodworking expertise: Power and precision



*For all professional blue power tools when registered within 4 weeks of purchase at www.bosch-professional.com/warranty

Robert Bosch Limited
Power Tools Division
 P.O. Box 98, Broadwater Park
 North Orbital Road, Denham,
 Uxbridge, Middlesex UB9 5HJ
 Tel: 0844 736 0107



Range for 2009/2010:
 Professional blue woodworking tools
 for professionals from professionals



www.bosch-professional.com

Developed for professionals, tested by professionals

As a professional in the woodworking trade, a lot is expected of you: speed, reliability and competence – in short: excellent results.

So isn't it only fair to demand the same from your power tools?

The professional blue power tools for woodworking are engineered for excellence – meeting the highest standards in speed, precision and robustness. They therefore give you everything you need to achieve great, professional work results.

When developing new blue power tools, Bosch works very closely with real professionals who use power tools as part of their everyday work and who also test the tools in extreme conditions. This means that you, the professional, can always count on this absolutely reliable technology.

Professional blue power tools for woodworking – Impressive solutions for professionals from professionals.



Saws 4

- ▶ Jigsaws 6
- ▶ Hand-held Circular Saws 8
- ▶ Sabre Saws 10
- ▶ Cordless Multi-Cutter 11

Routers, Planers, Sanders 12

- ▶ Routers 14
- ▶ Planers 16
- ▶ Orbital Sanders 17
- ▶ Random Orbit Sanders 18

Benchtop Tools 20

- ▶ Combination Saw 22
- ▶ Sliding Mitre Saws 22
- ▶ Bench Circular Saw 23

Cordless Screwdrivers 24

- ▶ 3.6 Volt Cordless Screwdriver 26
- ▶ 10.8 Volt Cordless Drill/Driver 26
- ▶ 14.4 Volt Cordless Drill/Driver 26
- ▶ 18 Volt Cordless Drill/Driver 27
- ▶ 36 Volt Cordless Drill/Driver 27

Tool Transport 28

- ▶ Systainer Carrying Cases 28
- ▶ Transport and Work Benches 28



“This tool is very easy to use. I don’t know of any jigsaw that even compares when it comes to achieving high-quality and precise work results.”

Thomas Sutter, joiner, WorldSkills champion in cabinetmaking

The right saws for every job

Bosch offers the right tool for every woodworking application with its professional blue range of saws: Bosch jigsaws offer maximum precision when cutting parquet and kitchen worktops. The hand-held circular saws perform impressively, even in extreme continuous use, due to their high power: e.g. when sawing roof panels or cutting roof beams to length. The sabre saws also impress when used for renovation work due to their reliability.

-
- ▶ **Jigsaws** P.6
 - ▶ **Hand-held Circular Saws** P.8
 - ▶ **Sabre Saws** P.10
 - ▶ **Cordless Multi-Cutter** P.11

Leader in precision: Blue Bosch jigsaws for professionals



Patented Bosch Precision Control for cutting at accurate angles:

Bosch Precision Control enables you to achieve precise work results, even in thick wood, sandwich materials and thin sheet metal. At the push of a button, the guide jaws adjust themselves precisely to the thickness of the saw blade, therefore holding it firmly in place and giving it additional support at the sides. This reduces vibration and guarantees uniquely precise cuts at accurate angles.

Jigsaws GST 135 CE and BCE Professional:
Unique: precision at the push of a button

- ▶ At the push of a button, the “Precision-Control” guide jaws adjust themselves automatically to the different saw blade thicknesses for cutting at accurate angles and for more precise guidance
- ▶ Highest possible convenience with Bosch “SDS”, the world’s easiest way to change saw blades – using only one hand
- ▶ Constant sawing progress even under load due to Constant Electronic



Jigsaws with 135 mm cutting depth at a glance

	GST 135 CE Professional	GST 135 BCE Professional
Rated power input	720 W	720 W
Cutting depth in wood	135 mm	135 mm
Cutting depth in aluminium	20 mm	20 mm
Cutting depth in unalloyed steel	10 mm	10 mm
Part number 110 V	0 601 510 760	0 601 511 762
Part number 240 V	0 601 510 761	0 601 511 763

More information about the professional blue power tools and accessories can be found at www.bosch-professional.com.

From the inventor of the jigsaw: The result of over 60 years of experience

Bosch is the inventor of the jigsaw. And not only that: many technical innovations in jigsaws are Bosch developments. The latest example: the Jigsaws **GST 135 CE and BCE Professional** with Precision Control and other solutions enable high-precision working.

Professional stacked construction and **aluminium housing** for long lifetime

Bosch SDS for fast one-handed saw blade changes

Swivel-mounted sole plate for easy mitre cuts and **glide shoe** to prevent damage to the surface

“**Extra clean for wood**” jigsaw blades for tear-free cut edges

Constant Electronic for constant sawing progress, even under load

Dust extraction outlet for connecting to dust extraction systems

Air blower function for optimum visibility

Bosch Precision Control

- ▶ At the push of a button, the guide jaws adjust themselves automatically to different saw blade thicknesses
- ▶ Uniquely precise guidance
- ▶ Cutting at accurate angles

1944



Bosch GEB 1: Bosch invents the first jigsaw for professional tradesmen



Bosch 8554: Bosch launches the first jigsaw with pendulum action onto the market



Bosch P 10: Bosch presents the first jigsaw with swivel-mounted sole plate for professionals



Bosch GST 60 PAE: Bosch develops the first jigsaw with tool-free saw blade changes



Bosch GST 135 CE and BCE Professional: Bosch presents the first jigsaw with tool-free switchable saw blade guidance (Precision Control)

2009

Bosch invented the jigsaw over 60 years ago and has continually developed it further ever since. The latest innovation is the Bosch Precision Control. The saw blade is precisely adjusted and fixed at the push of a button. For you, the professional, this means absolutely precise cuts at accurate angles.



Tear-free cuts on both sides with Bosch "extra clean for wood":

Bosch is the world's market leader for jigsaw blades and offers the most comprehensive range of saw blades on the market. The new "extra clean for wood" jigsaw blades are unlike any other in the world. The integrated pre-cutting function enables you to make absolutely clean and tear-free cuts. There is no need to sand the workpiece after sawing.

Jigsaws GST 120 E and BE Professional:
The sturdy tools for heavy-duty applications

- ▶ The reliable tool for the toughest jobs
- ▶ Long lifetime under extreme conditions thanks to robust SDS saw blade changing system
- ▶ Professional stacked construction and aluminium housing for long lifetime



Jigsaws with 120 mm cutting depth at a glance

	GST 120 E Professional	GST 120 BE Professional
Rated power input	650 W	650 W
Cutting depth in wood	120 mm	120 mm
Cutting depth in aluminium	20 mm	20 mm
Cutting depth in unalloyed steel	10 mm	10 mm
Part number 110 V	0 601 510 662	0 601 511 662
Part number 240 V	0 601 510 663	0 601 511 663

More information about the professional blue power tools and accessories can be found at www.bosch-professional.com.

Bosch Hand-held Circular Saws have been specially developed to meet the requirements of the building trade. Their powerful motors provide extremely high torque and they set new standards combined with their compact design and their low weight. This makes them perfect for convenient working, even when used for long periods of time.

Hand-held Circular Saw GKS 55 Professional:
The compact, robust circular saw

- ▶ Low weight and compact design for optimum handling
- ▶ Powerful 1200-watt motor
- ▶ Punched aluminium base plate and closed pendulum guard made of die-cast aluminium can withstand even hard impacts



Circular saws with 55 mm cutting depth at a glance

	GKS 55 Professional
Rated power input	1.200 W
Cutting depth (90°)	55 mm
Saw blade diameter	160 mm
Weight	3.5 kg
Part number 240 V	0 601 664 070

only available in 240 V



Extremely robust for lasting high performance:

The closed pendulum guard without spacer wedge remains fully functional, even after being dropped from a height of two metres. The break-resistant aluminium base plate with integrated rail guide guarantees absolutely perfect cuts.

More information about the professional blue power tools and accessories can be found at www.bosch-professional.com.

The perfect blade for every cut:

Bosch offers a wide range of circular saw blades – for perfect cuts in hardwood, MDF or particle board. The guide rails from Bosch in lengths of 700 mm and 1.400 mm also help you to achieve perfectly straight cuts.



Hand-held Circular Saw GKS 65 Professional:
The powerful circular saw

- ▶ Powerful 1600-watt motor
- ▶ Punched aluminium base plate and closed pendulum guard made of die-cast aluminium can withstand even hard impacts
- ▶ Lowest weight in its class for optimum handling



Hand-held Circular Saw GKS 85 Professional:
The high-torque circular saw

- ▶ Extremely resilient 2200-watt motor for high torque in solid wood beams of any moisture content up to 85 mm cutting depth
- ▶ Punched metal base plate and closed pendulum guard made of die-cast aluminium can withstand even hard impacts
- ▶ Optimised chip deflector and turbo blower for a clear view of the score line and precise cut guidance



Circular saws with 65–85 mm cutting depth at a glance

	GKS 65 Professional	GKS 85 Professional	NEW! GKS 190 Professional
Rated power input	1.600 W	2.200 W	1.400 W
Cutting depth (90°)	65 mm	85 mm	70 mm
Saw blade diameter	190 mm	235 mm	190 mm
Weight	4.8 kg	7.5 kg	4.2 kg
Part number 110 V	0 601 667 060	0 601 57A 060	0 601 623 060
Part number 240 V	0 601 667 070	0 601 57A 070	0 601 623 070

More information about the professional blue power tools and accessories can be found at www.bosch-professional.com.

Bosch Sabre Saws have more power but less vibration. They master every job reliably, quickly and precisely thanks to their overload-capable motors and Bosch Vibration Control.

Bosch sabre saw blades for every material:

Brick, metal, iron, aluminium, wood and plastic – the sabre saw blades from Bosch make better cuts in every material. The SDS system on Bosch sabre saws makes it possible to change the saw blade in seconds.



NEW! Sabre Saw GSA 1500 PCE Professional: The highest sawing progress with 15% less vibration

- ▶ 1500-watt high-performance motor with Constant Electronic for the highest sawing progress in its class
- ▶ Vibration Control handle and mass balance for the lowest vibration level in its class
- ▶ Pendulum mechanism for fast sawing progress in every material



Available from October 2009!

The new sabre saws at a glance

	NEW! GSA 1100 E Professional	NEW! GSA 1300 PE Professional	NEW! GSA 1500 PCE Professional
Rated power input	1.100 W	1.300 W	1.500 W
Cutting depth in wood	245 mm	245 mm	245 mm
Saw, stroke length	28 mm	32 mm	32 mm
Weight	3.9 kg	4.4 kg	4.5 kg
Part number 110 V	0 601 64C 860	0 601 64K 660	0 601 64C 660
Part number 240 V	0 601 64C 870	0 601 64K 670	0 601 64C 670

More information about the professional blue power tools and accessories can be found at www.bosch-professional.com.

The Bosch Cordless Multi-Cutter enables perfect trimming, adjusting and repairing – without a cable. This makes it versatile for use in shop, kitchen and furniture fitting.

NEW! Cordless Multi-Cutter GOP 10.8 V-LI Professional: Perfect trimming, adjusting, repairing

- ▶ Wide range of applications such as plunge cuts, flush sawing and sanding due to comprehensive range of accessories
- ▶ Excellent handling due to compact design and weight of only 1 kg
- ▶ Up to 20,000 oscillations per minute for the same professional performance as comparable mains-powered tools



	NEW! GOP 10,8 V-LI Professional
Battery voltage	10.8 V
Battery capacity	1.3Ah Premium
No-load speed	5.000–20.000 min ⁻¹
Weight incl. battery	1 kg
Part number	0 601 858 071

Accessories for Cordless Multi-Cutter GOP 10.8 V-LI Professional



The Bosch Cordless Multi-Cutter can perform the following tasks:

- ▶ plunge cuts
- ▶ flush sawing
- ▶ sanding, even in tight spaces
- ▶ and many more. And it does so without a cable, of course.

More information about the professional blue power tools and accessories can be found at www.bosch-professional.com.



“I’ve been impressed by the precision of the GMF 1400 CE Professional. It’s ideal for routing with templates thanks to its low centre of gravity.”

Andy King, joiner

Perfect surfaces when **routing, planing and sanding**

There is no room for error when working on surfaces: as a professional, you want clean edges when routing. Material removal accurate to the millimetre when planing. Perfect surfaces when sanding. Bosch has the right power tool for every application, so that you can achieve excellent results without having to make compromises. Bosch therefore offers a perfect combination of power and precision.

-
- ▶ **Routers** P.14
 - ▶ **Planers** P.16
 - ▶ **Orbital Sanders** P.17
 - ▶ **Random Orbit Sanders** P.18

Bosch Routers set standards in precision. Whether you want to rout corner profiles and grooves in solid wood or board materials, round off frames or chamfer veneered surfaces – the unique Bosch “fine adjustment system” guarantees precise results. Your advantage: precision for every range of applications.

Palm Router GKF 600 Professional:

The handy specialist for edges

- ▶ Very compact design and ergonomic grip area allow for one-handed guidance, especially for working on edges
- ▶ Continuously variable routing depth adjustment using the setting wheel and tight fitting of the motor enable exact setting and repeatable precision
- ▶ Comprehensive range of accessories in a sturdy carrying case for the many requirements of working on edges



Multifunction Router GMF 1400 CE Professional:

The flexible plunge-cutting and copy router

- ▶ Multifunction router: combination of plunge-cutting and copy router for perfect completion of all kinds of routing work
- ▶ SDS quick-change system: tight fitting of the separate motor block either in the plunge-cut or copy unit
- ▶ Powerful 1400-watt motor block in a robust aluminium housing with Constant Electronic for constant work progress



The guide rail for Bosch circular saws can also be used for the routers when combined with the Bosch guide rail adapter. This enables you to make absolutely exact grooves and cutouts.



Router GOF 2000 CE Professional:

The robust precision plunge-cutting router

- ▶ Robust 2000-watt motor, which has sufficient power reserves for large routing diameters with its Constant Electronic
- ▶ Lockable setting wheels and clamp levers guarantee repeatable precision up to 1/10 mm accuracy
- ▶ The suspension of the plunge-cut function can be switched off for more convenient working at large routing depths and in bench-mounted use



Biscuit Jointer GFF 22 A Professional:

The precise specialist tool for wood joints

- ▶ Robust metal angle guides with embossed scales and lock-in points enable precise settings for accurate joints
- ▶ 670 watts provide optimum power for making frame, corner, longitudinal and cross joints
- ▶ Tool-free routing depth adjustment for fast work progress



All routers at a glance

	Palm Router GKF 600 Professional	Multifunction Router GMF 1400 CE Professional	Router GOF 900 CE Professional	Router GOF 1300 CE Professional	Router GOF 2000 CE Professional		Biscuit Jointer GFF 22 A Professional
Rated power input	600 W	1.400 W	900 W	1.300 W	2.000 W	Rated power input	670 W
No-load speed	33.000 min ⁻¹	8.000–24.000 min ⁻¹	12.000–24.000 min ⁻¹	12.000–24.000 min ⁻¹	8.000–21.000 min ⁻¹	Max. cutting depth	22 mm
Toolholder	6–8 mm	8–12.7 mm	6–8 mm	6–12.7 mm	8–12.7 mm	Blade cutter diameter	105 mm
Maximum router cage stroke	–	59 mm	50 mm	58 mm	65 mm	Blade cutter diameter, bore	22 mm
Part number 110 V	–	0 601 617 860	0 601 614 641	0 601 613 641	0 601 619 741	Part number 110 V	0 601 620 041
Part number 240 V	0 601 60A 170	0 601 617 870	0 601 614 642	0 601 613 642	0 601 619 742	Part number 240 V	0 601 620 042

Bosch Planers work extremely powerfully and very precisely with only one planer blade thanks to their powerful motors and the unique Woodrazor system. Bosch planers enable you to achieve perfect surfaces without the need for subsequent finishing work. This saves time and money.

Planer GHO 26-82 Professional:

The handy planer with lots of power

- ▶ Small, handy machine with powerful 710-watt motor, ideal for all on-site fitting work
- ▶ The fastest and least expensive blade changes on the market due to durable Woodrazor reversible blades and the easiest possible adjustment
- ▶ Comfortable working due to chip clearance to left or right, as desired



Planer GHO 40-82 C Professional:

The planer for extremely high surface quality

- ▶ The highest surface quality due to ultra-sharp blades and constant speed, even when working in hardwood
- ▶ The fastest and least expensive blade changes on the market due to durable Woodrazor reversible blades and the easiest possible adjustment
- ▶ The longest lifetime due to precise aluminium bearing seat and thermodynamic motor protection




Planers at a glance

	GHO 26-82 Professional	GHO 40-82 C Professional
Rated power input	710 W	850 W
Planing width	82 mm	82 mm
Adjustable depth of cut	0–2.6 mm	0–4 mm
Adjustable rebating depth	0–9 mm	0–24 mm
Part number 110 V	0 601 594 341	0 601 59A 764
Part number 240 V	0 601 594 342	0 601 59A 762

The 1-blade Woodrazor system for perfect surfaces:

The patented Bosch Woodrazor system has only one planer blade, so you no longer have to go to the trouble of aligning a second blade, and optimum results are guaranteed. The Bosch Woodrazor reversible blades are hard-wearing, ultra-sharp and durable for perfect surfaces without the need for subsequent finishing work.

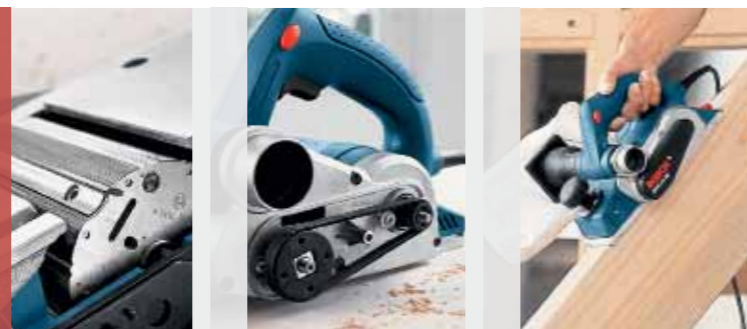


More information about the professional blue power tools and accessories can be found at www.bosch-professional.com.

Bosch Orbital Sanders excel due to their high material removal rate and extremely fine surface finish. They achieve the highest surface quality on every material thanks to their particularly easy handling and optimised speeds.

Putting an end to fine dust:

Bosch is the only manufacturer with a certification for air purity. The Bosch micro-filters collect 90% of dusts, even particles 100 times finer than a human hair. Another advantage is the collection box, which removes the need for expensive filter bags.

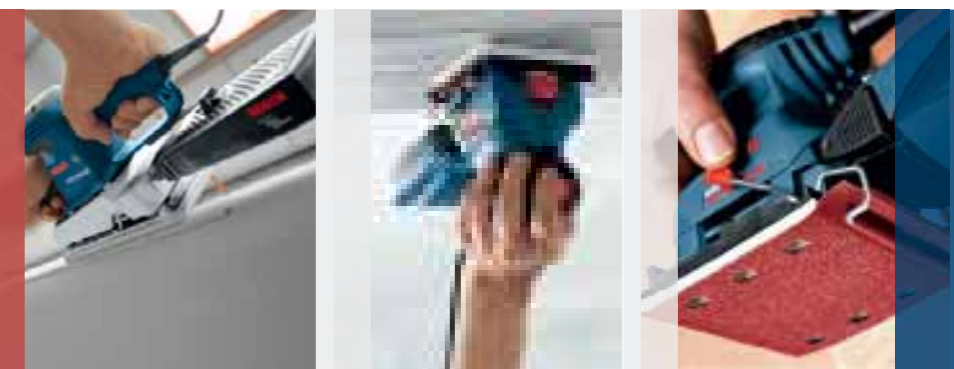

Orbital Sander GSS 140 A Professional:

Every type of sanding sheet sits perfectly with Easy-Fit

- ▶ A perfect hold of the paper without creasing and tearing due to Bosch Easy-Fit system – for Velcro-type paper and rolls of paper
- ▶ Bosch micro-filter system: perfect, efficient dust extraction
- ▶ Ergonomic design with two softgrip surfaces for two grip positions



Orbital Sander GSS 280 AE Professional:

The sander for extremely high surface quality

- ▶ High-quality sanding plates for the best surface quality and 5 times longer lifetime than rubber sanding plates
- ▶ Quiet and low-vibration for more comfortable working
- ▶ Best bearing seal and high-quality aluminium bearing flange for smooth running and long lifetime of the motor



Orbital sanders at a glance

	GSS 140 A Professional	GSS 230 AE Professional	GSS 280 AE Professional
Rated power input	180 W	300 W	330 W
Oscillating circuit diameter	1.6 mm	2.4 mm	2.4 mm
Sanding plate, width	113 mm	92 mm	114 mm
Sanding plate, length	105 mm	182 mm	226 mm
Part number 110 V	0 601 297 088	0 601 292 662	0 601 293 662
Part number 240 V	0 601 297 090	0 601 292 663	0 601 293 663

More information about the professional blue power tools and accessories can be found at www.bosch-professional.com.

Bosch Random Orbit Sanders ensure perfect surface results, even on curved and shaped workpieces. Excellent running smoothness and the freewheel brakes guarantee a surface finish free of scores and a high material removal rate.

The versatile GEX 150 Turbo Professional:

From fine sanding to coarse sanding or polishing with one click. Five times more material removal when coarse sanding in turbo operation. This time-saving means that the tool pays for itself after only a few working hours.



Random Orbit Sander GEX 150 Turbo Professional:
Three tools in one

- ▶ Just one click: switch from fine sanding to coarse sanding or polishing
- ▶ Five times more material removal in turbo operation (coarse sanding); the time-saving means that the tool pays for itself after a few working hours
- ▶ Longest lifetime thanks to perfect bearing seals, overload protection and a robust turbo switch



	GEX 150 Turbo Professional
Rated power input	600 W
Sanding pad diameter	150 mm
Oscillating circuit diameter	4.5 mm
No-load speed	3.100–6.650 min ⁻¹
Part number 110 V	0 601 250 782
Part number 240 V	0 601 250 783

Random Orbit Sander GEX 125-1 AE Professional:

Comfortable sanding in any work position

- ▶ Compact, ergonomic design with large softgrip surfaces for variable grip positions and outstanding convenience
- ▶ Bosch micro-filter system: perfect, efficient dust extraction
- ▶ Speed preselection for work suited to the material



Random Orbit Sander GEX 150 AC Professional:

The sander with high material removal rate

- ▶ The random orbit motion plus rotation ensures the finest finish with high sanding performance
- ▶ Aluminium bearing flange for long lifetime and high running smoothness
- ▶ Control Electronic and speed preselection, i.e. the right speed for every application



	GEX 125-1 AE Professional	GEX 125 AC Professional	GEX 150 AC Professional
Rated power input	250 W	340 W	340 W
Sanding pad diameter	125 mm	125 mm	150 mm
Oscillating circuit diameter	2.5 mm	5 mm	4 mm
No-load speed	7.500–12.000 min ⁻¹	4.500–12.000 min ⁻¹	4.500–12.000 min ⁻¹
Part number 110 V	0 601 387 561	–	0 601 372 662
Part number 240 V	0 601 387 571	0 601 372 483	0 601 372 663



The ideal special extractor for wood:

Dust-free working with Bosch woodworking tools: the GAS 50 M Professional is the certified special extractor for wood dusts. It extracts the dust with ease, and it fits on virtually all tools thanks to its flexible rubber sleeve. The Plus-Clean electromagnetic filter cleaning system ensures constant, maximum suction power.



“The great thing about this saw is its versatility. It gives me everything I need on the construction site: both a table saw function and a mitre saw function. The laser ensures maximum safety when sawing and gives me the required feel for precision.”

Thomas Haag, master interior fitter

Benchtop tools for precise work in any type of wood

Bosch benchtop tools are the perfect combination of power and precision. High-torque motors and high-quality features like the integrated laser allow for fast, precise work in any type of wood. This is why Bosch benchtop tools are used wherever accurate and fast work are required.

-
- ▶ **Combination Saw** P.22
 - ▶ **Sliding Mitre Saws** P.22
 - ▶ **Bench Circular Saw** P.23

Bosch Benchtop Tools – the highest standard in power and precision. Whether you are sawing panels, planks or boards, or making incline cuts or angled cuts – Bosch benchtop tools enable you to work quickly and very precisely thanks to their laser guidance (on the GTM 12 Professional and the GCM 8S Professional). The result: maximum efficiency in every job.

Combination Saw GTM 12 Professional:
Multi-talented tool with 100 % precision

- ▶ Table saw and mitre saw in one tool
- ▶ Precise work with integrated laser
- ▶ Powerful 1800-watt motor for fast work progress up to 95 mm cutting depth in hardwood



Sliding Mitre Saw GCM 8 S Professional:
Top class in precision and compactness

- ▶ Compact and lightweight (only 15 kg) for convenient transport to any construction site
- ▶ Precise working due to integrated laser
- ▶ Powerful 1400-watt motor for fast work progress



The best support for your work:
The Work Bench GTA 3700 Professional fits all Bosch mitre saws and sliding mitre saws. It is easy to transport and it can be quickly assembled without the need for additional tools. It is ideal for working on long workpieces (up to 250 kg) thanks to its support surface, which can be extended to up to 3.7 metres, its roller and its stop.

Double Bevel Slide Mitre Saw GCM 12 SD Professional:
Comfortably a cut above the rest

- ▶ Bevel setting on both sides up to 47°
- ▶ Easy and convenient angle settings on the front of the machine
- ▶ Handle with softgrip can be locked conveniently in 4 positions



Bench Circular Saw GTS 10 Professional:
The powerful tool with large cutting capacity

- ▶ Powerful 1800-watt motor
- ▶ Cutting depths up to 79 mm
- ▶ Cutting capacities up to 635 mm to the right and 330 mm to the left of the saw blade



Bosch benchtop tools – Precision made easy:
The integrated laser (on the GCM 8 S Professional and the GTM 12 Professional) marks exactly where the saw will cut and ensures absolute precision. High-quality, milled scales ensure accurate angle settings over the entire lifetime of your saw.

Benchtop tools at a glance

	Combination Saw GTM 12 Professional	Sliding Mitre Saw GCM 8 S Professional	Sliding Mitre Saw GCM 12 SD Professional	Bench Circular Saw GTS 10 Professional
Rated power input	1.800 W	1.400 W	1.800 W	1.800 W
Saw blade diameter	305 mm	216 mm	305 mm	254 mm
Mitre setting	48°L / 48°R	50°L / 58°R	52°L / 60°R	47°L / 2°R
Bevel setting	47°L	47°L	47°L / 47°R	
Max. cutting capacity at 0°	95 x 151 mm	60 x 270 mm	110 x 305 mm	641 x 737 mm
Weight	22 kg	15 kg	29 kg	34 kg
Part number 110 V	0 601 B15 060	0 601 B16 060	0 601 B23 541	0 601 B30 260
Part number 240 V	0 601 B15 070	0 601 B16 070	0 601 B23 542	0 601 B30 270



“We were constantly recharging half-full batteries because the power had gone. The new lithium-ion cordless screwdrivers have now put an end to that. We can drive more than a pack of 200 screws, 6 x 60 mm, with only one battery charge.”

Andreas Wörlein, master carpenter

Professional power in every voltage class


The right tool for every job.

Cordless tools for professionals with Bosch Premium lithium-ion technology from 3.6 – 36 volts set new standards in performance and reliability. They excel due to their particularly long battery runtime, optimum weight and extreme robustness.

- ▶ **3.6 Volt Cordless Screwdriver** P.26
- ▶ **10.8 Volt Cordless Drill/Driver** P.26
- ▶ **14.4 Volt Cordless Drill/Driver** P.26
- ▶ **18 Volt Cordless Drill/Driver** P.27
- ▶ **36 Volt Cordless Drill/Driver** P.27

Bosch Cordless drill/drivers and screwdrivers are mobile power packs for every application. Bosch is the only manufacturer to offer you a comprehensive range of cordless drill/drivers and screwdrivers from 3.6 volts to 36 volts with lithium-ion technology. The complete Bosch Premium lithium-ion range can be found at www.bosch-professional.com/li-ion

Bosch lithium-ion technology with ECP (Electronic Cell Protection): Protects the battery against overload, overheating and total discharge, therefore ensuring an up to 400% longer lifetime.

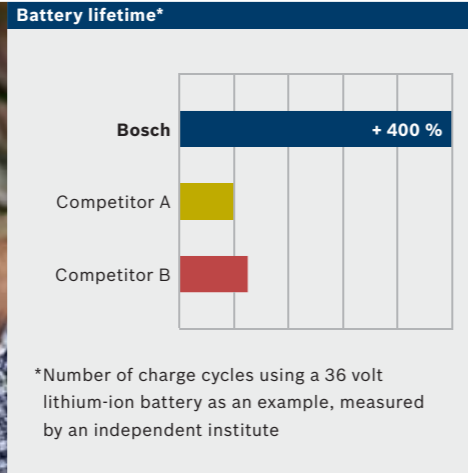

NEW! Cordless Screwdriver GSR ProDrive Professional: World's smallest professional cordless screwdriver

- ▶ Extremely small and handy – fits in any trouser pocket
- ▶ Powerful: 110 screws (3.5 x 30 mm in softwood) with only one battery charge



NEW! Cordless Drill/Driver GSR 10.8 V-LI-2 Professional: 100% drill/driver – at half the size

- ▶ Only half the size of a 12 volt standard cordless drill/driver
- ▶ Professional performance: 2-speed gearbox ensures perfect power transfer when drilling (up to 19 mm) and screwdriving (up to 7 mm)



Cordless screwdrivers and cordless drill/drivers at a glance

	GSR ProDrive Professional	GSR 10.8 V-LI-2 Professional	GSR 14.4 V-LI Professional	GSR 18 VE-2-LI Professional	GSR 36 V-LI Professional
Battery voltage	3.6V	10.8V	14.4V	18V	36V
Max. screw diameter	5 mm	7 mm	7 mm	12 mm	12 mm
Max. drilling diameter in wood	–	19 mm	32 mm	50 mm	50 mm
Torque, hard screwdriving applications	7 Nm	30 Nm	50 Nm	88 Nm	80 Nm
Battery capacity	1.3 Ah Premium	1.3 Ah Premium	2.6 Ah Premium	2.6 Ah Premium	1.3 Ah Premium
Part number	0 601 9A2 070	0 601 868 070	0 601 860 472	0 601 860 F71	0 601 912 174

More information about the professional blue power tools and accessories can be found at www.bosch-professional.com.

NEW! Cordless Drill/Driver GSR 14.4 V-LI Professional: The 14.4 volt long-distance runner: 210 screws per battery charge

- ▶ Highest number of screws driven per battery charge (210 screws, 6 x 60 mm, in softwood)
- ▶ Fast work progress due to powerful motor
- ▶ Perfect handling due to compact design and low weight (only 1.7 kg)



NEW! Cordless Drill/Driver GSR 18 VE-2-LI Professional: The extremely robust 18 volt cordless drill/driver

- ▶ For the toughest screwdriving and drilling applications with high torque in wood and metal
- ▶ Electronic Motor Protection (EMP) protects the motor against overload and ensures a long lifetime
- ▶ Extremely robust: fully functional, even after being dropped 2 metres onto concrete, thanks to flexible Dura-Shield housing



Cordless Drill/Driver GSR 36 V-LI Professional: screwdriving as powerful as corded – over 500 times

- ▶ As powerful as corded: up to 535 screws (6 x 80 mm in softwood) with only one battery charge
- ▶ Enormous power due to lithium-ion technology: it even drives 12 mm screws without a drop in speed
- ▶ Extremely robust: fully functional, even after being dropped 2 metres onto concrete, thanks to flexible Dura-Shield housing



Intelligent solutions for transporting your tools

Bosch Systainer Carrying Cases are a practical modular system for transporting your tools to any job site: they are perfect for gathering together the specific tools you need for the job and for transporting several tools safely and conveniently.

NEW! Systainer carrying cases: Flexible and convenient tool transport – even of several tools

- ▶ 4 different sizes and low weight for flexible and convenient tool transport
- ▶ Easy transport, even of several tools, due to stackable, easy-to-connect carrying cases



Systainer size	II	III	IV	V
Dimensions in mm (L x W x H)	400 x 300 x 157.5	400 x 300 x 210	400 x 300 x 315	400 x 300 x 420
Part number	1 605 438 159	1 605 438 160	1 605 438 161	1 605 438 162

Bosch Transport and Work Benches make it easier to transport your benchtop tools. They are assembled in seconds and are also convenient to transport on uneven construction site terrain thanks to their pneumatic tyres.

NEW! Transport and Work Bench GTA 60 W Professional: For bench circular saws

NEW! Transport and Work Bench GTA 2500 W Professional: For mitre saws and sliding mitre saws

- ▶ Double the benefit: a means of transport and a work bench in one
- ▶ Easy to assemble and dismantle with only one lever movement, without having to remove the benchtop tool



Tool Transport	GTA 60 W Professional	GTA 2500 W Professional
Length of work bench	122 cm	257 cm
Height of work bench	94 cm	84 cm
Weight	29 kg	35 kg
Part number	0 601 B12 000	0 601 B12 100

More information about the professional blue power tools and accessories can be found at www.bosch-professional.com.