

#4136 Twin OFC Loudspeaker Cable 6.0mm², 25m reel



Part NO: #4136

Product Code: RGW-1881

Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

2Cores

Cable Construction

Conductor	Bare Copper
Construction	0.1 ± 0.008 x 37 x 7 x 3
Standard Dia.(mm)	4.28
Insulation	Trans PVC
Thickness	0.9
Insulation Dia.(mm)	6.1 ± 0.1 x 2C
Insulation Color	Trans PVC

Marking

Colour Stripe (Black) on one side for identification

PACKAGING

25M/Reel

RoHS GUIDELINE

We operate according to the following standards


Control Item	Standard	Testing Method	Testing Equipment
Cadmium content (Cd)	<0.01%	EN1122	ICP-AES
Lead content (Pb)	<0.1%	EPA3050B	ICP-AES
Mercury content (Hg)	<0.1%	EPA3052	ICP-AES
Chromium (VI) content	<0.1%	EPA3060(UN-VIS)	ICP-AES
Polybrominated Biphenyls (PBB)	Forbidden	GC/MS	
Polybrominated Diphenyl Ether (PBDE)	Forbidden	GC/MC	

Revision History

A0-1

Price NO.:RGW-

Design

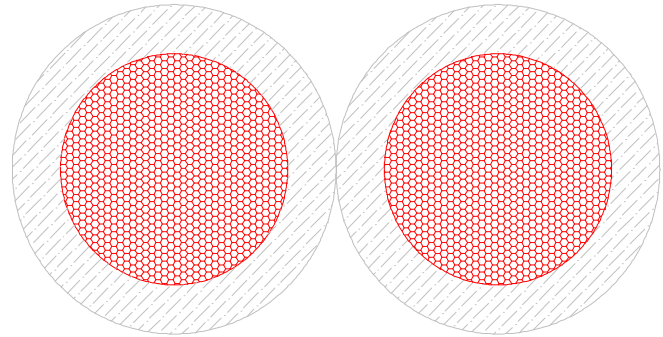

A: Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km)	<3.05
Min.Insulation DC Resistance at 20°C (MΩ *Km)	>200
Rated Temperature(°C)	80
Rated Voltage (V)	300
Capacitance (pF/m)	45 +/- 5
Inductance	0.60μH/m

Date: 2013-03-06

Page: 1 / 1